



## FLEX 12

Project: \_\_\_\_\_

Fixture Type: \_\_\_\_\_

Location: \_\_\_\_\_

Contact/Phone: \_\_\_\_\_

Flexible Low Voltage Trac System

### PENDANT MOUNT FEEDS, SUPPORTS, PENDANTS & ACCESSORIES

TF21, TF22, TF90, TF91, TF92,

T94, T96, TF950 & TF903 thru TF948

#### PRODUCT SPECIFICATIONS


##### Catalog Number TF21SL

**Description** Electrical Feed Cylinder • Heavy gauge beryllium copper contacts • Integral screw terminal connections accept up to 10 gauge solid wire • Wiper-action contact system simplifies installation • One Feed Cylinder required per 25 amp circuit • Use in conjunction with pendant/canopy accessories or Flexible Feed to install with Flex 12 Trac • Silver finish.

**Electrical** Rated 25 amps at 12V (300VA) or 24V (600VA).

**Labels** UL listed, CSA certified • New York City Approved.

Product specifications subject to change without notice.

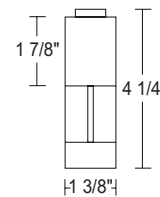


##### Catalog Number TF22SL

**Description** Mechanical Support Cylinder • Provides mechanical support for Flex 12 Trac installation • Same physical dimensions as Feed Cylinder for coordinated appearance • One Support Cylinder is required per trac run and for every 4' of Flex 12 Trac • Use in conjunction with pendant/canopy accessories to install with Flex 12 Trac • Silver finish.

**Labels** UL listed, CSA certified • New York City Approved.

Product specifications subject to change without notice.

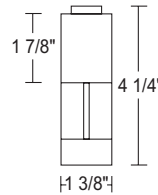


##### Catalog Number TF90SL

**Description** Canopy for T-Bar Ceilings • Combines with Pendant Stem and Feed Cylinder to provide power from the transformer secondary to the Flex 12 Trac • Mounts onto T-Bar runner • Can be electrically fed from the transformer secondary via flexible metal conduit or non-metallic cable entering into the top of the ceiling mounting plate • Silver finish.

**Labels** UL listed, CSA certified • New York City Approved.

 Product specifications subject to change without notice.




##### Catalog Number TF91SL

**Description** Canopy for Rigid Ceilings • Combines with Pendant Stem and Feed Cylinder to provide power from the transformer secondary to the Flex 12 Trac • Mounts over standard 4" ceiling outlet box • Silver finish.

**Labels** UL listed, CSA certified • New York City Approved.

 Product specifications subject to change without notice.



##### Catalog Number TF92SL

**Description** Mini-Canopy • Combines with Pendant Stem and Support Cylinder to provide mechanical support to the Flex 12 Trac • Supplied with toggle bolt for use in drywall ceilings • Installer may substitute wood screw or other fastener as required • Compatible with optional T-bar clip (order separately) for attachment to T-bar ceilings • Silver finish.

 
**Labels** UL listed, CSA certified • New York City Approved.

Product specifications subject to change without notice.

**R37D** - 15/16" T-Bar Clip for drop tile ceilings.

**R37F** - 15/16" T-Bar Clip for flush tile ceilings.

**R37-9-16** - 9/16" T-Bar Clip for drop or flush tile ceilings.



# FLEX 12

Flexible Low Voltage Trac System

## PENDANT MOUNT FEEDS, SUPPORTS, PENDANTS & ACCESSORIES

**TF21, TF22, TF90, TF91, TF92, T94, T96, TF950 & TF903 thru TF948**

### PRODUCT SPECIFICATIONS

**Catalog Number** TF903SL thru TF948SL

**Description** Pendant Stems • Use with Flex 12 Canopies or Surface Transformers to displace trac from ceiling at a fixed distance • Threaded top and bottom • Threads into Canopy, Feed Cylinder or Support Cylinder • Inside diameter accommodates two 10 gauge solid copper wires • Silver finish.


**Labels** UL listed, CSA certified • New York City Approved.

Product specifications subject to change without notice.

### DIMENSIONS

#### PRODUCT CODES

Catalog Number	Description	Length	Finish
TF903SL	Pendant Stem	3 1/2"	Silver
TF912SL	Pendant Stem	12"	Silver
TF918SL	Pendant Stem	18"	Silver
TF924SL	Pendant Stem	24"	Silver
TF936SL	Pendant Stem	36"	Silver
TF948SL	Pendant Stem	48"	Silver

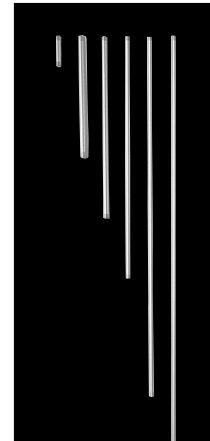

#### T96SL

Pendant Stem Threaded Coupling.  
Enables multiple pendant stems to be joined for higher ceiling applications.

**Catalog Number** T94SL

**Description** Sloped Ceiling Adapter • Permits pendant stems to be hung vertically from sloped ceilings • Used in conjunction with TF91 or TF92 Ceiling Canopy (not included) • Allows feeding of wires to trac at up to a 60 degree angle • Accommodates a maximum of two 12 gauge solid THHN copper wires • Reduces feed capacity to 20 amps maximum • Silver finish.

**Labels** UL listed, CSA certified • New York City Approved.

Product specifications subject to change without notice.



**Catalog Number** TF950SL, TF950SL-144

**Description** Flexible Feed Kit • Allows electrical feed location to be placed independently of mechanical supports • Mounts over standard 4" ceiling outlet box • Can be used in conjunction with Flex 12 Surface Transformer • Canopy provided with 60" (TF950) or 144" (TF950SL-144) of 10 gauge stranded tandem wire • Silver finish canopy • Requires TF21SL Electrical Feed Cylinder (order separately).

**Electrical** Rated 25 amps at 12V (300VA) or 24V (600VA).

**Labels** UL listed, CSA certified • New York City Approved.

Product specifications subject to change without notice.



1300 S. Wolf Road • Des Plaines, IL 60018 • Phone (847) 827-9880 • Fax (847) 827-2925  
220 Chrysler Drive • Brampton, Ontario • Canada L6S 6B6 • Phone (905) 792-7335 • Fax (905) 792-0064  
Visit us at [www.junolightinggroup.com](http://www.junolightinggroup.com)

Printed in U.S.A. ©2009 Juno Lighting, LLC.