

# Premium Outdoor Cords **ProPower™**

ProPower™ contractor grade extension cords are designed with the special needs of the professional contractor in mind. ProPower™ offers our best in durability, weather resistance and flexibility. These cords deliver the most power to your tools, which helps them perform better and last longer.

- **Excellent weather resistance** – our tough outer jacket will not crack in cold weather, even as low as -50°C. During the hot weather, this tough outer jacket will not deform in heat up to 60°C.
- **Heavy-duty strain relief** – these easy grip cord ends keeps plug on cord.
- **Powerlite™** indicator end – the clear ends are rugged, durable and light up when cord has power.
- **High visibility** – these Yellow/Black and Red/Black cords are very visible.
- **Super flexibility** – 30-50% more flexible than standard cords even at -50°C.
- **Longer Life** - 3 times greater resistance to abrasion than standard vinyl cords.
- **Warranty** – Guaranteed for life.

## Single Outlet with Power Indicator Light





ORDER NO.	PRODUCT CODE	GAUGE/ CONDUCTOR	WIRE TYPE	CORD LENGTH (M)	CORD COLOUR	PACK SIZE	SHIP CARTON MC/TRAY/DB
541901	PROMT607M	14/3	SJTW premium	7	Red/Blk	6	TRAY
541902	PROMT615M	14/3	SJTW premium	15	Red/Blk	5	TRAY
541909	PROMT630M	14/3	SJTW premium	30	Red/Blk	3	TRAY
541903	PROMT707M	12/3	SJTW premium	7	Yel/Blk	6	TRAY
541904	PROMT715M	12/3	SJTW premium	15	Yel/Blk	3	TRAY
541911	PROMT730M	12/3	SJTW premium	30	Yel/Blk	2	TRAY

# Premium Outdoor Cords **ProPower**<sup>TM</sup> MC

## 3-Outlet Fantail with Power Indicator Light



541908

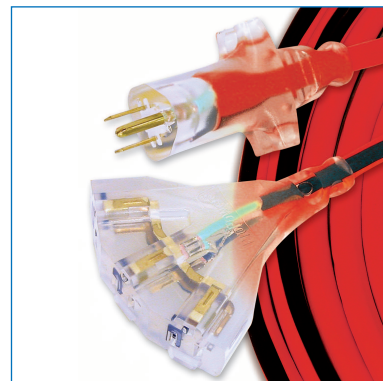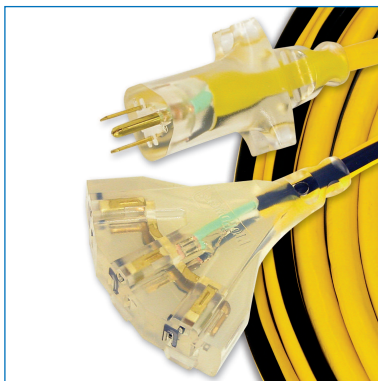

ORDER NO.	PRODUCT CODE	GAUGE/ CONDUCTOR	WIRE TYPE	CORD LENGTH (M)	CORD COLOUR	PACK SIZE	SHIP CARTON MC/TRAY/DB
540836	PROLFT501M	14/3	STW	1	Red/Blk	12	TRAY
541905	PROLFT607M	14/3	SJTW premium	7	Red/Blk	6	TRAY
541906	PROLFT615M	14/3	SJTW premium	15	Red/Blk	5	TRAY
541912	PROLFT630M	14/3	SJTW premium	30	Red/Blk	3	TRAY
541913	PROLFT707M	12/3	SJTW premium	7	Yel/Blk	6	TRAY
541907	PROLFT715M	12/3	SJTW premium	15	Yel/Blk	3	TRAY
541908	PROLFT730M	12/3	SJTW premium	30	Yel/Blk	2	TRAY

### Cord Caddy with 3-Outlet Power Indicator Light

- OIL RESISTANT SJTOW (#545822 only) : Wire does not break down even with frequent contact with oil and standard garage chemicals.
  - Stays flexible even when used in extreme cold weather, down to -40° (545822 & 545825)
- 3 Outlet power Indicator fantail end.
- Easy rewind lever for neat storage.
- Durable, impact-resistant polyethylene housing.
- 15 Amps, 125 Volts.



ORDER NO.	PRODUCT CODE	GAUGE/ CONDUCTOR	WIRE TYPE	CORD LENGTH (M)	CORD COLOUR	PACK SIZE	SHIP CARTON MC/TRAY/DB
545825	CSR1415M	14/3	SJTW	15.2	Black	3	TRAY
545822	CSR12198M	12/3	SJTOW	19.8	Black	3	TRAY