



Project:	Type:	QTY:
Product Code:		

## Product Code

IP65 - 208299 -	COLOR	LAMP	VOLTAGE	OPTION
	<b>B*</b> =Black	15W4K =1750 lumens	<b>120*</b> =120V	SCEC=Surface Conduit Entry Canopy
	W =White	<b>15W5K*</b> =1750 lumens	347**=347V	
	A =Aluminum	21W4K =2450 lumens		
	Z =dark bronze	<b>21W5K*</b> =2450 lumens		
	CC=Custom Color	30W4K =3500 lumens		
		<b>30W5K*</b> =3500 lumens		

Note: \* Components usually in stock for rapid assembly and shipping  
\*\* 347V comes with SCEC

## Features + Specifications

### Intended Use:

- Building interior/exterior

### Construction:

- Die-cast aluminum body & lens frame
- Clear tampered glass lens
- Extruded silicone gasket
- Wet location listed

### Finish:

- Powder coat paint finish

### Optical System:

- High Brightness CREE XT-E at 100+ lumens per LED watt
- Specially designed elliptical lens 135°x 75° rectilinear distribution
- 4100K or 5000K CCT, 75+ CRI Standard
- Computer designed thermal management
- Low Tj temperature offers 60000+ L70 life rating (LM-80, TM-21)
- Entire optical system enclosed inside IP65 rated housing

### Electrical System:

- Specially designed Constant Current driver technology
- Total System watts 18W, 25W & 36W
- 120V AC input can withstand 300V AC surge for 5 Sec
- HPF, thermally & short circuit protected
- 277V-347V AC input also available\*\*


### Mounting:

- 8 - 12ft mounting height

Right reserved for material and spec. modification without prior notice.

Datecode 20140918

Warranty - Up To 3 Years

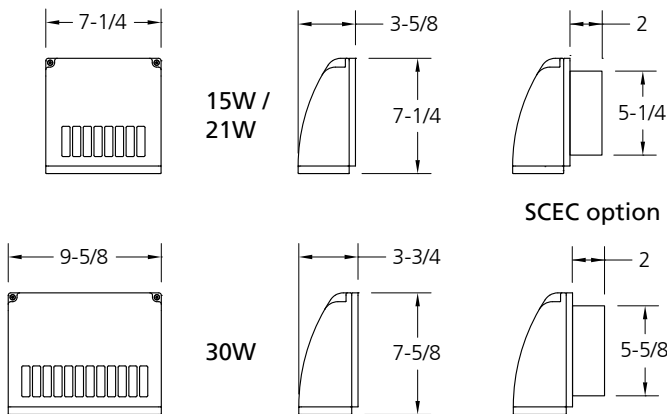

Certified to CSA C22.2 No.250.0 Conformed to UL 1598

Certification Marks (where applicable) will be found on our luminaires and its components



[www.iplighting.com](http://www.iplighting.com)

Light of Your World

