



Project:	Type:	QTY:
Product Code:		

Product Code

IP65 - 807210 -	COLOR	LAMP	VOLTAGE	OPTIONS
	B =Black CC=Custom Color	10W4K	UNV=120-277V	CP1 PCP1-347=347V Power Canopy GSV1 =Glare Shield Visor

Features + Specifications

Intended Use:

- Building interior/exterior
- Wet location listed
- Replace 90W Par38 incandescent or 26W PL lamp floods

Construction:

- Die-cast aluminum body and lens frame
- Tempered clear glass lens
- Extruded one piece silicone gasket
- Heavy gauge adjustable mounting bracket
- All stainless steel fastener
- 30CM connection cord with stripped ends

Finish:

- Powder coat paint

Optical System:


- High power COB (chip on board) Bridgelux LED
- 4100K, 75 CRI, 35000hrs L70, 800 lumens, LM79 tested
- Optional 3000K, red, blue, green color COB available
- 120° x 60° one piece semi-specular reflector

Electrical System:

- Good quality Constant Current driver
- HPF + High Efficiency, cold weather rated
- Short circuit and overheat protected
- RoHS compliant

Mounting:

- Yoke mount bracket screw directly onto flat surface
- CP1 = Optional mounting plate fits over round outlet box
- PCP1-347 = Optional power mounting canopy with 347V converter
- GSV1 = Optional glare shield visor, factory install

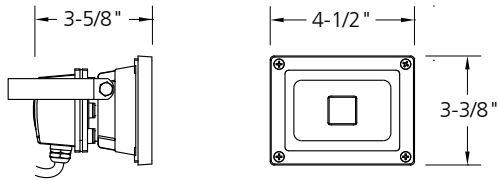

10W, 4100K, 800 lumens, 360.7CD Max, 104° Beam:

Distance	Center Beam fc		Beam Ø		
	ft	m	ft	m	
4'	1.2m	22.0 fc	236 lx	10.3'	3.1m
8'	2.4m	5.5 fc	60 lx	20.6'	6.3m
12'	3.7m	2.4 fc	26 lx	31.0'	9.4m
16'	4.9m	1.3 fc	14 lx	41.3'	12.6m
20'	6.1m	0.9 fc	10 lx	51.6'	15.7m



Light of Your World



www.iplighting.com

Certified to CSA C22.2 No.250.0 Conformed to UL 1598

Certification Marks (where applicable) will be found on our luminaires and its components



Right reserved for material and spec. modification without prior notice.

Datecode 20141222

Warranty - Up To 3 Years