



New LED Floodlights from Lind. In stock & ready for you to pick up.



LE970LED-TR



LE970LED-FS

Heavy-Duty LED Floodlight

- The LE970LED-FS is a bright and rugged LED floodlight that can easily replace a 500W quartz halogen light without the worries of constantly replacing bulbs or concerns about heat from the lamp
- The 50W integrated LED chip is cool running, operates really well in cold temperatures, and is rated for 50,000 hours
- Available with an aluminum floor stand or a 4-8' aluminum tripod stand so that the light can be aimed wherever necessary

- Approvals: ETL portable work light
- Light Temperature: 4500K (bright white light - no blue tint)
- Lumens: 5,000
- LED Life Expectancy: 50,000 hours
- Environmental Rating: IP65
- Construction: Cast aluminum housing, 15' 18/3 SJOW cord, tempered glass lens

Check out our handy Wire Stripping Tools from Rack-a-Tiers!

Copper Wire Stripper Jr.


- All aluminum frame
- Hardened one piece blade
- Strips solid core or braided wire
- Blade made from tool steel
- Blade easily re-sharpened
- Fully adjustable wire guide

Copper Wire Stripper (cws-1 & 2)

- All aluminum frame
- Hardened one piece blade
- Strips solid core or braided wire
- Blade made from tool steel
- Blade easily re-sharpened
- Fully adjustable wire guide
- Bench model - Anti-slip base



47030

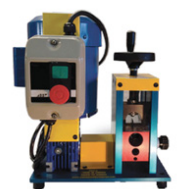

47100 (CWS-1)
47200 (CWS-2)

