

# FILLERS & CONNECTORS

## KO KILLERS: PLASTIC KNOCKOUT FILLERS

Fits thin (1/32") and thick (1/8") wall thickness.

### Features

- No tools required
- Snap in and out with ease
- Non-conductive, safer



- Part# KOK50 - 1/2" Filler (50/bag)
- Part# KOK75 - 3/4" Filler (50/bag)
- Part# KOK100 - 1" Filler (25/bag)
- Part# KOK125 - 1 1/4" Filler (25/bag)
- Part# KOK150 - 1 1/2" Filler (25/bag)
- Part# KOK200 - 2" Filler (25/bag)
- Part# KOK999 - Assorted Fillers Kit (25/bag)

## RAT 500

Rapid Fire NMSC connector

Suitable for all 1/2" knockouts  
Fast and Easy. No tools required

### Features

- 100/bag
- Single cables
- Two cables
- Install from outside

## RAT 750

Rapid Fire NMSC connector

Suitable for all 3/4" knockouts  
Fast and Easy. No tools required

### Features

- 50/bag
- Single cables
- Install from outside



- Part#
- RAT500 1/2" Connector
- RAT750 3/4" Connector

## TT500

NMSC Two Way 1/2" Connector

Installs from inside and outside the box

### Features:

- 100/bag
- Single cables
- Two cables

- Part#
- TT500



## STUD BUDDIES


Why Square Bushing? 70% More cross sectional area! More cables, easier pulls.

- One piece
- One hand installation
- Fits all standard steel studs & punches
- Fire rated V.O.
- Faster, easier to use

- Part#
- ROUND - SB200
- SQUARE - SB400



## 6.5 BLANK PLATE

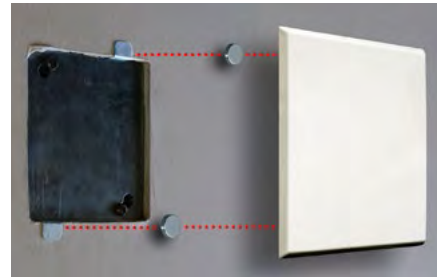

Part# D612

- Installs in seconds with rare earth magnets - snaps in place to metal clips (included)
- White decorative plate covers any 5-1/2" square hole or electrical box
- Can also be used to cover a round hole with up to a 5-1/2" diameter
- Visually appealing white decorative plate - no need to paint metal covers

## AIRCRAFT CABLE & WIRE CRIMPS

- Available in 500 and 1,000 Feet.
- No need to go anywhere else - Buy it from us!



- Part# SC500 - Aircraft Seismic Cable 500'
- Part# SC1000 - Aircraft Seismic Cable 1000'
- Part# SCC116 - Aircraft Seismic Cable Clamps

# NON-METALLIC CABLE SUPPORT SYSTEM

By SpeedWay

### QUICK & EASY INSTALLATION

- No structural damage from drilling
- No gluing
- Easily add cables
- Great for new construction
- Add circuits when needed
- Perfect for remodelling
- No more expensive drill bits
- Reduce home run length up to 30%



## LEVEL JACK


Alignment tabs reach across wood/metal studs to level low voltage outlets with A.C. boxes.

### Features

- No tape measure
- No level required



- Part#
- LJ50R - 1/2"
- LJ58R - 5/8"
- LJ100R - 1"

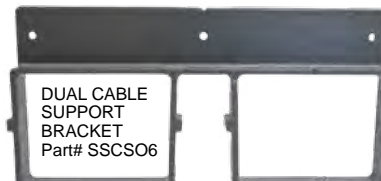

## EZ-CLIP

The EZ-Clip is a snap-on protection plate designed specifically for steel studs. Its one size fits all design will quickly and easily snap on to any steel stud. **NO SCREWS REQUIRED!**

- CSA approved for Canada and the U.S.
- Made from 1.6mm galvanized metal
- Protects your wire from drywall screws
- Fast, easy and simple
- No screws required
- Made in Canada

Part# SPE100 - 100 PACK  
Part# SPE25 - 25 PACK

# CABLE EZE

- Protection from radius bends for all data cables
- Rapid ease of installation (seconds to install, saves time and money)
- No tools required for installation (no need to cut and compromise the strength of basket tray)
- Ability to utilise Cable Eze anywhere on tray
- Can be retro fitted or installed after cable rough in
- Made from nylon
- Can be removed and reinstalled where necessary
- Fits all brands of 100mm x 50mm cable trays

Part# 42240

8 AND 10 FOOT LENGTHS AVAILABLE!

## MAXIMUM NUMBER OF INSTALLED CABLES ALLOWED

CABLE TYPES NMB-UF-SEU		CABLE TYPES NMB-UF-SEU	
CABLE WIRE SIZES	MAX NUMBER OF INSTALLED CABLES	CABLE WIRE SIZES	MAX NUMBER OF INSTALLED CABLES
14-2	38	14-3	29
12-2	30	12-3	23
10-2	22	10-3	16
8-2	14	8-3	10
6-2	10	6-3	6
4-2	5	4-3	3
2-2	4	2-3	2
2/0-2	2	2/0-3	1
4/0-2	2	4/0-3	1

Note: All cables listed contain an equipment grounding conductor that is bare and covered with the cable sheath. Passed UL temperature test with 80% load of the over-current device. Combinations of cables can be used not exceeding 40% maximum fill. UL Listed for one and two family dwellings.

# ULTRA-SIDEWINDER

CABLE PROTECTION SYSTEMS



### FEATURES:

- ARTICULATION PIECES OFFER FLEXIBLE DESIGN - CURVES, CORNERS & S-CURVES ARE EASILY MADE WHILE MAINTAINING A COMPLETELY FLAT PROFILE.
- SIMPLE INSTALLATION. NO TOOLS REQUIRED.
- AVAILABLE IN BLACK, YELLOW, BROWN, AND GRAY.
- FULLY-CUSTOMIZABLE LENGTH - FROM 4.5" TO AN UNLIMITED LENGTH.

Cavity Size: 3/4" W x 3/8" H

Part#	Description
U1800BY	3 FT System W/ Endcaps - Black & Yellow
U1802BK	3 FT System W/ Endcaps - Black
U1804BR	3 FT System W/ Endcaps - Brown
U1806G	3 FT System W/ Endcaps - Gray
U1801BY	1 FT Extension System - Black & Yellow
U1803BK	1 FT Extension System - Black
U1805BR	1 FT Extension System - Brown
U1807G	1 FT Extension System - Gray

# TEMPORARY CABLE GUARD

5' LONG X 4.5" WIDE X 1.25" HIGH

Accommodates cable up to .75" in diameter. Withstands heavy vehicle traffic.

Part# TCG5

The Temporary Cable Guard withstands heavy vehicle traffic without damaging cable. Easily anchored with concrete screws if needed. The Temporary Cable Guard helps you restore services quickly by allowing you to run temporary cables over most any surface. It reduces truck rolls and eliminates downtime due to cable cuts, storm damage, traffic or roadway activities.

5' LONG X 10.5" WIDE X 2.75" HIGH

Accommodates a cable/bundle up to 2.25". Withstands heavy vehicle traffic.

Part# TPG5




## The Original ELECTRICAL REFERENCE BOOKS

### EVERYONE NEEDS AN UGLY'S ON THE JOB REFERENCE

- Mathematical formulas
- National electrical code
- Wiring configurations
- Conduit bending
- Voltage drops

PART #S	Description
73213	ELECTRICAL DESK REFERENCE
73214	ELECTRICAL SAFETY & NFPA 70E®
73215	ELECTRICAL REFERENCES
73216	ELECTRIC MOTORS & CONTROLS
73217	REFERENCIAS ELÉCTRICAS

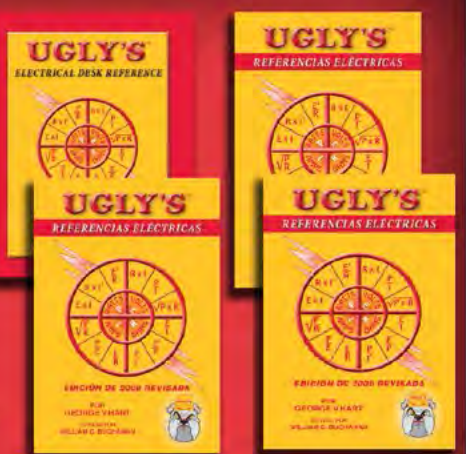

Part#	Description	Page	Part#	Description	Page
10455	Hooker - Wrench Adaptor	2	72000	Magnetic Bit Holder	39
11455	Rack-A-Tiers	1	72101, 72102	Nut Blaster XL and XXL	28
11460	Rack-N-Go	2	72120	ProGrabit	39
11555	Stick	3	7213series	LockHard Bits	38
11655	X-Dispenser	3	7321series	Ugly's Electrical Reference Books	45
118series	Reel Macs & Spindles	8	75000	Breaker Lok	28
119series	Spool Mac & Caddy Mac Line	7	77455	Bend-All	10
11931, 11932	Tug Wise Standard and Deluxe	4	78series	Bulldog Benders, The	10
12800	Spool Aid	4	7WBK100	Panel Buddy Knockout Kit	28
13355	Plate Visé	29	83000	LaserLine	29
17455	Reel-End	3	84000, 84100	Dirt Bag & Chip Catcher	36
18455	Wire Tub	5	88455	Laser Plumb Bob	23
19455	Thomas Wheeler	5	90101	Vacuum Adapter	35
19955	Wire-Pod	6	90103	Hole Saw Dust Shield	35
19Stud Reel Series	Stud Reels & Floor Units	6	90105	Arbor Hole Saw Adapter	35
40001	Wire Vortex	14	90200, 90300, 90400	Hole Pro - Hole Cutters	35
41100	PullLee	16	914series	TCT Masonry Hole Cutters	31
42200	LB Wire Guide	16	916series	TCT Mega Hole Cutters	31
42240	Cable Eze	43	91700	Rev-Bit	32
42400	Ropematic Pro	13	93series	Steel Cutters	31
42600	Cone Heads	15	94series	Gid-O	31
42620	Flex Puller	15	95000	Javelin	32
42800, 42900	Magnepull & Magnespot	18	97008	Qwik Lok	28
42series	All-American Pull Buddies	16	99000, 99001	AC Sensor & Ultimate AC Sensor	24
43002	Big Lugg 2	22	99005	Piper Conduit	12
43015, 43095, 43100	Butt Pouches	21	99101	Circuit Siren	24
43055	Electrician's Holster	21	99102	Plug Master	24
432series	Combo Tool Belt & Pouches	21	99215	EZ Generator Switch	24
434series	Support Belt	21	ATB1312	Aerial Tool Bin	40
43606	Suspenders	21	AUFILE	Auger Bit File	34
43706, 43707	Tool Carriers	21	AW34OD, AW78OD	OverDrive Bits	34
45200	Shoppe Rocket	23	AWseries	Auger - Standard & Tri-Cut	34
45303	Straight Shot	24	BB3412	Bumper Balls	34
45404	Jet Level	24	BPseries	Bag Pipers	15
47000, 47002	Croc's Needle Nose Wire Strippers & Jr.	26	CC1200, CT1100	Cable Caddy & Cable Truck	8
47001	V-Cutter	26	CC2000, CC2000D	Cable Cart & Cable Cart Data	8
47020	Easy Stripper	9	CD3000, CD3100	Cable Dolly & Jr	8
47030	Copper Wire Stripper Jr.	9	D612	Magnetic Drywall Plate Cover Kit	44
47099	Booty Pack	22	EF003	Efergy Elite Classic	24
47100	CWS-1 Copper Wire Stripper	9	ENseries	Nylon Fish Tapes & Polyester Fish Tapes	20
47200	CWS-2 Copper Wire Stripper	9	ETD034	Dirt Auger System	34
48000	Driller's Dust Bowl	35	ETseries	Switch Bits	33
51000	Exploding Garbage Can	36	FIB-GUD	Guide Tool	33
52300	Stud Ball	30	FIBLseries	Fibersnakes 5/16"	20
52455	Staple Shark	25	FIBRseries	Fibersnakes 1/4"	20
52466, 52486	Pencil & Quick Draw Felt Pen	28	FIBseries	Fiberfish Attachments	19
53020	Gopher 2	27	FIBTseries	Fibersnakes 3/16" 50' - 300'	20
53300, 53400	Owl Eye & Fire Fly	27	FLXseries	Piranhabits - High Speed Steel	33
53500, 53600	Stick Bug & Jr.	27	GLFseries	Plastic Coated Glowfish	19
54000, 54020	Glow Safe 360	40	KOKseries	KO Killers Connectors	43
55455	E-Z Roll	2	LJseries	Level Jacks	43
55632	Big E-Z	2	MLTseries	Multi-Bit Step Drills	31
56000	Pocket-Kart	4	Nseries	Nut Huggers	29
57050, 57075	Hoppy Bender	11	NT1050	Extendo Nut Driver	26
58series	Pipe Vipers	12	Pseries	Picquic Screwdrivers	39
65000	Bulb Caddy	27	PCFseries	Plastic Coated Fiberfish	19
65100, 65200	Shinmates	27	QTTseries	Quattro Flex Auger Bits	33
65300	Ladder-Mate	27	RAT500, RAT750	NMSC Connectors	43
66455	Knee Pads	22	RMseries	Mag Daddy	41-42
66536	Lift-N-Lok Tool Box	22	RS10series	Racky Straps	42
67119	Sluggo-Ox	30	RVseries	Van Magnets	41-42
67441	Bolt Template	40	SBseries	Stud Buddies Connectors	43
67500	GD Center Finder	14	SCseries	Aircraft Cable & Wire Crimps	44
68075	Alignment Tool	14	SDR14	Rolgear Screwdriver	39
69010	Fish Heads	17	SDseries	Robertson Screwdrivers	39
69050, 69075	Flex Flyers	17	SPEseries	EZ Clip	43
69455	Snatch Strap	17	SS1series	Standard Super Set, Super Set 18	19
69700, 69705	Penguin Puller Sr & Jr,	15	SSseries	Speedway Cable Support System	44
70000	Holdsabot	38	TPG5, TCG5	Temporary Cable Guard	45
7bit series	Racky Driver Bits	37-38	TT500	Tom Two-Way Connector	43
70988	Magnetizer / Demagnetizer	39	U18series	Sidewinders	45

# ATTENTION ALL WHOLESALERS!

SPRUCE UP YOUR SHOWROOM WITH A GREAT LOOKING DISPLAY FROM **RACK-A-TIERS**



**MOBILE 12 DISPLAY**  
Part# MOBILEDISPLAY12



**16" X 36" METAL PANEL WALL DISPLAY**  
Part# WALLDISPLAY16



**RACKY BITS**  
**COUNTERTOP DISPLAY**  
PART# 70SKE12



**24" X 48" PAPER WALL PANELS**  
Part# WALLPAPER-BK (24"x 48")

## RackRewards

### CONTRACTOR REWARDS PROGRAM

#### BUY RACK-A-TIERS PRODUCTS

Visit your favourite electrical wholesaler and purchase eligible Rack-A-Tiers products.

#### REGISTER YOUR PRODUCT CODES

Find the 10 digit code on your product packaging and enter it on the "Enter a Code" page. Volts are automatically added to your account!

XXX-XXXX-XX-XXXXX

#### GET REWARDS! (FREE STUFF)

Volts are just like money. Redeem your Volts for items in the Rewards Store. You'll find tons of different rewards like free Rack-A-Tiers Products, Electronics and More!



## INVENTOR'S CORNER

Find yourself flipping through the Rack-A-Tiers catalog wishing you thought of that tool, or frustrated that you thought of that idea first? Well, here's your chance to put your ideas into action. Rack-A-Tiers launched Inventor's Corner for creative folks like you to pitch ideas and read testimonials from past inventors.

We pride ourselves on being the most innovative and unique tool company in the electrical industry. As we continue to grow, more and more electricians approach us with great ideas. We would love to see every electrician get his or her idea into the market and will do everything in our power to make that happen. Even if Rack-A-Tiers is unable to add your idea to our product line, we have the experience and knowledge to provide advice for your next move as an inventor. Check out the Inventor's Corner at [rack-a-tiers.com/inventors](http://rack-a-tiers.com/inventors) and who knows maybe in next year's catalog your product could have a full-page spread.

