

# ULTRA-SIDEWINDER

CABLE PROTECTION SYSTEMS

## FEATURES:

- ARTICULATION PIECES OFFER FLEXIBLE DESIGN - CURVES, CORNERS & S-CURVES ARE EASILY MADE WHILE MAINTAINING A COMPLETELY FLAT PROFILE.
- SIMPLE INSTALLATION. NO TOOLS REQUIRED.
- AVAILABLE IN BLACK, YELLOW, BROWN, AND GRAY.
- FULLY-CUSTOMIZABLE LENGTH - FROM 4.5" TO AN UNLIMITED LENGTH.



Cavity Size: 3/4" W x 3/8" H

Part#	Description
U1800BY	3 FT System W/ Endcaps - Black & Yellow
U1802BK	3 FT System W/ Endcaps - Black
U1804BR	3 FT System W/ Endcaps - Brown
U1806G	3 FT System W/ Endcaps - Gray
U1801BY	1 FT Extension System - Black & Yellow
U1803BK	1 FT Extension System - Black
U1805BR	1 FT Extension System - Brown
U1807G	1 FT Extension System - Gray

# TEMPORARY CABLE GUARD

5' LONG X 4.5" WIDE X 1.25" HIGH

Accommodates cable up to .75" in diameter. Withstands heavy vehicle traffic. Part# TCG5

The Temporary Cable Guard withstands heavy vehicle traffic without damaging cable. Easily anchored with concrete screws if needed. The Temporary Cable Guard helps you restore services quickly by allowing you to run temporary cables over most any surface. It reduces truck rolls and eliminates downtime due to cable cuts, storm damage, traffic or roadway activities.

5' LONG X 10.5" WIDE X 2.75" HIGH

Accommodates a cable/bundle up to 2.25". Withstands heavy vehicle traffic. Part# TPG5

# ELECTRICAL CODE SIMPLIFIED PS KNIGHT

## FEATURES:


- Now over 1200 pages
- Over 1000 code rules & revisions, clearly explained & indexed
- Code tables & practice exam
- 400 questions & answers added

## MFG NOTE

The industry's most comprehensive publication on Canadian electrical code that clarifies the New Code Rules.

Electrical Code Simplified Part# 73129

Electrical Code Simplified - Residential Part# 73115

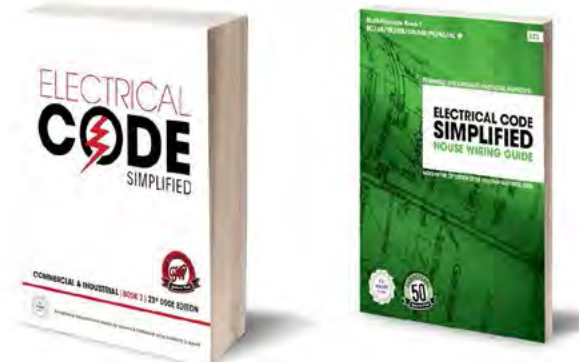

Part#	Description	Page	Part#	Description	Page
10455	Hooker - Wrench Adaptor	2	72120	ProGrabit	37
11455	Rack-A-Tiers	1	7213series	LockHard Bits	36
11460	Rack-N-Go	2	75000	Breaker Lok	26
11555	Stick	3	77455	Bend-All	8
11655	X-Dispenser	3	78series	Bulldog Benders, The	8
13355	Plate Vise	27	7bitseries	Racky Driver Bits	35-36
18455	Wire Tub	3	7WBK100	Panel Buddy Knockout Kit	26
118series	Reel Macs & Spindles	6	83000	LaserLine	27
119series	Spool Mac & Caddy Mac Line	5	84000, 84100	Dirt Bag & Chip Catcher	34
11931, 11932	Tug Wise Standard and Deluxe	4	88455	Laser Plumb Bob	21
2Super Rod Series	Super Rod	16	90101	Vacuum Adapter	33
40001	Wire Vortex	16	90103	Hole Saw Dust Shield	33
40400	Stingray	16	90105	Arbor Hole Saw Adapter	33
42200	LB Wire Guide	14	90200, 90300, 90400	Hole Pro - Hole Cutters	33
42240	Cable Eze	43	914series	TCT Masonry Hole Cutters	29
42400	Ropematic Pro	14	916series	TCT Mega Hole Cutters	29
42600	Cone Heads	13	91700	Rev-Bit	30
42620	Flex Puller	13	93series	Steel Cutters	29
42800, 42900	Magnepull & Magnespot	11	94series	Gid-O	29
42series	All-American Pull Buddies	14	95000	Javelin	30
43002	Big Lugg 2	20	97008	Qwik Lok	26
43015, 43095, 43100	Butt Pouches	19	99000, 99001	AC Sensor & Ultimate AC Sensor	22
43055	Electrician's Holster	19	99005	Piper Conduit	10
432series	Combo Tool Belt & Pouches	19	99101	Circuit Siren	22
434series	Support Belt	19	99102	Plug Master	22
43606	Suspenders	19	99215	EZ Generator Switch	22
43706, 43707	Tool Carriers	19	ATB1312	Aerial Tool Bin	38
45200	Shoppe Rocket	21	AUFILE	Auger Bit File	32
45303	Straight Shot	22	AW34OD, AW78OD	OverDrive Bits	32
45404	Jet Level	22	AWseries	Auger - Standard & Tri-Cut	32
47000, 47002	Croc's Needle Nose Wire Strippers & Jr.	24	BB3412	Bumper Balls	32
47010	V-Cutter	24	BPseries	Bag Pipers	13
47020	Easy Stripper	7	CC1200, CT1100	Cable Caddy & Cable Truck	6
47030	Copper Wire Stripper Jr.	7	CC2000, CC2000D	Cable Cart & Cable Cart Data	6
47099	Booty Pack	20	CD3000, CD3100	Cable Dolly & Jr	6
47100	CWS-1 Copper Wire Stripper	7	D612	Magnetic Drywall Plate Cover Kit	42
47200	CWS-2 Copper Wire Stripper	7	EF003	Efergy Elite Classic	22
48000	Driller's Dust Bowl	33	ENseries	Nylon Fish Tapes & Polyester Fish Tapes	18
51000	Exploding Garbage Can	34	ETD034	Dirt Auger System	32
52300	Stud Ball	28	ETseries	Switch Bits	31
52455	Staple Shark	23	FIB-GUD	Guide Tool	31
52466, 52486	Pencil & Quick Draw Felt Pen	26	FIBseries	Fiberfish Attachments	17
53020	Gopher 2	25	FIBLseries	Fibersnakes 5/16"	18
53300, 53400	Owl Eye & Fire Fly	25	FIBRseries	Fibersnakes 1/4"	18
53500, 53600	Stick Bug & Jr.	25	FIBTseries	Fibersnakes 3/16" 50' - 300'	18
54000, 54020	Glow Safe 360	38	FLXseries	Piranhabits - High Speed Steel	31
55455	E-Z Roll	2	Fseries	Robertson Screws	44
55632	Big E-Z	2	GLFseries	Plastic Coated Glowfish	17
56000	Pocket-Kart	4	KOKseries	KO Killers Connectors	43
57050, 57075	Hoppy Bender	9	LJseries	Level Jacks	43
58series	Pipe Vipers	10	MLTseries	Multi-Bit Step Drills	29
65000	Bulb Caddy	25	NT1050	Extendo Nut Driver	24
65100, 65200	Shinmates	25	Pseries	Picquic Screwdrivers	37
65300	Ladder-Mate	25	PCFseries	Plastic Coated Fiberfish	17
66455	Knee Pads	20	QTTseries	Quattro Flex Auger Bits	31
66536	Lift-N-Lok Tool Box	20	RAT500, RAT750	NMSC Connectors	43
67119	Sluggo-Ox	28	RMseries	Mag Daddy	39-40
67441	Bolt Template	38	RS10series	Racky Straps	40
67500	GD Center Finder	12	RVseries	Van Magnets	39-40
68075	Alignment Tool	12	SBseries	Stud Buddies Connectors	43
69010	Fish Heads	15	SCseries	Aircraft Cable & Wire Crimps	42
69050, 69075	Flex Flyers	15	SDR14	Rolgear Screwdriver	37
69455	Snatch Strap	15	SDseries	Robertson Screwdrivers	37
69700, 69705	Penguin Puller Sr. & Jr.	13	SPEseries	EZ Clip	43
70000	Holdsabit	36	SS1series	Standard Super Set, Super Set 18	17
70988	Magnetizer / Demagnetizer	37	TPG5, TCG5	Temporary Cable Guard	45
72000	Magnetic Bit Holder	37	TT500	Tom Two-Way Connector	43
72101, 72102	Nut Blaster XL and XXL	26	U18series	Sidewinders	45