


OUTDOOR EXTENSION CORDS

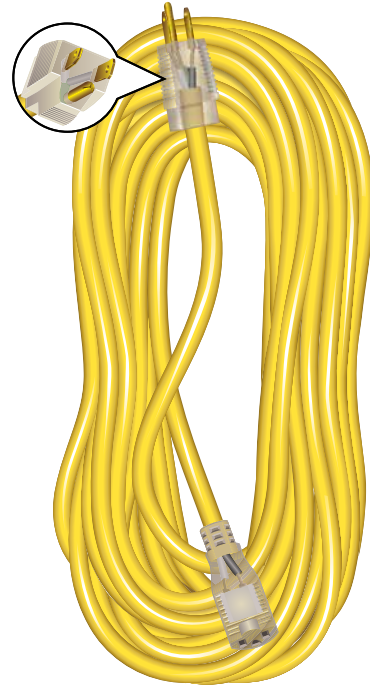

IRRIGATION CABLE



APPLICATIONS Suitable for use as follows:

- Construction, industrial, & maintenance job site power supply cord

CONSTRUCTION

- Quick Check® power indicator lighted end
- All Weather
- SJ Cord , 300 Volt
- NEMA 5-15
- Conductor Grounded

STANDARDS & REFERENCES

- UL & cUL Listed

Tuf-Flex® Oil & Water Resistant Jacket & Insulation

Pro-Grade: Water & Weather Resistant -50°C to +60°C

SJTW: Extra Flexible -40°C to +60°C

TUF-FLEX® SJE00W/SJT00W - 300 VOLT

SIZE (AWG) AND NUMBER OF CONDUCTORS	LENGTH (feet)	CORD COLOR	RATING	STANDARD CARTON	
				QTY.	APPROX. WEIGHT (lbs)
14/3	50	BLUE	15 A 125 V 1875 W	10	42
14/3	100	BLUE	13 A 125 V 1625 W	5	44
12/3	50	BLUE	15 A 125 V 1875 W	8	53
12/3	100	BLUE	15 A 125 V 1875 W	3	40
10/3	100	BLUE	15 A 125 V 1875 W	1	23

Stays Flexible in Extreme Cold or Hot Conditions Light Weight -50°C to +105°C

PRO-GRADE CONTRACTOR CORDS - SJTW - 300 VOLT

SIZE (AWG) AND NUMBER OF CONDUCTORS	LENGTH (feet)	CORD COLOR	RATING	STANDARD CARTON	
				QTY.	APPROX. WEIGHT (lbs)
14/3	25	YELLOW	15 A 125 V 1875 W	14	38
14/3	50	YELLOW	15 A 125 V 1875 W	10	52
12/3	50	YELLOW	15 A 125 V 1875 W	6	43
12/3	100	YELLOW	15 A 125 V 1875 W	3	44

SJTW - 300 VOLT

SIZE (AWG) AND NUMBER OF CONDUCTORS	LENGTH (feet)	CORD COLOR	RATING	STANDARD CARTON	
				QTY.	APPROX. WEIGHT (lbs)
16/3	25	YELLOW	13 A 125 V 1625 W	24	47
16/3	50	YELLOW	13 A 125 V 1625 W	12	46
14/3	25	ORANGE WITH BLACK STRIPE	15 A 125 V 1875 W	14	31
14/3	50	ORANGE WITH BLACK STRIPE	15 A 125 V 1875 W	10	50
14/3	100	ORANGE WITH BLACK STRIPE	13 A 125 V 1625 W	5	41
12/3	25	YELLOW	15 A 125 V 1875 W	10	40
12/3	50	YELLOW	15 A 125 V 1875 W	6	44
12/3	100	YELLOW	15 A 125 V 1875 W	3	42
10/3	100	YELLOW WITH BLACK STRIPE	15 A 125 V 1875 W	1	24

SJTW, 3 OUTLET POWER BLOCK - 300 VOLT

SIZE (AWG) AND NUMBER OF CONDUCTORS	LENGTH (feet)	CORD COLOR	RATING	STANDARD CARTON	
				QTY.	APPROX. WEIGHT (lbs)
14/3	25	ORANGE WITH BLACK STRIPE	15 A 125 V 1875 W	14	39
14/3	50	ORANGE WITH BLACK STRIPE	15 A 125 V 1875 W	10	50
12/3	25	YELLOW	15 A 125 V 1875 W	10	39
12/3	50	YELLOW	15 A 125 V 1875 W	6	46
12/3	100	YELLOW	15 A 125 V 1875 W	3	43

STW, 600 VOLT, ALL WEATHER 3 - OUTLET U-GROUND ADAPTER

SIZE (AWG) AND NUMBER OF CONDUCTORS	LENGTH (feet)	CORD COLOR	RATING	STANDARD CARTON	
				QTY.	APPROX. WEIGHT (lbs)
12/3	2	YELLOW	15 A 125 V 1875 W	40	30

PORTABLE GROUND FAULT CIRCUIT INTERRUPTER (GFCI)

SIZE (AWG) AND NUMBER OF CONDUCTORS	LENGTH (feet)	CORD COLOR	RATING	STANDARD CARTON	
				QTY.	APPROX. WEIGHT (lbs)
3-OUTLET POWER BLOCK - SJTW					
14/3	3	ORG/BLACK	15 A 125 V 1875 W	6	7
SINGLE WITH MALE AND FEMALE NEMA L5-20 - STW					
12/3	3	YELLOW	20 A 125 V 2500 W	6	9

OUTDOOR EXTENSION CORDS