



Overview


The 270 Series non-coded station will activate a positive alarm by pulling the alarm handle out and down. The station also provides a normally open alarm contact with a rating of 3 amps at 30VAC/60 Vdc. The finish is red enamel with aluminum markings.

Two versions are available. The SPOW series uses wire leads for field wiring connections. The SPO series is equipped with a terminal block for connection of field wiring up to 12 AWG max.

The hardy die-cast housing is finished with Fire Red alkyd baking enamel complemented by painted aluminum stripes and markings. English, French, and Bilingual models are available.

The 270 series Manual Stations can be semi-flush or surface mounted. The semi-flush style mounts to a recessed 4" (100mm) standard North-American electrical box with a single gang 1/2" (12mm) raised plaster cover. Surface mounting requires Catalogue number 27193-11 surface mount box.

Installation and Mounting

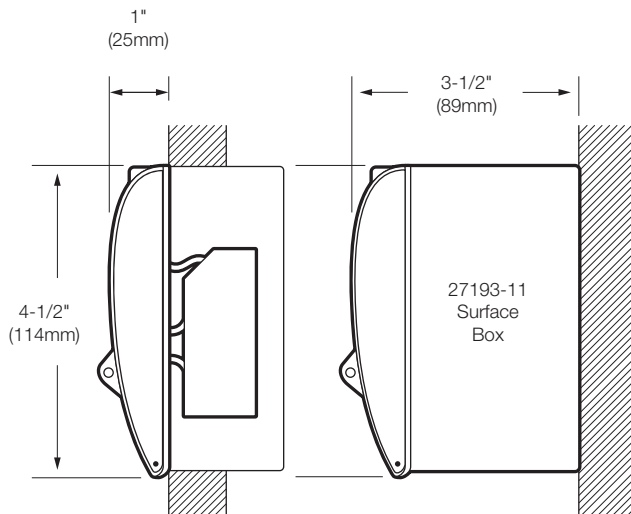

Standard Features

- Surface or semi-flush mounting
- Metal construction
- Positive pull action with break rod
- Terminal or wire lead connections
- Open circuit type
- ULC listed

Ordering Information

Cat.No.	Description
270-SPOW	English markings - wire leads
270-SPOWF	French markings - wire leads
270-SPOWB	Bilingual markings - wire leads
270-SPO	English markings - terminal block
270-SPOF	French markings - terminal block
270-SPOB	Bilingual French/English markings - terminal block

Accessories	
27193-11	Surface box - red
27165P	Replacement break rods 1 dozen per package

Fire Alarm Stations

270 SPO Series



270-SPOB
270-SPOWB



270-SPO
270-SPOW

