




Overview

Neat appearance, concealed plunger, grounded frame. Attractive gray finish. Ideal for OEM applications. Standard bell operates on 6Vdc or 8VAC and is ideally suited for AC powered systems with battery standby. Mounts on 3-3/4" (95mm) bolt circle.

Dimensions	
A	B
3 (76)	1-7/8 (47)

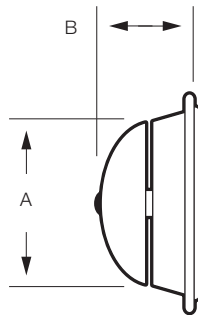

Monitor Bell

Model 156

Ordering Information

Cat. No.	Size	DC Volts	Amps	VA	DC Coil Res.(Ohms)	dB at 10'(3M)
156G-3AM	3 (76)	6Vdc	.6	3.6	2.7	72
		8VAC	.6	4.8	2.7	
156G-3G1	3 (76)	24Vdc	.15	3.6	36	
156G-3G5		24VAC	.3	7.5	16	



Overview

Compact, strap-mounted bell/buzzer designed for flush mounting in a standard single gang box. Easy to mount. Neat, low-cost installation. Eliminates need for heavy-duty transformers.

Applications

Residential and commercial door signals; interoffice or secretary call signal.

Standard Features



- Flush mounting
- Low voltage

Ordering Information

Cat. No.	Description	Volts AC	Amps	VA	DC Coil Res. (Ohms)	dB @ 3' (.9M)
762	Bell/Buzzer	24	.25	6	55	85

Strap Mounted Bell/Buzzer

Model 762

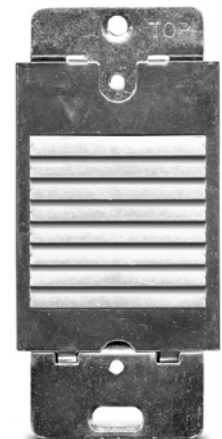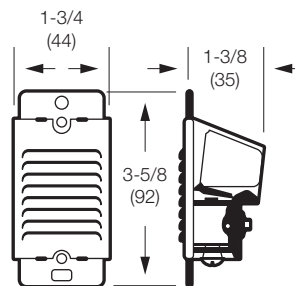

A
B
C
D
E
F
G