

## **Type 1 Mild Steel Metering Cabinets** *CMC Series*

Hinge Door with Quarter Turn



### **Application**

- Designed for indoor housing of metering transformers.

### **Standards**

- CSA Type 1
- Complies with
  - IEC 60529, IP20


### **Construction**

- Formed and spot welded from 14 or 16 gauge steel.
- Spot welded construction and formed edges.
- Removable inner panel.
- Hinged covers.
- 2 cutouts in top of each cabinet with metering plates included.


### **Finish**

- Enclosure and cover are finished in ANSI 61 gray inside and out.
- Inner panel is finished in white powder coating

## Single Door

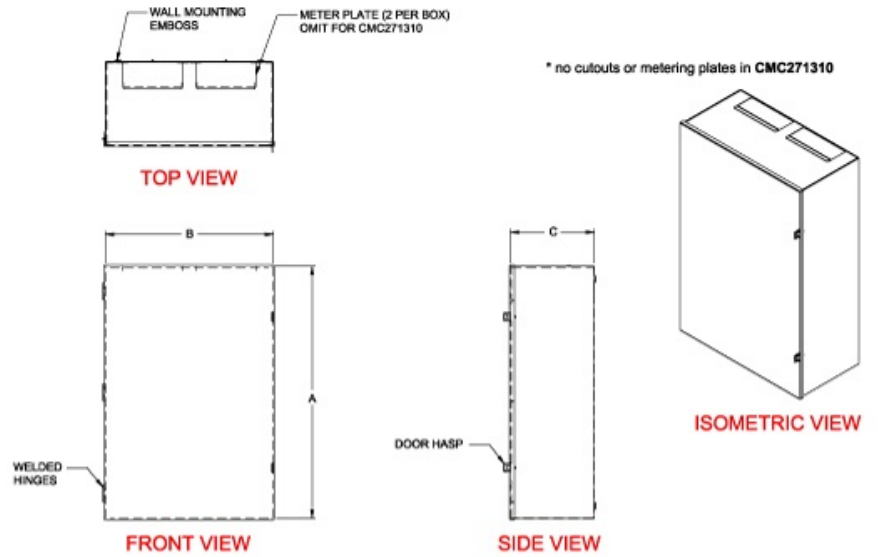

## Double Door

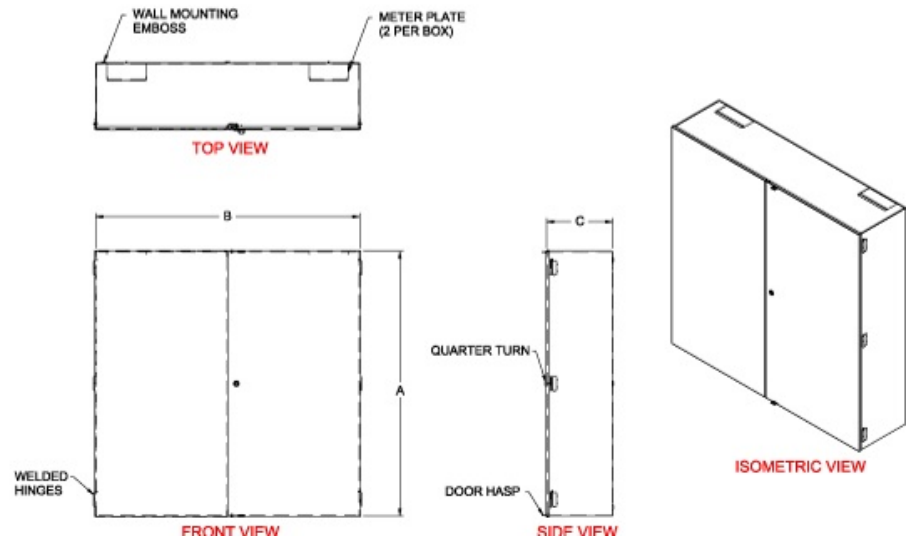

Part No.	Dimensions			Panel Dimensions	Type of Door	Latch Type	Qty	Ship Latch Plates	Metering Wt. lbs.
	A	B	C						
CMC202010	20.00	20.00	10.00	16 x 16	Single	Hasp	2	2	42
CMC271310*	27.00	13.00	10.00	23 x 9	Single	Hasp	2	0	38
CMC302010	30.00	20.00	10.00	26 x 16	Single	Hasp	2	2	69
CMC303010	30.00	30.00	10.00	26 x 26	Double	2 Hasp + Quarter Turn	3	2	92
CMC363612	36.00	36.00	12.00	32 x 32	Double	2 Hasp + Quarter Turn	3	2	131
CMC484812	48.00	48.00	12.00	44 x 44	Double	2 Hasp + Quarter Turn	3	2	210

\* No cutouts in top or metering plates

Data subject to change without notice.

