

Modular Equipment Cabinet System *C2 Series*



Features

- Constructed in:
 - 14-gauge steel (body)
 - 16-gauge steel (doors and side panels)
- EIA-310-D compliant 10-32 tapped or square hole punched rails with permanent rack unit labels.
- Overall width of 23.00" (584 mm) maintains a standard 19.00" panel width.
- Panel rails are NOT included.


Specifications

- Infinite-depth setting using C-channel struts.
- Zinc-plated mounting rails provide superior surface areas for equipment grounding.
- Four (4) leveling feet are included with support for optional casters.
- Grounding studs provided on frame as well as side panels and doors.
- Tested to nearly double the suggested load rating of 1,500 lbs.
- RoHS Compliant.
- Manufactured in North America.



[Short on time? Click here to see our Pre-Assembled C2RR Cabinet Series](#)

Gallery

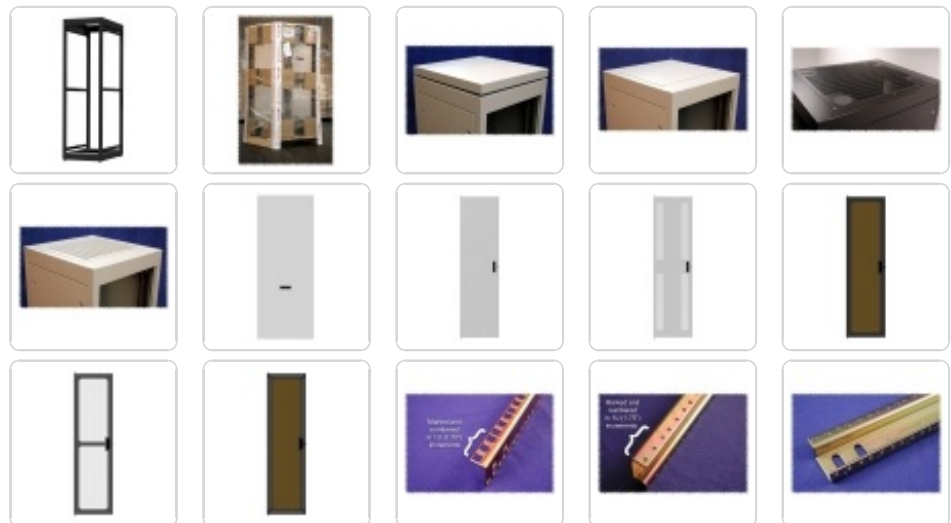



Accessories

- | | |
|---|---|
| Cabinet Fan Tops | • Vertical Cabinet Cable Manager |
| Two Post Mounting Cantilever Shelf | • Four Post Fixed Depth Shelf |
| Four Post Mounting Zero Space Fixed Shelf | • Four Post Mounting Adjustable Depth Shelf |
| Four Post Mounting Storage Drawer | • Four Post Mounting Sliding Shelf |
| Four Post Mounting Keyboard Drawer | • Rack Unit Label |
| Horizontal Lacing Bar | • Horizontal Steel Ring Cable Manager |
| Horizontal Hinged Cable Manager | • Horizontal Steel Finger Cable Manager |
| Horizontal Hinged Cable Guide | • Vertical Cable Tray |
| Outlet Strips | • Mounting Hardware |
| Rack Panels | • Grounding |
| Caster Set | • C2/C3 Bolt Down Kit |
| Cabinet Baying/Ganging/Joining Kit | |

C2 Frames

Part No. Black	Part No. Beige	Part No. Light Gray	Overall Dimensions			Usable Mounting Dimensions		
			Height A	Width B	Depth C	Rack Units	Height H	Depth
C2F193523BK1	C2F193523CG1	C2F193523LG1	42.31	23.00	23.63	20U	35.06	21.63
C2F194223BK1	C2F194223CG1	C2F194223LG1	49.31	23.00	23.63	24U	42.06	21.63
C2F194923BK1	C2F194923CG1	C2F194923LG1	56.31	23.00	23.63	28U	49.06	21.63
C2F195623BK1	C2F195623CG1	C2F195623LG1	63.31	23.00	23.63	32U	56.06	21.63
C2F196323BK1	C2F196323CG1	C2F196323LG1	70.31	23.00	23.63	36U	63.06	21.63
C2F197023BK1	C2F197023CG1	C2F197023LG1	77.31	23.00	23.63	40U	70.06	21.63
C2F197823BK1	C2F197823CG1	C2F197823LG1	86.06	23.00	23.63	45U	78.81	21.63
C2F198523BK1	C2F198523CG1	C2F198523LG1	93.06	23.00	23.63	49U	85.81	21.63
C2F193531BK1	C2F193531CG1	C2F193531LG1	42.31	23.00	31.50	20U	35.06	29.50
C2F194231BK1	C2F194231CG1	C2F194231LG1	49.31	23.00	31.50	24U	42.06	29.50
C2F194931BK1	C2F194931CG1	C2F194931LG1	56.31	23.00	31.50	28U	49.06	29.50
C2F195631BK1	C2F195631CG1	C2F195631LG1	63.31	23.00	31.50	32U	56.06	29.50
C2F196331BK1	C2F196331CG1	C2F196331LG1	70.31	23.00	31.50	36U	63.06	29.50
C2F197031BK1	C2F197031CG1	C2F197031LG1	77.31	23.00	31.50	40U	70.06	29.50
C2F197831BK1	C2F197831CG1	C2F197831LG1	86.06	23.00	31.50	45U	78.81	29.50
C2F198531BK1	C2F198531CG1	C2F198531LG1	93.06	23.00	31.50	49U	85.81	29.50
C2F193536BK1	C2F193536CG1	C2F193536LG1	42.31	23.00	36.00	20U	35.06	34.00
C2F194236BK1	C2F194236CG1	C2F194236LG1	49.31	23.00	36.00	24U	42.06	34.00
C2F194936BK1	C2F194936CG1	C2F194936LG1	56.31	23.00	36.00	28U	49.06	34.00
C2F195636BK1	C2F195636CG1	C2F195636LG1	63.31	23.00	36.00	32U	56.06	34.00
C2F196336BK1	C2F196336CG1	C2F196336LG1	70.31	23.00	36.00	36U	63.06	34.00
C2F197036BK1	C2F197036CG1	C2F197036LG1	77.31	23.00	36.00	40U	70.06	34.00
C2F197836BK1	C2F197836CG1	C2F197836LG1	86.06	23.00	36.00	45U	78.81	34.00
C2F198536BK1	C2F198536CG1	C2F198536LG1	93.06	23.00	36.00	49U	85.81	34.00

*Note: "CG1" (Beige color) is being phased out from stock - replaced with "LG1" a light gray (RAL7035)

C2 Mounting Rails

Part No. Tapped 10-32 Comination Rail	Part No. Square Hole L-Panel Rail	Mounting Dimensions	
		Rack Units	Height
CCR22TZPL	Not Available	13U	22.75
CCR35TZPL	CPR35SZPL	20U	35.00
CCR42TZPL	CPR42SZPL	24U	42.00
CCR49TZPL	CPR49SZPL	28U	49.00
CCR56TZPL	CPR56SZPL	32U	56.00
CCR63TZPL	CPR63SZPL	36U	63.00
CCR70TZPL	CPR70SZPL	40U	70.00
CCR77TZPL	CPR77SZPL	44U	77.00
CCR78TZPL	CPR78SZPL	45U	78.75
CCR85TZPL	CPR85SZPL	49U	85.75

C2 Doors

Door Type	Part No. Black	Part No. Beige*	Part No. Light Gray	Use with Cabinet		Shipping Weight
				Rack Units	Height	
Solid	CDF1935SBK1	CDF1935SCG1	CDF1935SLG1	20U	35.00	24
	CDF1942SBK1	CDF1942SCG1	CDF1942SLG1	24U	42.00	28
	CDF1949SBK1	CDF1949SCG1	CDF1949SLG1	28U	49.00	33
	CDF1956SBK1	CDF1956SCG1	CDF1956SLG1	32U	56.00	40
	CDF1963SBK1	CDF1963SCG1	CDF1963SLG1	36U	63.00	45
	CDF1970SBK1	CDF1970SCG1	CDF1970SLG1	40U	70.00	51
	CDF1978SBK1	CDF1978SCG1	CDF1978SLG1	45U	78.75	57
	CDF1985SBK1	CDF1985SCG1	CDF1985SLG1	49U	85.75	63
Louvered Door	CDF1935LBK1	CDF1935LCG1	CDF1935LLG1	20U	35.00	24
	CDF1942LBK1	CDF1942LCG1	CDF1942LLG1	24U	42.00	28
	CDF1949LBK1	CDF1949LCG1	CDF1949LLG1	28U	49.00	33
	CDF1956LBK1	CDF1956LCG1	CDF1956LLG1	32U	56.00	40
	CDF1963LBK1	CDF1963LCG1	CDF1963LLG1	36U	63.00	45
	CDF1970LBK1	CDF1970LCG1	CDF1970LLG1	40U	70.00	51
	CDF1978LBK1	CDF1978LCG1	CDF1978LLG1	45U	78.75	57
	CDF1985LBK1	CDF1985LCG1	CDF1985LLG1	49U	85.75	63
Perforated Door	CDF1970VBK1	CDF1970VCG1	CDF1970VLG1	40U	70.00	50
	CDF1978VBK1	CDF1978VCG1	CDF1978VLG1	45U	78.75	55
Acrylic Door	C2DF1935PBK1	Not Available	Not Available	20U	35.00	11
	C2DF1942PBK1	Not Available	Not Available	24U	42.00	17
	C2DF1949PBK1	Not Available	Not Available	28U	49.00	19
	C2DF1956PBK1	Not Available	Not Available	32U	56.00	24
	C2DF1963PBK1	Not Available	Not Available	36U	63.00	27
	C2DF1970PBK1	Not Available	Not Available	40U	70.00	30
	C2DF1978PBK1	Not Available	Not Available	45U	78.75	34
	C2DF1985PBK1	Not Available	Not Available	49U	85.75	38
Vented Acrylic Door	CDF1970VPBK1	CDF1970VPCG1	CDF1970VPLG1	40U	70.00	30
	CDF1978VPBK1	CDF1978VPCG1	CDF1978VPLG1	45U	78.75	34

*Note: "CG1" (Beige color) is being phased out from stock - replaced with "LG1" a light gray (RAL7035)

C2 Side Panels

Part No.	Part No.	Part No.	Use with Cabinet Frame	Weight
----------	----------	----------	------------------------	--------

Black	Beige*	Light Gray	Rack Units	Height	Depth	Part No.	(Per Pair)
CSP3523BK1	CSP3523CG1	CSP3523LG1	20U	35.00	23.63	C2F193523	30
CSP4223BK1	CSP4223CG1	CSP4223LG1	24U	42.00	23.63	C2F194223	38
CSP4923BK1	CSP4923CG1	CSP4923LG1	28U	49.00	23.63	C2F194923	46
CSP5623BK1	CSP5623CG1	CSP5623LG1	32U	56.00	23.63	C2F195623	54
CSP6323BK1	CSP6323CG1	CSP6323LG1	36U	63.00	23.63	C2F196323	65
CSP7023BK1	CSP7023CG1	CSP7023LG1	40U	70.00	23.63	C2F197023	70
CSP7823BK1	CSP7823CG1	CSP7823LG1	45U	78.75	23.63	C2F197823	85
CSP8523BK1	CSP8523CG1	CSP8523LG1	49U	85.75	23.63	C2F198523	90
CSP3531BK1	CSP3531CG1	CSP3531LG1	20U	35.00	31.50	C2F193531	36
CSP4231BK1	CSP4231CG1	CSP4231LG1	24U	42.00	31.50	C2F194231	44
CSP4931BK1	CSP4931CG1	CSP4931LG1	28U	49.00	31.50	C2F194931	52
CSP5631BK1	CSP5631CG1	CSP5631LG1	32U	56.00	31.50	C2F195631	68
CSP6331BK1	CSP6331CG1	CSP6331LG1	36U	63.00	31.50	C2F196331	78
CSP7031BK1	CSP7031CG1	CSP7031LG1	40U	70.00	31.50	C2F197031	90
CSP7831BK1	CSP7831CG1	CSP7831LG1	45U	78.75	31.50	C2F197831	102
CSP8531BK1	CSP8531CG1	CSP8531LG1	49U	85.75	31.50	C2F198531	108
CSP3536BK1	CSP3536CG1	CSP3536LG1	20U	35.00	36.00	C2F193536	41
CSP4236BK1	CSP4236CG1	CSP4236LG1	24U	42.00	36.00	C2F194236	49
CSP4936BK1	CSP4936CG1	CSP4936LG1	28U	49.00	36.00	C2F194936	57
CSP5636BK1	CSP5636CG1	CSP5636LG1	32U	56.00	36.00	C2F195636	78
CSP6336BK1	CSP6336CG1	CSP6336LG1	36U	63.00	36.00	C2F196336	88
CSP7036BK1	CSP7036CG1	CSP7036LG1	40U	70.00	36.00	C2F197036	100
CSP7836BK1	CSP7836CG1	CSP7836LG1	45U	78.75	36.00	C2F197836	110
CSP8536BK1	CSP8536CG1	CSP8536LG1	49U	85.75	36.00	C2F198536	132

*Note: "CG1" (Beige color) is being phased out from stock - replaced with "LG1" a light gray (RAL7035)

C2 Top Panels

Top Panel Type	Part No. Black	Part No. Beige*	Part No. Light Gray	Use with Cabinet Depth
Solid Top	C2T1923SBK1	C2T1923SCG1	C2T1923SLG1	23.63
	C2T1931SBK1	C2T1931SCG1	C2T1931SLG1	31.50
	C2T1936SBK1	C2T1936SCG1	C2T1936SLG1	36.00
Vented Top	C2T1923VBK1	C2T1923VCG1	C2T1923VLG1	23.63
	C2T1931VBK1	C2T1931VCG1	C2T1931VLG1	31.50
	C2T1936VBK1	C2T1936VCG1	C2T1936VLG1	36.00
Vented Top With 3x 3.5" Cable Entry Holes	C2T1923VCEBK1	C2T1923VCECG1	C2T1923VCELG1	23.63
	C2T1931VCEBK1	C2T1931VCECG1	C2T1931VCELG1	31.50
	C2T1936VCEBK1	C2T1936VCECG1	C2T1936VCELG1	36.00
Raised Top	C2T1923RBK1	C2T1923RCG1	C2T1923RLG1	23.63
	C2T1931RBK1	C2T1931RCG1	C2T1931RLG1	31.50
	C2T1936RBK1	C2T1936RCG1	C2T1936RLG1	36.00

*Note: "CG1" (Beige color) is being phased out from stock - replaced with "LG1" a light gray (RAL7035)

C2 Bottom Panels

Bottom Panel Type	Part No. Black	Part No. Beige*	Part No. Light Gray	Use with Cabinet Depth
Solid Bottom	C2BPS1923BK1	C2BPS1923CG1	C2BPS1923LG1	23.63
	C2BPS1931BK1	C2BPS1931CG1	C2BPS1931LG1	31.50

	C2BPS1931BK1	C2BPS1931CG1	C2BPS1931LG1	36.00
	C2BPCE1923BK1	C2BPCE1923CG1	C2BPCE1923LG1	23.63
Micro Cell	C2BPCE1931BK1	C2BPCE1931CG1	C2BPCE1931LG1	31.50
	C2BPCE1931BK1	C2BPCE1931CG1	C2BPCE1931LG1	36.00

*Note: "CG1" (Beige color) is being phased out from stock - replaced with "LG1" a light gray (RAL7035)

Data subject to change without notice.

© 2013. Hammond Manufacturing Ltd. All rights reserved.