


Four Post Fixed Depth Shelf *RF Series*

Features

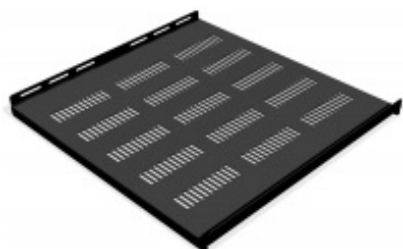

- Attach to the sides of both pair of rack combination rails.
- Requires no front rail mounting.
- Front & rear lip folded for extra strength.
- Versatile design can be used upside down (front & rear lip become equipment retainers).
- Heavy duty 14 gauge steel construction.
- Sides folded up for easy hardware installation from above.
- Sides are slotted for easy adjustment with most rail depth locations.
- Rugged textured powder paint finish.
- Tested to nearly double the suggested load rating of 350 lbs.
- RoHS Compliant.
- Manufactured in North America.
- Includes all mounting hardware.
- If used with our [CPR square hole rails](#) you will need to order [CPRSA rail adaptor](#) for each shelf ordered.
- MOUNTS ON TWO PAIR OF COMBINATION RAILS (FRONT & BACK).

Solid Shelves

Part No. Black	Part No. Beige*	Shelf Depth
RFUS1918BK1	RFUS1918CG1	18.00
RFUS1921BK1	RFUS1921CG1	21.00
RFUS1926BK1	RFUS1926CG1	26.00
RFUS1931BK1	RFUS1931CG1	31.00

*Note: "CG2" (Beige color) is being phased out from stock - replaced with "LG2" a light gray (RAL7035)

Vented Shelves

Part No. Black	Part No. Beige*	Shelf Depth
RFVS1918BK1	RFVS1918CG1	18.00
RFVS1921BK1	RFVS1921CG1	21.00
RFVS1926BK1	RFVS1926CG1	26.00
RFVS1931BK1	RFVS1931CG1	31.00

*Note: "CG2" (Beige color) is being phased out from stock - replaced with "LG2" a light gray (RAL7035)

Data subject to change without notice.

