

Reference Data	
Efficiency	88.4%
Spacing Ratio	1.5
Electronic Ballast	
Input Watts (120V)	62.0W
Ballast Factor	.88

Application Data*			
Luminaire Spacing	FC	W/Sq Ft	
<i>50' x 70' x 12' Space</i>			
12' on centre	78	1.2	
<i>50' x 70' x 8.5' Space</i>			
10' on centre	100	1.3	
<i>50' x 70' x 8.5' Space</i>			
12' on centre	86	1.2	
<i>30' x 30' x 8.5' Space</i>			
12' on centre	84	1.4	

Ordering Guide T5					
Type	Lum. Lgth. Nominal	Lamps in Width	Lamp Qty/Type	Lamp Length	Catalogue Number
Solid Top Reflector	48"	1	1-T5	48"	EE128
	48"	2	2-T5	48"	EE228
	96"	1	2-T5	96"	EE128T
	96"	2	4-T5	96"	EE228T
	48"	3	3-T5	48"	EE328
10% Uplight Reflector	96"	3	6-T5	96"	EE328T
	48"	1	1-T5	48"	FF128
	48"	2	2-T5	48"	FF228
	96"	1	2-T5	96"	FF128T
	96"	2	4-T5	96"	FF228T
	48"	3	3-T5	48"	FF328
	96"	3	6-T5	96"	FF328T

Ordering Guide T8 and T12HO					
Type	Lum. Lgth. Nominal	Lamps in Width	Lamp Qty/Type	Lamp Length	Catalogue Number
Solid Top Reflector	48"	1	1-T8	48"	EE148
	48"	2	2-T8	48"	EE248
	96"	1	2-T8	96"	EE148T
	96"	2	4-T8	96"	EE248T
	48"	3	3-T8	48"	EE348
	96"	3	6-T8	96"	EE348T
	48"	2	2-T12HO	48"	EE248H
	96"	1	1-SL	96"	EE196S
	96"	2	2-SL	96"	EE296S
	10% Uplight Reflector	48"	1	1-T8	48"
48"		2	2-T8	48"	FF248
96"		1	2-T8	96"	FF148T
96"		2	4-T8	96"	FF248T
48"		3	3-T8	48"	FF348
96"		3	6-T8	96"	FF348T
48"		2	2-T12HO	48"	FF248H
96"		1	1-T12HO	96"	FF196H
96"		2	2-T12HO	96"	FF296H
96"		1	1-SL	96"	FF196S
96"	2	2-SL	96"	FF296S	

SL: Slimline


FF248	UNV	HI	
Basic Catalogue Number: Open Industrial	Voltage: 120: 120V 277: 277V UNV: 120-277V 347: 347V	Ballast: See p. 192	Options: See p. 192 Add appropriate suffix to catalogue number

Reference Data	
Efficiency	89.2%
Spacing Ratio	1.3
Electronic Ballast	
Input Watts (120V)	62.0W
Ballast Factor	.88


Application Data*			
Luminaire Spacing	FC	W/Sq Ft	
<i>50' x 70' x 12' Space</i>			
16' on centre	60	0.9	
<i>50' x 70' x 12' Space</i>			
12' on centre	76	1.2	
<i>50' x 70' x 8.5' Space</i>			
10' on centre	97	1.3	
<i>30' x 30' x 8.5' Space</i>			
12' on centre	83	1.4	

Ordering Guide					
Type	Lum. Lgth. Nominal	Lamps in Width	Lamp Qty/Type	Lamp Length	Catalogue Number
15% Uplight Flat Reflector	48"	2	2-T5	46"	TU228
	96"	2	4-T5	46"	TU228T
	48"	2	2-T8	48"	TU248
	96"	2	4-T8	48"	TU248T
	48"	3	3-T8	48"	TU348
	96"	3	6-T8	48"	TU348T
	48"	4	4-T8	48"	TU448
	48"	2	2-T5HO	46"	TU254
	96"	2	4-T5HO	46"	TU254T
	48"	3	2-T5	46"	TU328
	48"	3	2-T5HO	46"	TU354
	48"	4	2-T5	46"	TU428
	48"	4	2-T5HO	46"	TU454
	48"	2	2-T12HO	48"	TU248H
	96"	2	2-T12HO	48"	TU296H

TU248	UNV	HI	
Basic Catalogue Number: Premium Turret Industrial	Voltage: 120: 120V 277: 277V UNV: 120-277V 347: 347V	Ballast: See p. 192	Options: See p. 192 Add appropriate suffix to catalogue number

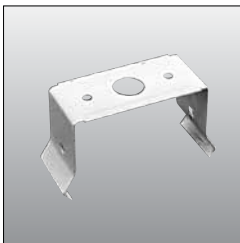

Heavy Duty Slide-Grip Hanger **EE9H3**.

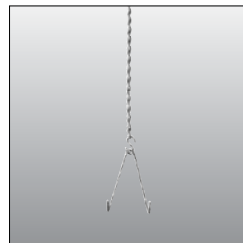

Chain Hanger Kit **EE9HC**.
Two 24" heavy duty link chain.

*Average Footcandles Maintained. Total LLF=BF (1.0) x .85 = .85 Reflectance: 80% Ceiling, 50% Wall, 20% Floor RE835 lamp rated at 3000 lumens.