


Aluminum Pathlyte (CPL12) Specification Sheet

Project Name:	Location:	MFG: Philips Hadco
Fixture Type:	Catalog No.:	Qty:

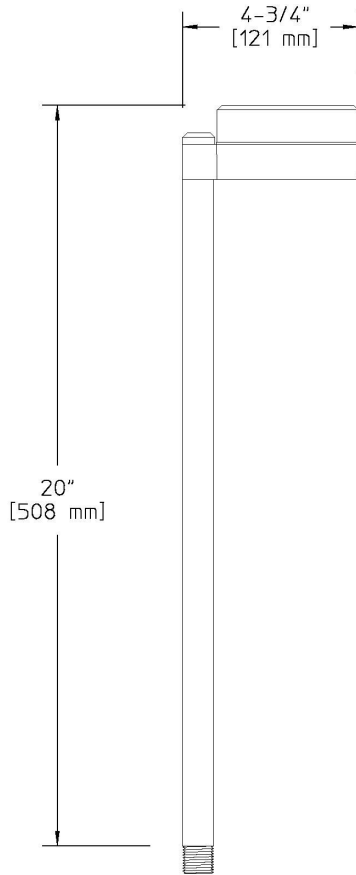

Ordering Guide

Example: CPL12 A S7

Product Code	CPL12	Aluminum Pathlyte
Finish	A H	Black Bronze
Mounting	S7	Mounting Stake *1

*1 Mounting stake is optional.

Spacing Chart

Recommended Spacing - CPL12 - 10'
Horizontal footcandles

Volt/Lamp	1'	2'	3'	4'	5'	6'	7'	8'	9'
12V, 20W T3	12.5	4.89	3.58	1.90	.27	.15	.07	-	-

Specifications

HOUSING:

Die-cast aluminum with twist-lock top for tool-less relamping. Stem is extruded aluminum. Single-piece molded silicone gasket to prevent water, dust, and insect filtration. 1/2" NPS male threads to screw onto accessory mounting stake or junction box, sold separately.

FINISH:

Thermoset polyester powdercoat is electrostatically applied after a five-stage conversion cleaning process and bonded by heat fusion thermosetting. Laboratory tested for superior weatherability and fade resistance in accordance with ASTM B117 specifications.

OPTICAL ASSEMBLY:

Clear tempered glass lens. Reflector is made of stamped, multi-faceted aluminum.

LAMPING:

20W maximum T3 bi-pin lamp. Lamp is included with fixture. Lower wattage lamps are acceptable.

ELECTRICAL ASSEMBLY:

Bi-pin socket type (G4) with 250° C high temperature teflon coated wire leads. 12 Volt fixture is pre-wired with 3-ft pigtail of 18-2 AWG, 105° C, SPT-1W wire. Low voltage quick connector, catalog #LVC3 included for easy hook-up to the low voltage supply cable, not included. 12 Volt system requires remote transformer, not included.

WARRANTY:

Three-year limited warranty.

CERTIFICATIONS:

ETL listed to U.S. safety standards for wet locations. cETL listed to Canadian safety standards for wet locations. Manufactured to ISO 9001:2008 Standards.

Height :

Aluminum Pathlyte (CPL12) Specification Sheet

Project Name:

Location:

MFG: Philips Hadco

Fixture Type:

Catalog No.:

Qty:

20" (508mm)

Width:

4 3/4" (121mm)

Max. Weight:

2.04 lb.