


# MSL18 Specification Sheet

Project Name:	Location:	MFG: Philips Hadco
Fixture Type:	Catalog No.:	Qty:

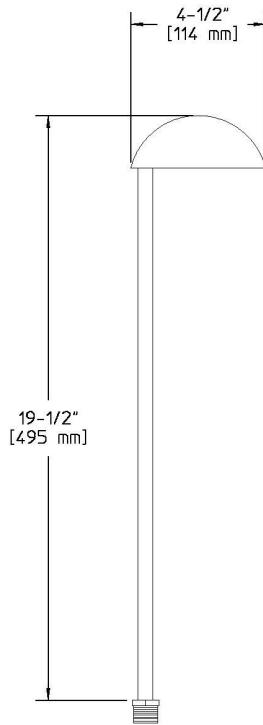

## Ordering Guide

Example: MSL18 A S7

<b>Product Code</b>	MSL18		
<b>Finish</b>	A	Black	
	H	Bronze	
	G	Verde	
<b>Mounting</b>	S7	Mounting Stake	*1

\*1 Mounting stake is optional.

## Specifications

### HOUSING:

Die-cast aluminum. Hidden fasteners and aluminum stem. Fasteners are 300 series stainless steel. 1/2" NPS male threads to screw onto accessory mounting stake or junction box, sold separately.

### FINISH:

Thermoset polyester powdercoat is electrostatically applied after a five-stage conversion cleaning process and bonded by heat fusion thermosetting. Laboratory tested for superior weatherability and fade resistance in accordance with ASTM B117 specifications.

### LAMPING:

27W maximum S-8 (1156) lamp. Lamp is included with fixture. Lower wattage lamps are acceptable.

### ELECTRICAL ASSEMBLY:

Single contact bayonet (S-8). 12 Volt fixture is pre-wired with 3-ft pigtail of 18-2 AWG, 105° C, SPT-1W wire. Low voltage quick connector, catalog #LVC3 included for easy hook-up to the low voltage supply cable, not included. 12 Volt system requires remote transformer, not included.

### WARRANTY:

Three-year limited warranty.

### CERTIFICATIONS:

ETL Listed to U.S. safety standards for wet locations. cETL listed to Canadian safety standards for wet locations. Manufactured to ISO 9001:2008 Standards.

### Height :

19 1/2" (495mm)

### Width:

4 1/2" (114mm)

### Max. Weight:

1.5 lb.