




**6 3/4" Aperture
Deep Alzak Reflector
(Enclosed Reflector Lamp)**

**Lytecaster
Recessed Downlight
H.I.D.**

1145H

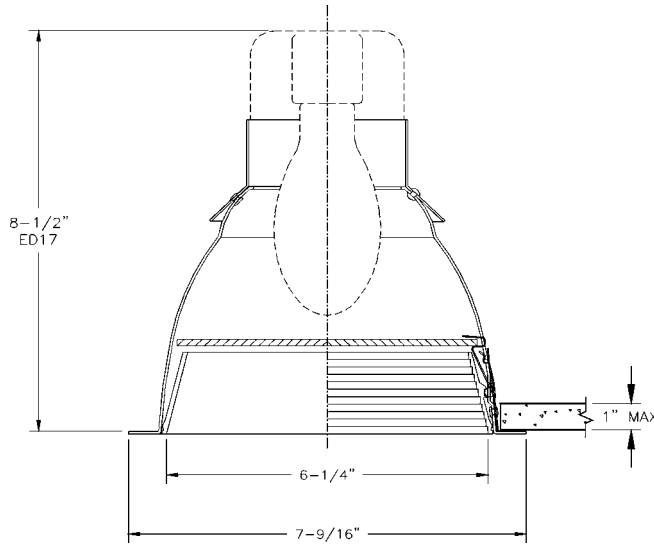

Ceiling Opening : 6 3/4"

Complete fixture consists of Reflector Trim & Frame-in Kit. Select each separately

REFLECTOR TRIM		MH FRAME-IN-KIT		LAMP
1145HCL	Specular Clear Alzak	1102H10H3Y	120/277/347V	100W ED17 MH
1145HBK	Black Step Baffle	1102H70H3Y	120/277/347V	70W ED17 MH

Y = Standard pulse rated socket for enclosed reflector lamp or PAR lamps

Features

Reflector : Hydroformed aluminum, .050" thick ; 38° shielding angle; specular clear finish; Treated to be UV resistant and non-fading. White trim flange.

Step Baffle : Die-cast aluminum with stepped conical surface for low brightness, black finish.

Cone : Hydroformed aluminum, .080" thick. Specular Alzak finish. Treated to be UV resistant and non-fading.

Lamp Guard : High heat resistant clear glass (as required by lamp manufacturer)

Frame-In-Kit

Note : For complete **Frame-In-Kit** specifications, see sheet **1102H**

Accessories

Extra Wide Flange Trim Ring : 1954 ; For most 1100 series Reflector Trim. O.D. 8 5/8".

Labels : CSA

Suitable for damp locations.

WE RESERVE THE RIGHT TO CHANGE DETAILS OF DESIGN, MATERIALS AND FINISH, IN ANY WAY THAT WILL NOT ALTER INSTALLED APPEARANCE OR REDUCE FUNCTION AND PERFORMANCE.

