

Gimbal ES/ESD16 ☆



WH




Black



Brushed Steel

Pivoting Gimbal ring houses ES/ESD16 lamps close to the opening. Features front relamping. The lamp adjusts 20° vertically and 360° horizontally. For mounting plates for use with remodelers see p. 546. Accommodates all ceiling types from 1/8" to 1-1/8" thick. For thicker ceilings see extra thick ceiling housing accessories on p. 547

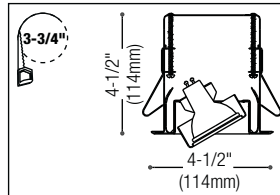


- 330BKX** Black
- 330STX** Brushed Steel
- 330WHX** White

Note: Frame-in Kit not applicable for MR16 lamp.

INCANDESCENT		
NON-IC	IC	IC/AIRSEAL®
302ESX 50W ES/ESD16 (GU10)	302ESICX 50W ES/ESD16 (GU10)	302ESAICX 50W ES/ESD16 (GU10)
REMODELER		
300ESX 50W ES/ESD16 (GU10)		

Adjustable Pinhole ☆☆☆

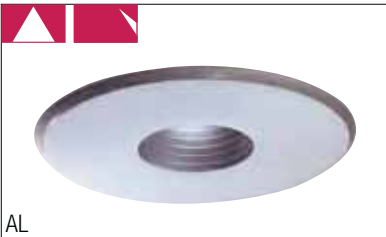

AL




Black Faceplate and Baffle



White Faceplate and Baffle

Tiny aperture accent light. Easy relamping and aiming permits up to 30° vertical and 360° horizontal adjustments. For mounting plates for use with remodelers see p. 546. Accommodates all ceiling types from 1/8" to 1-1/8" thick. For thicker ceilings see extra thick ceiling housing accessories on p. 547

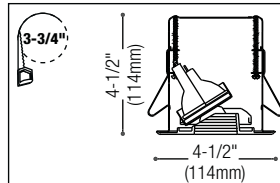

- 308ALX** Aluminum Painted Faceplate and Baffle
- 308BKX** Black Faceplate and Baffle
- 308WWX** White Faceplate and Baffle

Note: Frame-in Kits not applicable: 303MRE, 302MRIC7SPX, 302ESAICX.

INCANDESCENT		
NON-IC	IC	IC/AIRSEAL®
302MRSPX 302MREX 302MRLX 50W MR16 37W MR16 IR	302MRIC9SPX 50W MR16 37W MR16 IR 302ESICX 50W ES/ESD16 (GU10)	302MRAICSPX 302MRAICEX 37W MR16 IR
REMODELER		
300MRSPX 50W MR16 37W MR16 IR 3401MREX 42W MR16 300ESX 50W ES/ESD16 (GU10)		

HID
NON-IC
302MH20MRE1 20W MR16 (GX10) CMH 302MH39MRE1 39W MR16 (GX10) CMH
REMODELER
3401MH20MRE1 20W MR16 (GX10) CMH 3401MH39MRE1 39W MR16 (GX10) CMH