

Adjustable Premium Die-Cast Step Baffle ☆☆☆



BKK




Aluminum Painted Step Baffle and Self-Flange



White Step Baffle and Self-Flange

One-colour luminaire features a one-piece die-cast flange and step baffle (except 305BKK). Recessed lamp rotates 360° horizontally and 35° vertically, can be aimed without removing trim. For mounting plates for use with remodelers see p. 546. Accommodates all ceiling types from 1/8" to 1-1/8" thick. For thicker ceilings see extra thick ceiling housing accessories on p. 547.

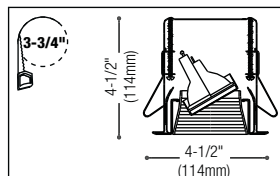


- 305BKK** Black Step Baffle and White Flange
- 305ALPX** Aluminum Painted Step Baffle and Self-Flange
- 305WHWX** White Step Baffle and Self-Flange

Note: Frame-in Kit not applicable: 303MRE.


INCANDESCENT		
NON-IC	IC	IC/AIRSEAL®
302MRSPX	302MRC7SPX	302MRAICSPX
302MREX	302MRC9SPX	302MRAICEX
302MRLX		
50W MR16	50W MR16	50W MR16
37W MR16 IR	37W MR16 IR	37W MR16 IR
	302ESICX	302ESAICX
302ESX	50W ES/ESD16 (GU10)	50W ES/ESD16 (GU10)
50W ES/ESD16 (GU10)		
REMODELER		
300MRSPX		
3401MREX		
50W MR16		
37W MR16 IR		
300ESX		
50W ES/ESD16 (GU10)		

HID
NON-IC
302MH20MRE1
20W MR16 (GX10) CMH
302MH39MRE1
39W MR16 (GX10) CMH
REMODELER
3401MH20MRE1
20W MR16 (GX10) CMH
3401MH39MRE1
39W MR16 (GX10) CMH

Nelio Premium Die-Cast Baffle Adjustable ☆☆☆

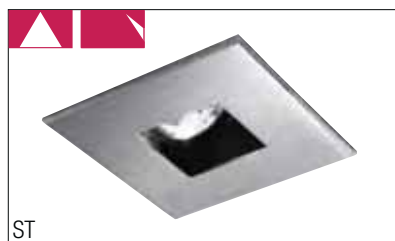

ST

 


Chrome



White

The lamp is slightly off-centre which enables a 0-35° vertical adjustability (locking device included). It also provides a 358° horizontal rotation capability which is adjustable from below with a screwdriver. The aperture is only 1-7/8" x 1-7/8" (48mm x 48mm) and the faceplate is made of die-cast aluminum 1/8" (3.2mm) thick. The truncated die-cast baffle features a black painted finish for low brightness. For mounting plates for use with remodelers; see p. 546. Accommodates all ceiling types from 1/8" to 1-1/8" thick. For thicker ceilings see extra thick ceiling housing accessories on p. 547.

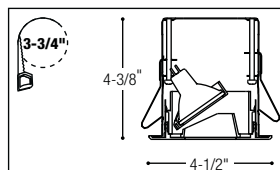

- 344ASTX** Brushed Steel
- 344ACMX** Chrome
- 344AWHX** White

Note: Frame-in Kit not applicable: 303MRE, 302MRC7SPX and ES16 Frame-in Kits.

INCANDESCENT		
NON-IC	IC	IC/AIRSEAL®
302MRSPX	302MRC9SPX	302MRAICSPX
302MREX	50W MR16	302MRAICEX
302MRLX	37W MR16 IR	37W MR16 IR
50W MR16		
37W MR16 IR		
REMODELER		
300MRSPX		
3401MREX		
37W MR16 IR		

HID
NON-IC
302MH20MRE1
20W MR16 (GX10) CMH
302MH39MRE1
39W MR16 (GX10) CMH
REMODELER
3401MH20MRE1
20W MR16 (GX10) CMH
3401MH39MRE1
39W MR16 (GX10) CMH