




Nelio Open Adjustable ☆☆☆

The lamp is slightly off-centre which enables a 0-35° vertical adjustability or it can be locked in a downlight position with the lamp centered (locking device included). It also provides a 358° horizontal rotation capability which is adjustable from below with a screwdriver. The aperture is only 1-7/8" x 1-7/8" (48mm x 48mm) and the faceplate is made of die-cast aluminum 1/8" (3.2mm) thick. For mounting plates for use with remodelers; see p. 546. Accommodates all ceiling types from 1/8" to 1-1/8" thick. For thicker ceilings see extra thick ceiling housing accessories on p.547.

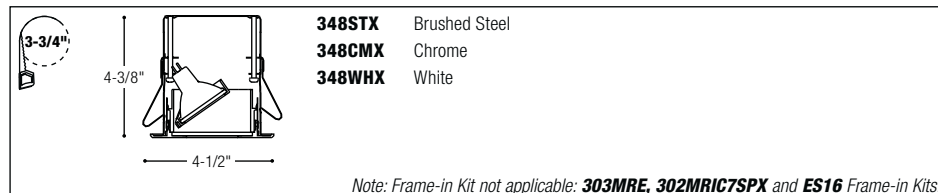


INCANDESCENT		
NON-IC	IC	IC/AIRSEAL®
302MRSPX 302MREX 302MRLX 50W MR16 37W MR16 IR	302MRIC9SPX 50W MR16 37W MR16 IR	302MRAICSPX 302MRAICEX 37W MR16 IR
REMODELER		
300MRSPX 3401MREX 37W MR16 IR		

HID	
NON-IC	
302MH20MRE1 20W MR16 (GX10) CMH	
302MH39MRE1 39W MR16 (GX10) CMH	
REMODELER	
3401MH20MRE1 20W MR16 (GX10) CMH	
3401MH39MRE1 39W MR16 (GX10) CMH	

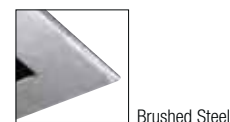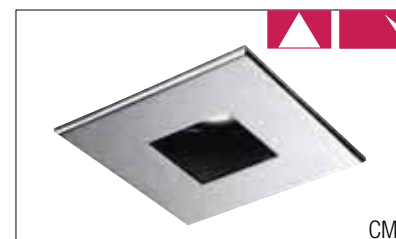**Residence** ☆☆☆

Lamp sits flush with the ceiling. Adjustable up to 30° for accent lighting to a vertical surface and 360° horizontally. The industry leader, offering the easiest and fastest installation with rear lamping and patented spring clips. For mounting plates for use with remodelers see p. 546. Accommodates all ceiling types from 1/8" to 1-1/8" thick. For thicker ceilings see extra thick ceiling housing accessories on p. 547

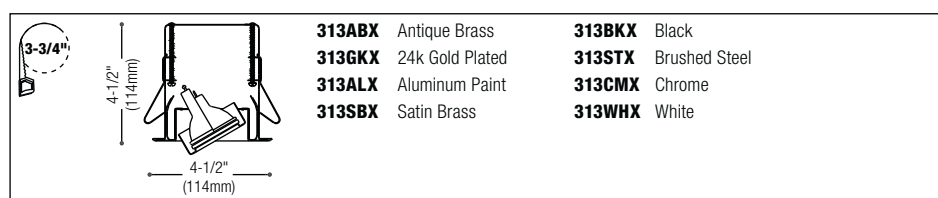

INCANDESCENT		
NON-IC	IC	IC/AIRSEAL®
302MRSPX 302MREX 302MRLX 50W MR16 37W MR16 IR	302MRIC7SPX 302MRIC9SPX 50W MR16 37W MR16 IR	302MRAICSPX 302MRAICEX 50W MR16 37W MR16 IR
302ESX 50W ES/ESD16 (GU10)	302ESICX 50W ES/ESD16 (GU10)	302ESAICX 50W ES/ESD16 (GU10)
REMODELER		
300MRSPX 3401MREX 50W MR16 37W MR16 IR		
303MRE 37W MR16 IR		
300ESX 50W ES/ESD16 (GU10)		

HID	
NON-IC	
302MH20MRE1 20W MR16 (GX10) CMH	
302MH39MRE1 39W MR16 (GX10) CMH	
REMODELER	
3401MH20MRE1 20W MR16 (GX10) CMH	
3401MH39MRE1 39W MR16 (GX10) CMH	



Antique Brass



Black



24k Gold Plated



Brushed Steel



Aluminum Paint



Chrome



Satin Brass