

Elbow ☆☆



ST




White



Black

Versatile accent light utilizing miniature low voltage MR16 lamps. Elbow adjusts up to 70° vertically and 360° horizontally for focal lighting. Retracts to provide fully recessed downlight. Certified for wall mounting applications with 303 MRE using a 37W MR16 IR lamp. For mounting plates for use with remodelers see p. 547. Accommodates all ceiling types from 1/8" to 1-1/8" thick. For thicker ceilings see extra thick ceiling housing accessories on p. 547. For metal snoot see p. 546.

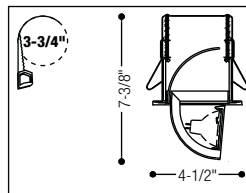

- 378BKX** Black
- 378STX** Brushed Steel
- 378WHX** White

Note: Frame-in Kit not applicable: **302ESX, 300ESX, 302ESICX, 302ESAICX.**
 *Also suitable for wall mount applications (37W MR16 IR).

INCANDESCENT		
NON-IC	IC	IC/AIRSEAL®
302MRSPX 302MREX 302MRLX 50W MR16 37W MR16 IR	302MRIC7SPX 302MRIC9SPX 37W MR16 IR	302MRAICSPX 302MRAICEX 50W MR16 37W MR16 IR
REMODELER		
300MRSPX 3401MREX 50W MR16 37W MR16 IR		
303MRE* 37W MR16IR		

Round Elbow ☆☆



BK




Brushed Steel Finish



White

Versatile accent light utilizing miniature low voltage MR16 lamps. Elbow adjusts up to 70° vertically and 358° horizontally for accent lighting. Retracts to provide fully recessed downlight. Certified for wall mounting applications with 303 MRE using a 37W MR16 IR lamp. For mounting plates for use with remodelers see p. 546. Accommodates all ceiling types from 1/8" to 1-1/8" thick. For thicker ceilings see extra thick ceiling housing accessories on p. 547. For metal snoot see p. 546.

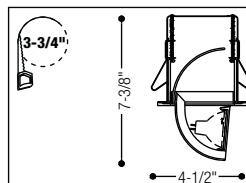

- 379BKX** Black
- 379STX** Brushed Steel
- 379WHX** White

Note: Frame-in Kit not applicable: **302ESX, 300ESX, 302ESICX, 302ESAICX.**
 *Also suitable for wall mount applications (37W MR16 IR).

INCANDESCENT		
NON-IC	IC	IC/AIRSEAL®
302MRSPX 302MREX 302MRLX 50W MR16 37W MR16 IR	302MRIC7SPX 302MRIC9SPX 37W MR16 IR	302MRAICSPX 302MRAICEX 50W MR16 37W MR16 IR
REMODELER		
300MRSPX 3401MREX 50W MR16 37W MR16 IR		
303MRE* 37W MR16 IR		