

DuraMax Deco Globe

DuraMax Deco 100W Med 120V G40 WH 1CT



Philips DuraMax® Long Life Deco Globe Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. DuraMax deco globe bulbs are available in a wide assortment of shapes, sizes and wattages. Clear globes add decorative sparkle, white globes emit soft white light and half-chrome provides decorative sparkle and reduced glare.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	G40
Bulb Finish	White
Filament Shape	C-9 [Pendant]
Operating Position	Universal [Any or Universal (U)]
Main Application	Decorative
Atmosphere	Gas

• Light Technical Characteristics

Initial lumen	985 Lm
---------------	--------

• Electrical Characteristics

Watts	100 W
Voltage	120 V

• Product Dimensions

Max Overall Length (MOL) - C	6.938 (max) in
Diameter D	5.028 in


• Product Data

Product number	168534
Full product name	DuraMax Deco 100W Med 120V G40 WH 1CT
Short product name	DuraMax Deco 100W Med 120V G40 WH 1CT
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677168537
Bar code on case	50046677168532
Logistics code(s)	925179036304
eop_net_weight_pp	0.001 kg


PHILIPS

sense and simplicity

Dimensional drawing

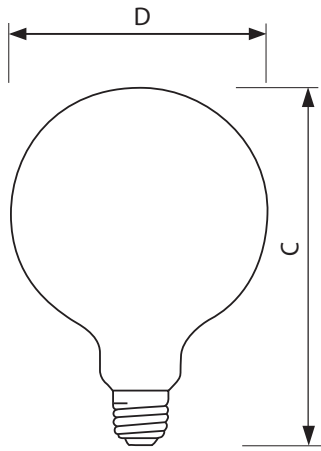

DuraMax Deco 100W Med 120V G40 WH 1CT

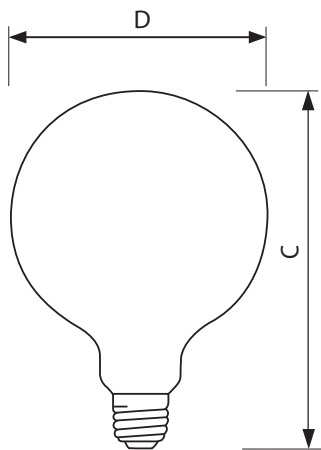

DuraMax Deco 100W Med 120V G40 WH 1CT



E26



© 2013 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2013, May 13
data subject to change