



MR16

50W GU5.3 MR16 1BC

Philips Halogen MR16 lamps provide a bright white light for accent lighting. They make it easy to optimize the look and feel of your brand, your merchandise, and the shoppers experience, with lower operating costs.

Product data

• General Characteristics

Philips Code	14600
ANSI Code Halogen	EXN
Base	GU5.3
Bulb	MR16 [MR 16inch/50mm]
Operating Position	Universal [Any or Universal (U)]
RatedAvgLife(See Family Notes)	2000 hr

• Electrical Characteristics

Energy Used	50 W
Lamp Wattage Technical	50 W
Voltage	12 V
Dimmable	Yes

• Light Technical Characteristics

Beam Angle	36 D
Beam Angle Technical	36 D
Approx. MBCP	1200 (max) cd
Color Rendering Index	100 Ra8
Color Temperature	3000 K
Color Temperature technical	3000 K

• Product Dimensions

Overall Length C	51.5 (max) mm
Diameter D	50.7 (max) mm



• Luminaire Design Requirements

Cap-Base Temperature	350 (max) C
----------------------	-------------

• Product Data

Order code	924049717188
Full product code	924049717188
Full product name	50W GU5.3 MR16 1BC
Order product name	BC50MRC16/FL/EXN
Pieces per pack	1
Packing configuration	6
Packs per outerbox	6
Bar code on pack - EAN1	46677162498
Bar code on outerbox - EAN3	50046677162493
Logistic code(s) - 12NC	924049717188
ILCOS code	HRGI-50-12-GU5.3-50/36
Net weight per piece	0.032 kg

Dimensional drawing

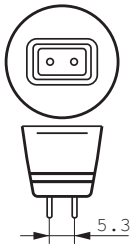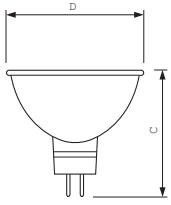

Product	C (Max)	D (Max)
FIGHTER 14600 50W GU5.3 12V MR16 36D	51.5	50.7



© 2011 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2011, August 25
data subject to change