
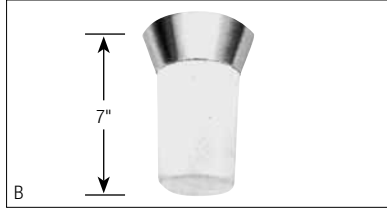


Guards

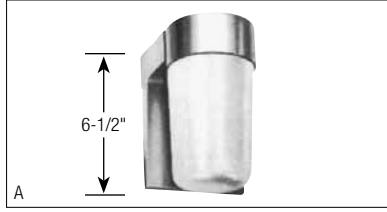

Catalogue No.	Ref.No.	Max. Watts	Globe Type	Shape	Replacement Globe Cat. No.
P60781	A	60	Lexan	Cylinder	APRC5
P61181	A	100	Glass	Cylinder	AGA0100


- Wall Brackets: cylindrical globe and 4 1/2" x 6" mounting plates fit over 3" - 4" recessed outlet boxes (lamp not included)
- CSA approved

Catalogue No.	Ref.No.	Max. Watts	Globe Type	Shape	Replacement Globe Cat. No.
P60783	B	60	Lexan	Cylinder	APRC5
P61183	B	100	Glass	Cylinder	AGA0100

- Surface Brackets: cylindrical globe with a tapered housing fits over all 3" - 4" recessed outlet boxes (lamp not included)
- CSA approved

Ground Mounting Accessories

Rocket Perma-Post®

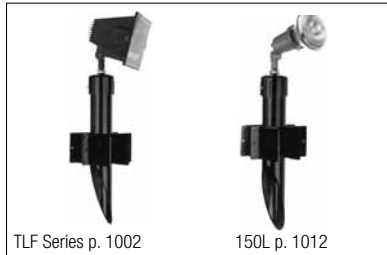

Catalogue No.	Description	Colour
RPP30B	3" O.D.x 30"	Black

- Heavy wall, black impact resistant PVC construction
- Threaded 1/2" NPT hub with ground wire
- Slanted bottom accepts conduits of different depths
- PVC stabilizers included (no concrete required)
- Ideal for mounting landscape products as well as incandescent, quartz, and low wattage HID floods
- CSA approved

Groundmount Combination Examples

Mix and match to suit your requirements. Order separate catalogue numbers by referring to appropriate page number.

4" Square Buriable Box



Catalogue No.	Body Holes	Bottom Holes	Cover Holes	Plugs	Tap Size
SJ2	0	2	1	0	1/2"

- Cast iron and hot dipped galvanized
- Complete with 1/8" rubber gasket and cast cover with 1/2" NPT hole and stainless hardware
- Base equipped with 2-1/2" NPT access holes in bottom
- CSA approved