

4" Round Vapourtight Boxes

Catalogue No.	Tap Size	Description	Catalogue No.	Thread Size	Description
VXL1	1/2"	Vapourtight base	12	1/2"	Plug
VXL13	3/4"	Vapourtight base	13	3/4"	Plug

- Die-cast aluminum for use with conduit, Stonco vapourtight ceiling, surface and wall fixtures
- Four side and one back hole tapped 3/4" or 1/2", as shown
- Heavy-duty gaskets, screws, three machined aluminum five-thread plugs. No cover
- Close up plugs are aluminum with fine machined tapered threads
- CSA approved



Coloured & Specialty Globes

3-1/2" Dia. Glass Globe (100W Max.)

Catalogue No.	Description	Catalogue No.	Description
VGC100	Clear	VGC200	Clear
VGCH100	Clear, heat tempered	VGCH200	Clear, heat tempered
VGP100	Clear, prismatic	VGP200	Clear, prismatic
VGA100	Amber 60W max.	VGA200	Amber 75W max.
VGB100	Blue 60W max.	VGB200	Blue 75W max.
VGG100	Green 60W max.	VGG200	Green 75W max.
VGR100	Ruby 60W max.	VGR200	Ruby 75W max.




3-1/2" Dia. Lexan Globe (60W Max.)

Catalogue No.	Description	Catalogue No.	Description
VPRC5	Clear Prismatic	VPRC10	Clear Prismatic

- Full molded threads. Fits all Stonco vapourtight housings
- Lexan globes for vertical mounting only
- CSA approved

4-3/8" Dia. Lexan Gloe (75W Max.)


Globe

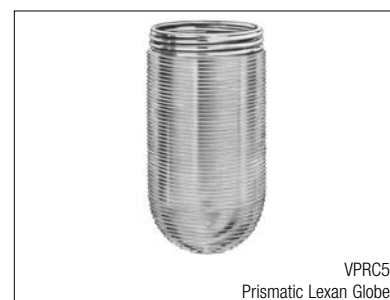

Catalogue No.	Fits Globe Diameter
VT131	3-1/2"
VT132	4-3/8"

- Cast aluminum guards screw-on type
- CSA approved

Guards

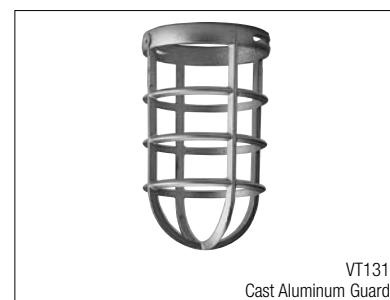

*Vapourtight fixtures not suitable for hazardous locations. Lamps not included.