


- Up to 200 watts incandescent (lamp not included)
- **Construction:** Vapourtight, fully enclosed and gasketed. Rugged design for locations exposed to moisture, corrosive fumes, non-explosive vapours or non-combustible dusts. All exposed metal parts are weatherproof, corrosion resistant surface hardened and die-cast aluminum

- **Lamp Socket:** Glazed porcelain prewired socket, enclosed with screw on heat resistant clear glass globe
- CSA Approved
- **Warranty:** 1-Year
- Mounting to be globe down only


4" Box-Mounted Fixtures

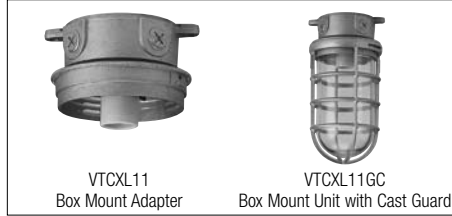

Cat. No.	Max. Watts	Description	Height	Dia.
VTCXL11	100W	Surface unit only. Order globe separately	3"	3-3/4"
VTCXL21	200W	Surface unit only, Order globe separately	3-1/4"	4-1/4"
VTCXL11K	100W	With clear glass globe	8-3/4"	4-3/16"
VTCXL21K	200W	With clear glass globe	10-3/4"	4-3/4"
VTCXL11GC	100W	With clear glass globe, cast guard	9-1/8"	4-3/8"
VTCXL21GC	200W	With clear glass globe, cast guard	10-7/8"	5- 3/8"

- Complete with vapourtight die-cast aluminum box. Four side and one top hole tapped 1/2" NPT
- Three plugs included
- For 3/4" conduit, use VTK series with VXL-13 universal box


Surface Fixtures for Round and Octagon Boxes

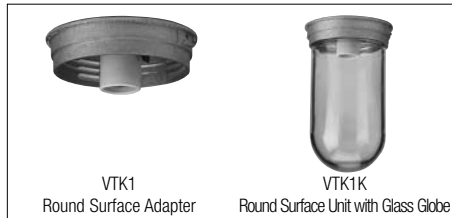

Cat. No.	Max. Watts	Description	Height	Dia.
VTK1	100W	Surface unit only. Order globe separately	1-1/8"	3-3/4"
VTK2	200W	Surface unit only. Order globe separately	1-1/8"	4-1/4"
VTK1K	100W	With clear glass globe	7-1/4"	4-3/16"
VTK2K	200W	With clear glass globe	8-3/4"	4-3/4"
VTK1GC	100W	With clear glass globe, cast guard	7-13/16"	4-3/8"
VTK2GC	200W	With clear glass globe, cast guard	9-9/16"	5-3/8"

- Boxes not included. 100W fixtures fit all 3-1/2" round and octagon boxes and all 4" round boxes

4" Box-Mounted Wall Brackets

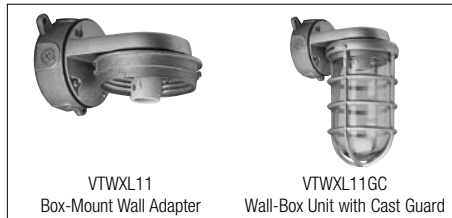

Cat. No.	Max. Watts	Description	Height	Dia.
VTWXL11	100W	Wall unit only. Order globe separately	4"	6-3/8"
VTWXL21	200W	Wall unit only. Order globe separately	4"	7-5/8"
VTWXL11K	100W	With clear glass globe	9-1/4"	6-15/16"
VTWXL21K	200W	With clear glass globe	10-7/8"	7-7/16"
VTWXL11GC	100W	With clear glass globe, cast guard	9-5/16"	7-7/16"
VTWXL21GC	200W	With clear glass globe, cast guard	11-3/8"	7-3/4"

- Four side and one back hole tapped 1/2" NPT
- Three plugs included. For 3/4" conduit, use VTW series with 3/4" VXL 13 universal box


Wall Brackets for Standard Boxes



Cat. No.	Max. Watts	Description	Height	Dia.
VTW1	100W	Wall unit only. Order globe separately	4"	5-1/4"
VTW2	200W	Wall unit only. Order globe separately	4"	6-1/16"
VTW1K	100W	With clear glass globe	9-3/16"	5-1/4"
VTW2K	200W	With clear glass globe	10-3/16"	5-3/4"
VTW1GC	100W	With clear glass globe, cast guard	9-9/16"	5-3/4"
VTW2GC	200W	With clear glass globe, cast guard	11-5/16"	6-1/16"

- Boxes not included. Fit all 4" round or octagon boxes
- Use Series VXL 4" boxes to convert VTW fixtures to box-mounted VTWXL units

Pendant Fixtures (Stems not included.)

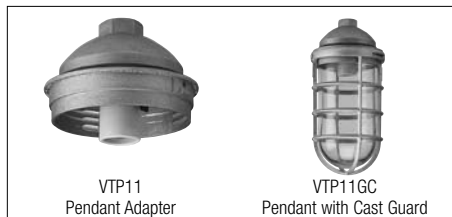

Cat. No.	Max. Watts	Description	Height	Dia.
VTP11	100W	Pendant unit only. Order globe separately	2-1/2"	3-3/4"
VTP21	200W	Pendant unit only. Order globe separately	2-1/2"	4-1/4"
VTP11K	100W	With clear glass globe	8-1/2"	3-3/4"
VTP21K	200W	With clear glass globe	10-1/2"	4-3/4"
VTP11GC	100W	With clear glass globe, cast guard	8-7/8"	4-3/8"
VTP21GC	200W	With clear glass globe, cast guard	10-7/8"	5-3/8"

- Top hub tapped 1/2" NPT

*Not suitable for hazardous locations.