




Adjustable Specular Cone ★★★



CL

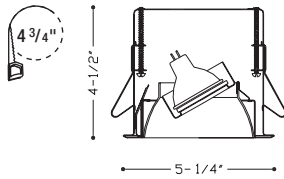

Fully adjustable accent light with Specular cone that offers non-glare optics for added visual comfort. Recessed lamp rotates 360° horizontally and 35° vertically, can be aimed without removing trim. Accommodates all ceiling types from 1/8" to 1" thick. Available low-maintenance Comfort Clear™ Diffuse finish prevents dust build-up and fingerprint marks; its special iridescent-free soft-glow surface is well-suited to point source MR16 lamps.

404BAX Specular Black Specular Cone and White Flange

404CCDX Clear Diffuse Cone and White Flange

404CLX Specular Clear Specular Cone and White Flange

404GD Specular Gold Specular cone and White Flange

| Non-IC Remodeler | | Non-IC Frame-In Kit | | | IC Frame-In Kit |
|------------------|----------|---------------------|----------|------------------------|-----------------|
| 400MRX | 3401MREX | 402MRX | 402MREX | Multi-Unit MR16 Series | 402MRIC9X |
| 75W MR16 | 50W MR16 | 75W MR16 | 75W MR16 | 75W MR16 | 50W MR16 |



GD



CCD




BA



Adjustable Premium Die-Cast Step Baffle ★★★



BK

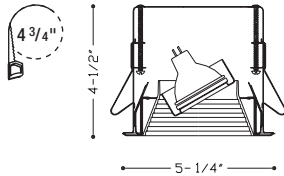


Fully adjustable premium accent step baffle features regressed lamp for maximum glare control. Recessed lamp rotates 360° horizontally and 35° vertically, can be aimed without removing trims. Accommodates all ceiling types from 1/8" to 1" thick.

405BKX Black Step Baffle and White Flange

405WHX White Step Baffle and White Flange

| Non-IC Remodeler | | Non-IC Frame-In Kit | | | IC Frame-In Kit |
|------------------|----------|---------------------|----------|------------------------|-----------------|
| 400MRX | 3401MREX | 402MRX | 402MREX | Multi-Unit MR16 Series | 402MRIC9X |
| 75W MR16 | 50W MR16 | 75W MR16 | 75W MR16 | 75W MR16 | 50W MR16 |

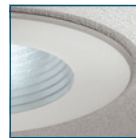


WH



Eyeball ★★★



WH

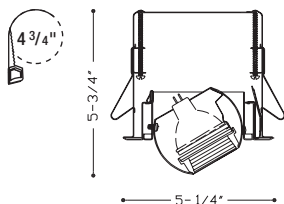

Elegant mini-eyeball for accent lighting, rotates 360° horizontally and adjusts 45° vertically. One-piece housing with black or white premium step baffle. Eyeball faceplate snaps out for easy relamping. Accommodates all ceiling types from 1/8" to 1" thick.

406WHX White Eyeball and Black Step Baffle

406WWX White Eyeball and White Step Baffle

| Non-IC Remodeler | | Non-IC Frame-In Kit | | | IC Frame-In Kit |
|------------------|----------|---------------------|----------|------------------------|-----------------|
| 400MRX | 3401MREX | 402MRX | 402MREX | Multi-Unit MR16 Series | 402MRIC9X |
| 75W MR16 | 50W MR16 | 75W MR16 | 75W MR16 | 75W MR16 | 50W MR16 |



WW