

Complete fixture consists of Reflector Trim & Remodeler. Select each separately.

Remodeler	Lamp	Reflector Trim
501X	50W PAR20	Accepts all 4-1/4" (108mm), 500X Series trims: See Reflector Trim specification sheets.

### Features

**Remodeler:** Ideal for remodeling. Integral junction box with snap-off covers permits wiring from below. US pattern 665.9627

**Socket:** Porcelain medium base; nickel plated screw shell. Pre-wired with 18ga. SEW leads connected to junction box.

**Thermal Protector:** Meets CSA/UL requirements. Insulation, if used, must be kept 3" (76mm) away from mounting frame sides and junction box.

### Accessories



**0092L:** Long mounting plate 500X series, for 12" (305mm) and 16" (406mm) center to center wood joist.

**0092S:** Short mounting plate 500X series, 6-1/2" (165mm) wide x 7-1/4" (184mm) long.

### Marking

cCSAus Certified, suitable for damp or wet locations depending on trim used.

Job Information	Type:
Job Name:	
Cat. No.:	
Lamp(s):	
Notes:	

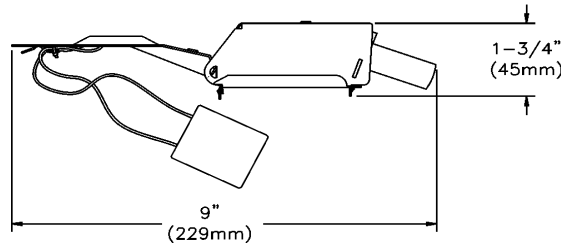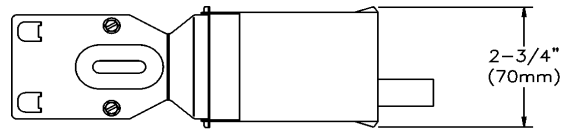

1

Le luminaire complet comprend la Garniture du Réflecteur et Bloc d'alimentation : choisir chacun séparément.

Bloc d'alimentation	Lampe	Garniture du réflecteur
501X	50W PAR20	Accepte les garnitures 4-1/4 po (108mm) de la série 500X : voir les fiches technique appropriées.

### Caractéristiques

**Bloc d'alimentation** : idéal pour la rénovation. Boîte de raccordement intégré avec couvercles enclenchables permettant de brancher le filage par en dessous. Brevet US 665.9627

**Douille** : base medium de porcelaine; intérieur fileté nickelé. Pre-filé avec fil de calibre 18 SEW branché à la boîte de raccordement.

**Protection thermique** : rencontre les exigences de la CSA/UL. L'isolant, si utilisé, doit être à un minimum de 3 po (76mm) de chaque côté du cadre de montage et de la boîte de raccordement.

### Accessoires

**0092L** : Plaque de montage longue série 500X, pour poutrelles de 12 po (305mm) et 16 po (406mm) centre à centre.

**0092S** : Plaque de montage courte serie 500X, 6-1/2" (165mm) large x 7-1/4". (184mm)

### Marquage

Certifié cCSAus convient pour les endroits humides ou mouillés selon la garniture employée.

Job Information	Type:
Job Name:	
Cat. No.:	
Lamp(s):	
Notes:	