



Fixed Canopy Kit

4-1/2" diameter. Includes crossbar.


- 55100AL** Aluminum
- 55100WH** White
- 55100BK** Black



Canopy Kit For Sloped Ceilings

Installs over standard outlet box. Adjusts from 0° to 90°. For sloped or cathedral ceiling applications. Includes 4-1/2" diameter canopy, swivel and crossbar.

- 55101WH** White
- 55101BK** Black

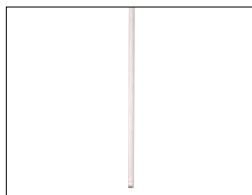

Stem Mounting Kits

For suspending track. Complete kits are made up of two catalogue numbers: one for the stem and the other for the canopy (#55100 or #55101). Use 2 stems for a 4-foot track, three stems for an 8-foot or 12-foot track. For continuous runs, use one stem every 4'. Stems attach to track at any point. Can be field cut to the desired length must be re-threaded (1/8 - 27 1.P.T.). 72" Extension Stem is used to extend stem length. Stem diameter: 1/2".

- 18" Stem
- 55102AL** Aluminum
- 55102WH** White
- 55102BK** Black

- 72" Stem
- 55105AL** Aluminum
- 55105WH** White
- 55105BK** Black

- 36" Stem
- 55103AL** Aluminum
- 55103WH** White
- 55103BK** Black

- 72" Extension Stem
- 55106AL** Aluminum
- 55106WH** White
- 55106BK** Black


- 48" Stem
- 55104AL** Aluminum
- 55104WH** White
- 55104BK** Black



Sloped Ceiling Adapter

Installs on Monopoint, Multipoint or track. Adjusts from 0° to 90°. For sloped or cathedral ceiling applications. Can be used alone or with Suspension Stems. For compatible Lytespots, please refer to p.626-635 of the Canlyte Resource Guide.

- 6079WH** White
- 6079BK** Black

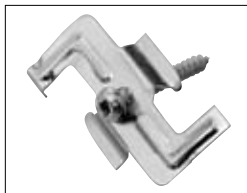

Twist-Lock Flush Clips

Set of 6. For Fast Track or Advent.

- 55066** Zinc plated



T-Bar Clips

Set of 6. For grid ceilings. For Fast Track or Advent.

- 55041** Zinc plated



Suspension Stems

For suspending Lytespots on Fast Track or Advent Tracks. Stem diameter: 1/2". For compatible Lytespots, please refer to p.626-635 of the Canlyte Resource Guide.

- 6074WH** 18" White
- 6074BK** 18" Black
- 6075WH** 36" White
- 6075BK** 36" Black
- 6076WH** 48" White
- 6076BK** 48" Black

Note: Not field cuttable



Surface Clips

Set of 6. For installation on uneven ceilings. For Fast Track or Advent.

- 55065WH** White
- 55065BK** Black



Pendant Adapter

Supports cord-mounted luminaires (5 lbs. max.) and stem or chain luminaires (25 lbs. max.). Loop (female thread 1/4" - 18 NPS) and chain not included.

- 7589** White
- 7589BK** Black




Convenience Outlet

Provides auxiliary source for plug-in equipment. Capacity of 6 amps.


- 6085** White

Invisible Floating Feed

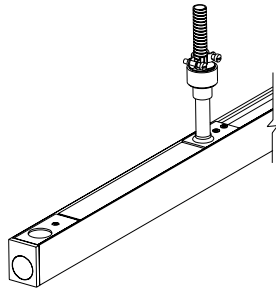

26082


End Feed J Box & Floating Canopy Kit

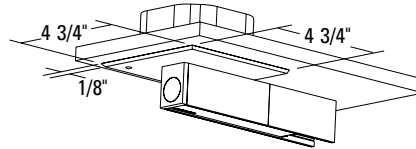

Mounts to any feed connector or along track. Use with 1/16" mounting clip or direct track mount.

- 26060WH** White
- 26060BK** Black

End Feed J Box & Floating Canopy Kit for 3/8" Stand Off Clip

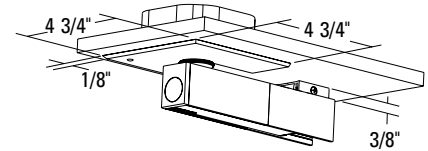


Mounts to any feed connector or along track. For use with 3/8" Stand-Off Mounting Clips.

- 26061WH** White
- 26061BK** Black


Grid Ceiling Canopy and J Box

Mounts to any feed connector or along track length 4' max. from feed connector.

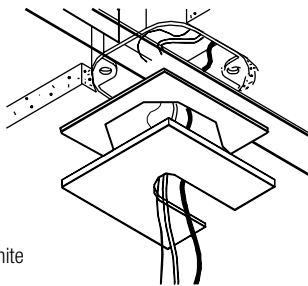

26096WH White

Lytespan to ProSpec Adapter

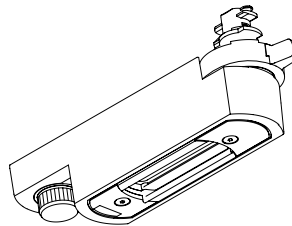

Allows most Lytespan fixtures to be mounted to ProSpec track.

- 120V Only**
- 26075WH** White
- 26075BK** Black


6-3/4" l x 1-9/16" w x 1-7/16" h



Canopy Kit For Sloped Ceilings

Installs over standard outlet box. Adjusts from 0° to 90°. For sloped or cathedral ceiling applications. Includes 4-1/2" diameter canopy, swivel and crossbar.

- 55101WH** White
- 55101BK** Black

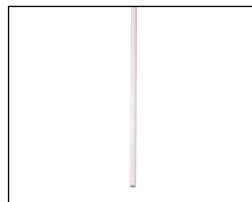

Stem Mounting Kits



 



For suspending track. Complete kits are made up of two catalogue numbers: one for the stem and the other for the canopy (#55100 or #55101). Use 2 stems for a 4-foot track, three stems for an 8-foot or 12-foot track. For continuous runs, use one stem every 4'. Stems attach to track at any point. Can be field cut to the desired length. Must be re-threaded on site. 72" Extension Stem is used to extend stem length and may not be field cut. Stem diameter: 1/2".

- 18" Stem
- 55102WH** White
- 55102BK** Black
- 55102AL** Aluminum
- 36" Stem
- 55103WH** White
- 55103BK** Black
- 55103AL** Aluminum

- 48" Stem
- 55104WH** White
- 55104BK** Black
- 55104AL** Aluminum
- 72" Stem
- 55105WH** White
- 55105BK** Black
- 55105AL** Aluminum

- 72" Extension Stem
- 55106WH** White
- 55106BK** Black
- 55106AL** Aluminum

Grid Ceiling Mounting Clips

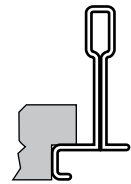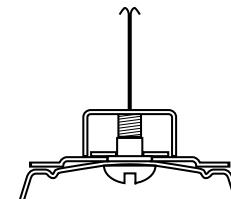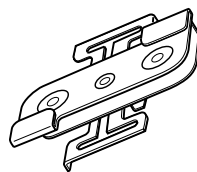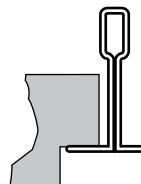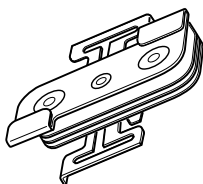

For Regressed-Edge Panels and 9/16" or 15/16" T-Bar runners.

Set of 9.
6087 White

Stems attach to the track at any point and may be spaced up to 4' apart. Stems cannot be attached directly to track connectors.

For Square-Edge Panels and 9/16" or 15/16" T-Bar runners.

Set of 9.
6089 White

Sloped ceiling stem provides 0°-90° adjustment for sloped ceilings.

For Regressed-Edge Panels and Slotted Grid runners in ceiling systems such as DONN®, FINELINE® and Ultraline® 3500.†

Set of 9.
6088 White

†DONN® and FINELINE® are registered trademarks of USG Interiors, Inc. Ultraline® 3500 is a registered trademark of Chicago Metallic Corporation.