



EnduraLED PAR30 Indoor Flood

12PAR30S/END/F22 2700 DIM 6/1

Philips EnduraLED PAR indoor reflectors with high brightness LEDs are suited for track and recessed lighting. Energy saving, long life LED PAR long and short lamps install into existing fixtures, lower costs with reduced wattage and reduce re-lamping frequency.

Product data

• General Characteristics

Cap-Base	-
Bulb	PAR30S [PAR30S mm]
Rated Avg. Life (Hours)	45000 hr

• Light Technical Characteristics

Color Code	WW
Color Designation	Warm White
Beam Angle	22 D
Beam Description	22D [Medium beam]
Correlated Color Temperature	2700 K
Approximate Lumens	665 Lm
Approx. MBCP	2900 cd
Color Temp. (Kelvin)	2810 K [CCT 2810K]

• Electrical Characteristics

Wattage	12 W
---------	------

Wattage Technical	12 W
Voltage	120 V
Dimmable	Yes


• Product Dimensions

Overall Length C [inch]	3.664 (max) in
-------------------------	----------------

• Product Data

Product number	410118
Full product name	12PAR30S/END/F22 2700 DIM 6/1
Short product name	12PAR30S/END/F22 2700 DIM 6/1
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677410117
Bar code on case	50046677410112
Logistics code(s)	929000175502
eop_net_weight_pp	0.300 kg

Dimensional drawing

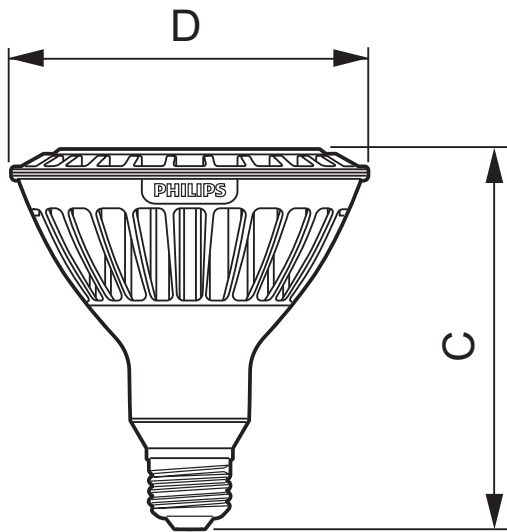

12W/17W PAR30S/PAR38 Dimmable

Product	C (Norm)	D (Norm)
LED 12W WW 2810K 120V PAR30S Dimmable	-	-

For product and purchase inquiries contact:

ecodirect

CLEAN ENERGY SOLUTIONS

www.ecodirect.com



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, February 1
data subject to change