



MR16 LED

7MR16/END/F24 3000 DIM10/1

Philips MR16 Dimmable LED Lamps provide ambient level light to illuminate hard to maintain applications. Increased transformer compatibility allows for operation on a wider range of transformers. Available in dimmable and non-dimmable versions, these lamps are ideal for track and open recessed fixtures in retail, hospitality and residential spaces.

Product data

• General Characteristics

Cap-Base	GU5.3
Bulb	MR16 [MR 16inch/50mm]
Rated Avg. Life (Hours)	40000 hr

• Light Technical Characteristics

Color Code	WH
Color Designation	White
Beam Angle	24 D
Beam Description	- [-]
Correlated Color Temperature	3000 K
Approx. MBCP	1550 cd
CRI	82
Color Temp. (Kelvin)	3000 K [CCT 3000K]
Rated Luminous Flux	380 Lm

• Electrical Characteristics

Wattage	7 W
Wattage Technical	7.0 W
Voltage	12 V

Line Frequency	50-60 Hz
Power Factor	0.8 -
Lamp Current mA	650 mA
Dimmable	Yes

• Product Dimensions

Overall Length C	53.7 mm
Overall Length C [inch]	2.116 (max) in
Diameter D	50 mm

• Product Data



Product number	414698
Full product name	7MR16/END/F24 3000 DIM10/1
Short product name	7MR16/END/F24 3000 DM10/1
Pieces per Sku	1
eop_pck_cfg	10
Skus/Case	10
Bar code on pack	46677414696
Bar code on case	50046677414691
Logistics code(s)	929000179102
eop_net_weight_pp	0.035 kg

Dimensional drawing



PHILIPS

Dimensional drawing

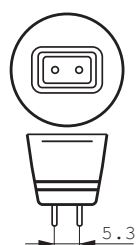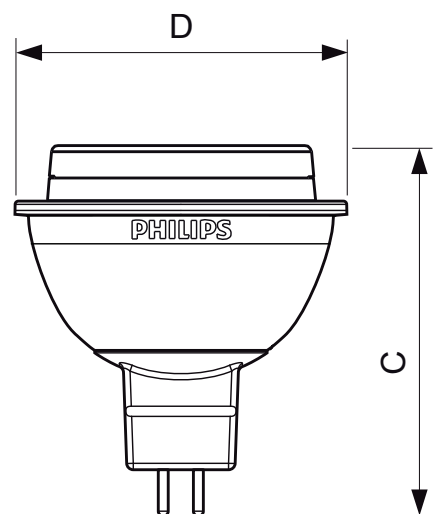

GU5.3

7MR16/END/F24 3000 DIM10/1

Product	C (Norm)	D (Norm)
LED 7W GU5.3 3000K 12V MR16 24D Dimm	53.7	50



© 2013 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2013, June 21
data subject to change