



11-23-34W Med ICT

Product family description

Looking for an energy saver that does not look like one? The Philips EnergySaver family provides energy efficient lighting options that don't just provide similar light as your standard incandescent light bulb, they also have the same classic shapes. Try the Philips EnergySavers and see how they truly provide advanced lighting designed around your needs.

Features

- Similar light output as standard incandescent lamps
- Compact size fits many small fixtures
- Instant on
- Long Life—Lasts up to 7 years*
- Terrific energy savings—uses up to 70% less energy than standard incandescent light bulbs, a real impact to your bottom line!
- Available in: 11/23/34 Watt version (equivalent 50/100/150)
- *Based on an average daily usage of 3-4 hours/day, 7 days/week

Benefits

- Philips Energy Saver 3-Way Twister provides energy savings and reduced operating costs without sacrificing quality of light compared to standard incandescent equivalents.
- Save 39/77/116 watts in your 3-way lamp when you replace a 50/100/150 w incandescent 3-way with Philips 11/23/34 W Energy Saver 3-Way twister.
- Energy savings and long life can impact your bottom line.

Application

- Ideal for table/floor lamps and reading lamps

Notes

- Approximate initial lumens—The lamp lumen output is based upon lamp performance after 100 hours of operating life under standard laboratory conditions

PHILIPS

- Average life under specified test conditions with lamps turned off and restarted no more frequently than once every 3 operating hours. Use in recessed cans or enclosed indoor fixtures could result in reduced lamp life.
- Warnings and Cautions - Do not use with dimmers. Some electronic timer and photo sensor switches contain dimming circuitry, so before using such a switch check with it's manufacturer to ensure compatability with electronic CFL bulbs. Do not use with emergency exit fixtures or lights. Outdoor use requires a weather-protected fixture. Turn off power before changing bulb. The device complies with Part 18 of the FCC rules.
- For base down operation only. Do not use in recessed cans or enclosed indoor fixtures as it could result in reduced lamp life.
- Reliable operating temperature range -22F/-30C to 140F/60C.
- This product may cause interference with radios,televisions, telephones or remote controls. If interference occurs, move this product away from device or plug into another outlet.

Product data	
Product Number	211938
Full product name	11-23-34W Med ICT
Ordering Code	211938
Pack type	1 Lamp in a Folding Carton
Pieces per Sku	1
Skus/Case	6
Pack UPC	046677211936
EAN2US	
Case Bar Code	50046677211931
Successor Product number	
Base	Medium [Single Contact Medium Screw]
Packing Type	ICT [1 Lamp in a Folding Carton]
Packing Configuration	6
Ordering Code	HELIX TWISTER EL/3W 11-23-34
Pack UPC	046677211936
Case Bar Code	50046677211931
Watts	11-34W [11-23-34]
Voltage	110-127V
Line Frequency	50/60Hz
Color Code	827 [CCT of 2700K]
Color Rendering Index	82 Ra8
Color Designation	Warm White
Color Description	827 Warm White
Color Temperature	2700 K
Initial Lumens	1500 Lm
Overall Length C	176.0 mm




Product data	
Diameter D	70.0 mm
Product Number	211938



Helix Twister 11-34W Medium/E27



Base Medium

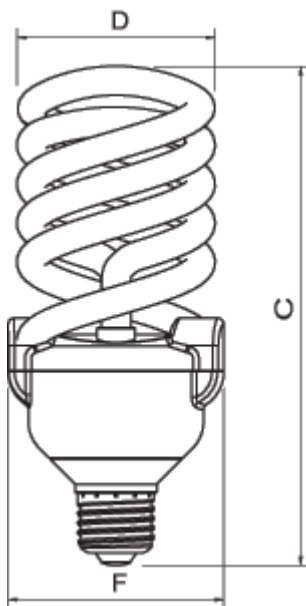

Helix Twister 11-34W Medium Dimmable



©2009 Koninklijke Philips Electronics N.V.

All rights reserved. Reproduction in whole or in part is prohibited without the prior written consent of the copyright owner. The information presented in this document does not form part of any quotation or contract, is believed to be accurate and reliable and may be changed without notice. No liability will be accepted by the publisher for any consequence of its use. Publication thereof does not convey nor imply any license under patent- or other industrial or intellectual property rights.

Document order number : 0000 000 00000