



PL-L 40W/841/4P 1CT

Product family description
PL-L Long 4pin Fluorescent Lamp.

Features/Benefits

- High lumen Output in a slim, compact size.
- Broad range of available wattages: 18, 24, 36, 40, 50, 55, and 80W.
- Excellent Color Rendering - 82 Color Rendering Index (CRI); 55W available with 91 CRI.
- Available in 3000, 3500 and 4100K; 55W available as 5000K only.
- Dimmable - PL-L 4-pin lamps may be used with electronic dimming ballasts.
- Long life: 15,000 to 20,000 hours average life depending on wattage.

Applications

- Ideal for commercial interior lighting applications in 2'x2' fixtures, 1'x2' fixtures, and indirect lighting.

Notes


- Rated average life under specified test conditions with lamps turned off and restarted no more frequently than once every 3 operating hours. Lamp life is appreciably longer if lamps are started less frequently. (202)
- Approximate Initial Lumens. The lamp lumen output is based upon lamp performance after 100 hours of operating life, when the output is measured during operation on a reference ballast under standard laboratory conditions. (203)
- Design Lumens are the approximate lamp lumen output at 40% of the lamp's Rated Average Life. This output is based upon measurements obtained during lamp operation on a reference ballast under standard laboratory conditions. (208)

Product data	
ProNumUS	300442
Full product name	PL-L 40W/841/4P 1CT
OrdCodUS	300442
Pack type	1 Lamp in a Folding Carton
Pieces per Sku	1
Skus/Case	25
EAN1US	
EAN2US	
EAN3US	
Successor Product number	



Product data	
System Description	Rapid Start
Base	2G11
Base Information	4P
Execution	/4P [4 Pins]
Packing Type	1CT [1 Lamp in a Folding Carton]
Packing Configuration	25
Avg. Life	10000 hr
Avg. Hrs. Life	- hr
Ordering Code	PL-L 40W/841/4P RS/IS
Pack UPC	046677111809
Case Bar Code	50046677111804
Watts	40W
Lamp Voltage	126 V
Dimmable	Yes
Color Code	840 [CCT of 4000K]
Color Rendering Index	82 Ra8
Color Designation	Cool White
Color Description	840 Cool White
Color Temperature	4000 K
Initial Lumens	3500 Lm
Overall Length C	571.6 mm
Diameter D	39 mm
Diameter D1	18 mm
Product Number	300442



PL-L

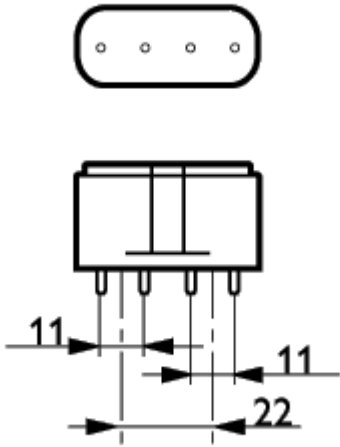


Base 2G11

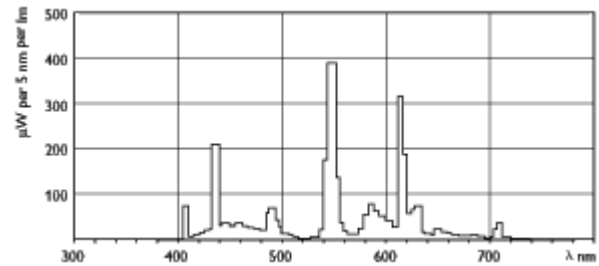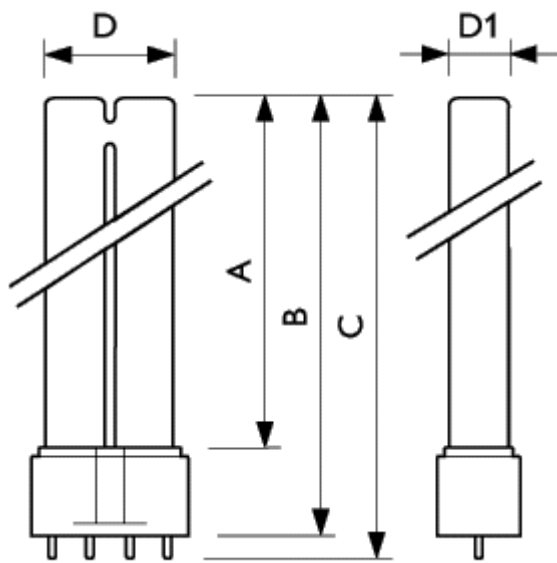

PL-L/840

PL-L

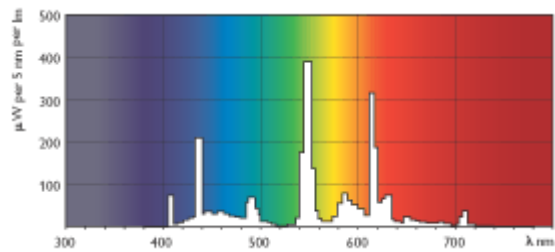

PL-L/840

