

Circline

FC16T9 40W Cool White Plus 1CT

T9 4-Pin Circular Fluorescent Lamps.



Product data

• General Characteristics

Base	G10q
Bulb	C-T9 [C-T 29 mm]

• Light Technical Characteristics

Color Code	33
Color Rendering Index	60 Ra8
Color Designation	Cool White
Color Temperature	4100 K
Initial Lumens	2500 Lm
Lumen Maintenance 2000h	85 %
Lumen Maintenance 5000h	75 %
Chromaticity Coordinate X	380 -
Chromaticity Coordinate Y	380 -

• Electrical Characteristics

Watts	40 W
-------	------

Lamp Wattage	39.5 W
Lamp Voltage	109 V
Lamp Current EM	0.42 A

• Product Dimensions


Diameter D	26.2 (min), 31.0 (max) mm
Overall Width E	393.7 (min), 406.4 (max) mm
Inner Width I	341.0 (min), 347.7 (max) mm

• Product Data

Product number	391185
Full product name	FC16T9 40W Cool White Plus 1CT
Short product name	FC16T9/COOL WHITE PLUS
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677391188
Bar code on case	50046677391183
Logistics code(s)	928028803335
eop_net_weight_pp	0.250 kg


Dimensional drawing

Dimensional drawing

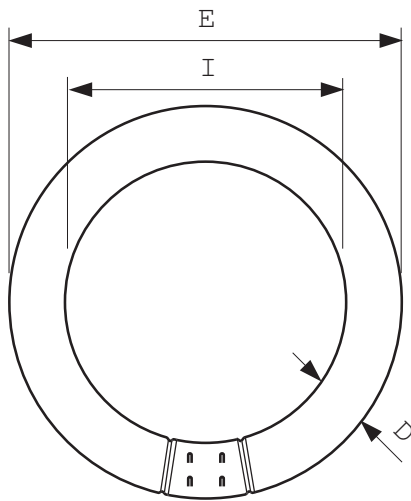

FC16T9 40W Cool White Plus 1CT

Product	D (Min)	D (Max)	E (Min)	E (Max)	I (Min)	I (Max)
TL-E 40W/33 RS	26.2	31.0	393.7	406.4	341.0	347.7

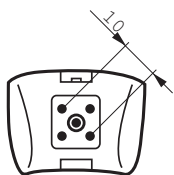

G10q



© 2013 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2013, May 13
data subject to change