



A-Shape LED

8A19/END/2700 DIM 6/1

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

Product data

• General Characteristics

Cap-Base	E26
Bulb	A19
Bulb Finish	- [-]
Rated Avg. Life (Hours)	25000 hr

• Light Technical Characteristics

Color Code	WW
Color Designation	Warm White
Correlated Color Temperature	2700 K
CRI	81
Color Temp. (Kelvin)	2700 K [CCT 2700K]
Rated Luminous Flux	470 Lm

• Electrical Characteristics

Wattage	8 W
Wattage Technical	8 W

Voltage	120 V
Dimmable	Yes

• Environmental characteristics

Energy Efficiency Label (EEL)	A
-------------------------------	---


• Product Data

Product number	414839
Full product name	8A19/END/2700 DIM 6/1
Short product name	8A19/END/2700-470 DIM ES
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677414832
Bar code on case	50046677414837
Logistics code(s)	929000188202
eop_net_weight_pp	0.120 kg



PHILIPS
sense and simplicity

Dimensional drawing

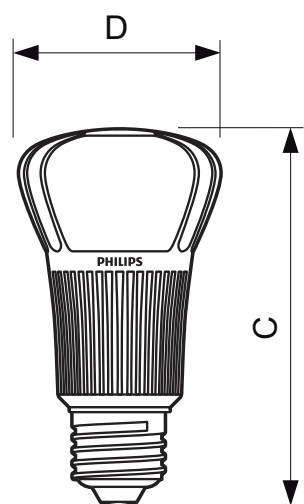

E26

8A19/END/2700 DIM 6/1

Product	C (Norm)	C1 (Max)	D (Norm)	D1 (Norm)
LED 8W E26 2700K 120V A19 DIM	-	-	-	-



© 2013 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2013, March 15
data subject to change