 


### Slimline Fluorescent Lamps (Instant Start), continued

Nominal Lamp Watts	Product Number 046677-	Ordering Code	Pkg. Qty.	Description	Nom. Length (In.)	Avg. Life, Hrs. (202)	Approx. Initial Lumens (203, 204)	Design Lumens (208)	CRI
56		F72T12/30U/ALTO	15	Ultralume, 3000K	72	12,000	4850	4550	85
		F72T12/35U/ALTO	15	Ultralume, 3500K	72	12,000	4850	4550	85
	☐	F72T12/41U/ALTO	15	Ultralume, 4100K	72	12,000	4850	4550	85
		F72T12/SPEC35	15	SPEC, 3500K	72	12,000	4700	4400	73
		F72T12/D/ALTO	15	Daylight, 6500K	72	12,000	3800	3350	79
		F72T12/WW/ALTO	15	Warm White, 3000K	72	12,000	4550	4000	53
		F72T12/CW/ALTO	15	Cool White, 4100K	72	12,000	4450	3900	62
		F72T12/CW/ALTO UPC	15	Cool White, 4100K (225)	72	12,000	4450	3900	62
60	ⓔ Ⓢ	F96T12/30U/EW/ALTO	15	Ultralume, 3000K	96	12,000	5900	5550	85
	ⓔ Ⓢ	F96T12/35U/EW/ALTO	15	Ultralume, 3500K	96	12,000	5900	5550	85
	ⓔ Ⓢ	F96T12/41U/EW/ALTO	15	Ultralume, 4100K	96	12,000	5900	5550	85
	☐ ⓔ Ⓢ	F96T12/50U/EW/ALTO	15	Ultralume, 5000K	96	12,000	5850	5500	85
	Ⓢ	F96T12/C50/EW	15	Colortone 50, 5000K	96	12,000	4100	3700	92
	☐ Ⓢ	F96T12/DX/EW/ALTO	15	Daylight Deluxe, 6500K	96	12,000	4200	3675	84
	ⓔ Ⓢ	F96T12/SPEC30/EW/ALTO	15	SPEC, 3000K	96	12,000	5750	5400	70
	ⓔ Ⓢ	F96T12/SPEC35/EW/ALTO	15	SPEC, 3500K	96	12,000	5750	5400	73
	ⓔ Ⓢ	F96T12/SPEC35/EW/ALTO UPC	15	SPEC, 3500K (225)	96	12,000	5750	5400	73
	ⓔ Ⓢ	F96T12/SPEC41/EW/ALTO	15	SPEC, 4100K	96	12,000	5750	5400	70
	ⓔ Ⓢ	F96T12/WW/EW/ALTO	15	Warm White, 3000K	96	12,000	5500	4850	53
	ⓔ Ⓢ	F96T12/CW/EW/ALTO	15	Cool White, 4100K	96	12,000	5400	4750	62
	ⓔ Ⓢ	F96T12/CW/EW/ALTO UPC	15	Cool White, 4100K (225)	96	12,000	5400	4750	62
	ⓔ Ⓢ	F96T12/CW/EW/ALTO	16	Cool White, 4100K, 2 Pack	96	12,000	5400	4750	62
	ⓔ Ⓢ	F96T12/LW/EW/ALTO	15	Lite White, 4200K	96	12,000	5600	4950	51
75	ⓔ	F96T12/30U/ALTO	15	Ultralume, 3000K	96	12,000	6600	6225	85
	ⓔ	F96T12/35U/ALTO	15	Ultralume, 3500K	96	12,000	6600	6225	85
	ⓔ	F96T12/41U/ALTO	15	Ultralume, 4100K	96	12,000	6600	6225	85
	ⓔ	F96T12/50U/ALTO	15	Ultralume, 5000K	96	12,000	6500	6125	85
		F96T12/C50	15	Colortone 50, 5000K	96	12,000	4650	4200	92
		F96T12/C50 UPC	15	Colortone 50, 5000K (225)	96	12,000	4650	4200	92
		F96T12/DX/ALTO	15	Daylight Deluxe, 6500K	96	12,000	4500	3950	84
	☐ Ⓢ	F96T12/DX/ALTO UPC	15	Daylight Deluxe, 6500K (225)	96	12,000	4500	3950	84
	☐ Ⓢ	F96T12/DX/ALTO	16	Daylight Deluxe, 6500K, 2 Pack	96	12,000	4500	3950	84
		F96T12/CWX	15	Deluxe Cool White, 4200K	96	12,000	4500	3950	89
		F96T12/N	15	Natural, 3700K	96	12,000	4300	3850	90
	ⓔ	F96T12/SPEC30/ALTO	15	SPEC, 3000K	96	12,000	6425	6050	70
	ⓔ	F96T12/SPEC35/ALTO	15	SPEC, 3500K	96	12,000	6425	6050	73
	ⓔ	F96T12/SPEC41/ALTO	15	SPEC, 4100K	96	12,000	6425	6050	73
		F96T12/GO	15	Gold Sleeved Lamp	96	12,000	3400	—	—

- Ⓢ — Energy Saving Product
- ☐ — Exclusive Philips Product
- ⓔ — This Bulb Meets US Federal Minimum Efficiency Standard
- ☐ — Features ALTO® Lamp Technology
- ☐ — Highest Color Rendering Lamps (CRI ≥ 80)
- ☐ — High Color Rendering Lamps (CRI 70–79)

Footnotes located on page 78



T12 Single Pin

**U-Bent Fluorescent Lamps** T12 Medium Bipin

Nominal Lamp Watts	Product Number 046677-	Ordering Code	Pkg. Qty. •	Description	Nom. Length (In.)(212)	Avg. Life, Hrs. (205)	Approx. Initial Lumens (203, 204)	Design Lumens (208)	CRI
40	Ⓔ 37879-4	<b>FB40/30U/6/ALTO</b>	12	Ultralume, 3000K	22 <sup>7</sup> / <sub>16</sub>	18,000	3100	2850	85
	Ⓔ 37840-6	<b>FB40/35U/6/ALTO</b>	12	Ultralume, 3500K	22 <sup>7</sup> / <sub>16</sub>	18,000	3100	2850	85
	Ⓔ 37876-0	<b>FB40/41U/6/ALTO</b>	12	Ultralume, 4100K	22 <sup>7</sup> / <sub>16</sub>	18,000	3100	2850	85
	☐ 21993-1	<b>FB40/DX/6</b>	12	Daylight Deluxe 6500K (225)	22 <sup>7</sup> / <sub>16</sub>	18,000	2250	1950	84
	Ⓔ 37866-1	<b>FB40/SPEC30/6/ALTO</b>	12	SPEC, 3000K	22 <sup>7</sup> / <sub>16</sub>	18,000	3050	2775	70
	Ⓔ 37854-7	<b>FB40/SPEC35/6/ALTO</b>	12	SPEC, 3500K	22 <sup>7</sup> / <sub>16</sub>	18,000	3050	2775	73
	Ⓔ 37875-8	<b>F40/SPEC35/6/ALTO UPC</b>	12	SPEC, 3500K	22 <sup>7</sup> / <sub>16</sub>	18,000	3050	2775	73
	Ⓔ 37868-7	<b>FB40/SPEC41/6/ALTO</b>	12	SPEC, 4100K	22 <sup>7</sup> / <sub>16</sub>	18,000	3050	2775	70
	Ⓔ 37861-2	<b>FB40/HL Cool/ALTO</b>	12	Home Light Cool, 4100K, Sleeved	22 <sup>7</sup> / <sub>16</sub>	18,000	3050	2775	70

**Slimline Fluorescent Lamps (Instant Start)** T12 Single Pin

Nominal Lamp Watts	Product Number 046677-	Ordering Code	Pkg. Qty. •	Description	Nom. Length (In.)	Avg. Life, Hrs. (202)	Approx. Initial Lumens (203, 204)	Design Lumens (208)	CRI
20	26277-4	<b>F24T12/CW</b>	24	Cool White, 4100K	24	7500	1090	960	62
30	26284-0	<b>F36T12/CW</b>	24	Cool White, 4100K	36	7500	1850	1630	62
35	26303-8	<b>F42T12/CW</b>	24	Cool White, 4100K	42	7500	2200	1920	62
30	§ 36605-4	<b>F48T12/SPEC35/EW/ALTO</b>	15	SPEC, 3500K	48	9000	2575	2350	73
	§ 36609-6	<b>F48T12/SPEC41/EW/ALTO</b>	15	SPEC, 4100K	48	9000	2575	2350	70
	§ 37650-9	<b>F48T12/CW/EW/ALTO</b>	15	Cool White, 4100K	48	9000	2400	2150	62
39	☐ 36610-4	<b>F48T12/41U/ALTO</b>	15	Ultralume, 4100K	48	9000	3150	2950	85
	36613-8	<b>F48T12/SPEC35/ALTO</b>	15	SPEC, 3500K	48	9000	3000	2800	73
	36219-4	<b>F48T12/D/ALTO</b>	15	Daylight, 6500K	48	9000	2500	2200	79
	36660-9	<b>F48T12/WW/ALTO</b>	15	Warm White, 3000K	48	9000	2950	2650	53
	36321-8	<b>F48T12/CW/ALTO</b>	15	Cool White, 4100K	48	9000	2950	2600	62
	36323-4	<b>F48T12/41U/ALTO UPC</b>	15	Cool White, 4100K (225)	48	9000	2900	2600	62
50	35564-4	<b>F60T12/D</b>	15	Daylight, 6500K	60	12,000	3150	2850	79
	35563-6	<b>F60T12/CW</b>	15	Cool White, 4100K	60	12,000	3450	3050	62
51	35577-6	<b>F64T12/D</b>	15	Daylight, 6500K	64	12,000	3200	2800	79
	35576-8	<b>F64T12/CW</b>	15	Cool White, 4100K	64	12,000	3750	3300	62


- § — Energy Saving Product
- ☐ — Exclusive Philips Product
- Ⓔ — This Bulb Meets US Federal Minimum Efficiency Standard

- ☐ — Features ALTO® Lamp Technology
- — Highest Color Rendering Lamps (CRI≥80)
- — High Color Rendering Lamps (CRI 70–79)

Footnotes located on page 78



T12 Single Pin

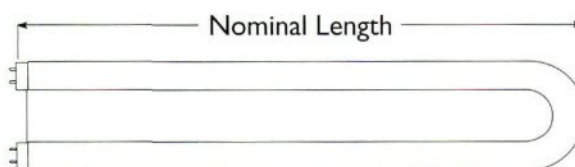

T12 Medium Bipin U-Bent

Nominal Length of U-Bent is base face