



# Candle LED

3.5B11/END/2700 E12 DIM 8/1

Philips Candle Dimmable LED Lamps offer decorative energy saving ambience with the elegant effect of incandescent candles. Available in bent, blunt and flame tip candles, their unique design provides light in all directions, giving lighting designers a long life alternative to standard incandescent sources.

## Product data

### • General Characteristics

Cap-Base	E12
Bulb	B11
Rated Avg. Life (Hours)	25000 hr
Rated Lifetime (years)	22.8 an

### • Light Technical Characteristics

Color Code	WW
Color Designation	Warm White
Beam Description	- [-]
Correlated Color Temperature	2700 K
CRI	80
Color Temp. (Kelvin)	2700 K [CCT 2700K]
Rated Luminous Flux	180 Lm

### • Electrical Characteristics

Wattage	3.5 W
Wattage Technical	3.5 W
Voltage	120 V
Line Frequency	60 Hz

Lamp Current mA	42 mA
Dimmable	Yes
Wattage Equivalent	25 W

### • Measuring Conditions

Switching cycle	50000x
-----------------	--------

### • Product Dimensions

Overall Length C	100 mm
Diameter D	35.5 mm

### • Product Data


Product number	427799
Full product name	3.5B11/END/2700 E12 DIM 8/1
Short product name	3.5B11/END/2700-E12 DIM 8/1
Pieces per Sku	1
eop_pck_cfg	8
Skus/Case	8
Bar code on pack	46677427795
Bar code on case	50046677427790
Logistics code(s)	929000241704
eop_net_weight_pp	0.050 kg

## Dimensional drawing




# PHILIPS

## Dimensional drawing

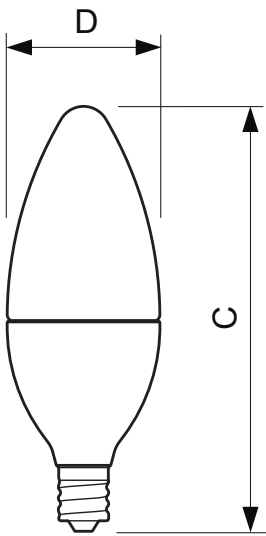

### 3.5B11/END/2700 E12 DIM 8/1

 Product	C (Norm)	C1 (Max)	D (Norm)	D1 (Norm)
LED 3.5W E12 2700K 120V B11	100	-	35.5	-



E12



© 2013 Koninklijke Philips N.V. (Royal Philips)  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2013, August 8  
data subject to change