

KEENE

Floodlights

PENTAFLOOD - PF1 ☆☆☆



Catalogue No.	Description	Lamp Type & Source	Ballast Type	Lamp Watts	Voltage	Ser. Qty
PF1A070PLWEMAL-8	Arm Mount	T4 G8.5 CMH	CWA	70	MULTI-TAP (120 /208/240/277)	8

PENTAFLOOD - PF2 ☆☆☆



Catalogue No.	Description	Lamp Type & Source	Ballast Type	Lamp Watts	Voltage	Ser. Qty	Applic. Pages
PF2Y175MAL-T	Yoke Mount	ED17 MH	CWA	175	TRI-TAP (120/277/347V)	6	119-124
PF2A175MAL-T	Arm Mount	ED17 MH	CWA	175	TRI-TAP (120/277/347V)	10	119-124

PENTAFLOOD - PF3 ☆☆☆



Catalogue No.	Description	Lamp Type & Source	Ballast Type	Lamp Watts	Voltage	Ser. Qty	Applic. Pages
PF3Y250MAL-T	Yoke Mount	ED28 MH	CWA	250	TRI-TAP (120/277/347V)	10	118-119-124
PF3Y250LXL-T	Yoke Mount	ED18 HPS	CWA	250	TRI-TAP (120/277/347V)	6	118-119-124
PF3Y400MAL-T	Yoke Mount	ED28 MH	CWA	400	TRI-TAP (120/277/347V)	30	118-119-124
PF3Y400LXL-T	Yoke Mount	ED18 HPS	CWA	400	TRI-TAP (120/277/347V)	10	118-119-124
PF3A400MAL-T	Adjustable Tenon Mount	ED28 MH	CWA	400	TRI-TAP (120/277/347V)	6	118-119-124



KEENE

Floodlights (cont'd)

PENTAFLOOD - PF4 ☆☆☆



Catalogue No.	Description	Lamp Type & Source	Ballast Type	Lamp Watts	Voltage	Ser. Qty
PF4A400MAL-T	Adjustable Tenon Mount	ED28 MH	CWA	400	TRI-TAP (120/277/347V)	6
PF4A400LXL-T	Adjustable Tenon Mount	ED28 HPS	CWA	400	TRI-TAP (120/277/347V)	6
PF4Y400MAL-T	Yoke Mount	ED18 MH	CWA	400	TRI-TAP (120/277/347V)	6
PF4Y400LXL-T	Yoke Mount	ED18 HPS	CWA	400	TRI-TAP (120/277/347V)	6

PENTAFLOOD - PF5 ☆☆☆



Catalogue No.	Description	Lamp Type & Source	Ballast Type	Lamp Watts	Voltage	Ser. Qty	Applic. Pages
PF5Y1000MAL-T	Yoke Mount	BT/ED/E56 MH	CWA	1000	TRI-TAP (120/277/347V)	10	118-119-124
PF5A1000MAL-T	Adjustable Tenon Mount	BT/ED/E56 MH	CWA	1000	TRI-TAP (120/277/347V)	15	118-119-124
PF5Y1000LXL-T	Yoke Mount	BT/ED/E56 HPS	CWA	1000	TRI-TAP (120/277/347V)	2	118-119-124
PF5A1000LXL-T	Adjustable Tenon Mount	BT/ED/E56 HPS	CWA	1000	TRI-TAP (120/277/347V)	4	118-119-124

DYNOLITE ☆



Catalogue No.	Lamp Type & Source	Ballast Type	Lamp Watts	Voltage	Ser. Qty	Applic. Pages
DLA070NLXL-1	ED17 MH	Reactor (NPF) or (HPF)	70	120V	30	118-124
DLA150NLXL-1	ED17 MH	Reactor (NPF) or (HPF)	150	120V	30	118-124



Floodlights (cont'd)

MINIRAY ☆☆☆




Catalogue No.	Description	Lamp Type & Source	Ballast Type	Lamp Watts	Voltage	Ser. Qty
🌿 MRA175DMAL-T	Arm Mount	ED17 MH	CWA	175	TRI-TAP (120/277/347V)	15
🌿 MRY175DMAL-T	Yoke Mount	ED17 MH	CWA	175	TRI-TAP (120/277/347V)	8

DYNOLITE and MINIRAY ACCESSORIES

Catalogue No.	Description	Ser. Qty
SL552	Polycarbonate Shield, Vandal Resistant	5

BANDIT ☆☆☆

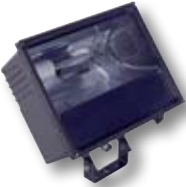

Catalogue No.	Description	Lamp Type & Source	Ballast Type	Lamp Watts	Voltage	Ser. Qty
🌿 BTA400MAL-T	Arm Mount	ED28 MH	CWA	400	TRI-TAP (120/277/347V)	6
BTY250LXL-T	Yoke Mount	E18 HPS	CWA	250	TRI-TAP (120/277/347V)	12
🌿 BTY250MAL-T	Yoke Mount	ED28 MH	CWA	250	TRI-TAP (120/277/347V)	20
BTY400LXL-T	Yoke Mount	E18 HPS	CWA	400	TRI-TAP (120/277/347V)	20
🌿 BTY400MAL-T	Yoke Mount	ED28 MH	CWA	400	TRI-TAP (120/277/347V)	30

HAZARDOUS BANDIT ☆☆☆



Catalogue No.	Lamp Type & Source	Ballast Type	Lamp Watts	Voltage	Ser. Qty
HBY400LXL-T	E18 HPS	CWA	400	TRI-TAP (120/277/347V)	6
🌿 HBY400MAL-T	ED28 MH	CWA	400	TRI-TAP (120/277/347V)	8



Floodlights (cont'd)

BANDIT and HAZARDOUS BANDIT ACCESSORIES

Catalogue No.	Description	Ser. Qty
BT552	Polycarbonate Shield, Vandal Resistant	7
BT10	Universal Slipfitter (2") for 2-3/8" O.D. Tenon	40

FLOODPAK AREA☆☆ WALL☆☆☆ FLOOD☆☆☆



Catalogue No.	Lamp Type & Source	Ballast Type	Lamp Watts	Voltage	Ser. Qty	Applic. Pages
FPM070MAL-T	ED17 MH	HX-HPF	70	TRI-TAP (120/277/347V)	4	119-120-121-124
FPM100MAL-T	ED17 MH	HX-HPF	100	TRI-TAP (120/277/347V)	4	119-120-121-124
FPM175MAL-T	ED17 MH	CWA	175	TRI-TAP (120/277/347V)	12	119-120-121-124
FPL250MAL-T	ED28 MH	CWA	250	TRI-TAP (120/277/347V)	8	119-120-121-124
FPL400MAL-T	ED28 MH	CWA	400	TRI-TAP (120/277/347V)	8	119-120-121-124

FLOODPAK ACCESSORIES

Catalogue No.	Description	Ser. Qty
FPLAA	Adjustable arm 2" tenon for FPL	8
FPLPMA	Pole Mount arm FPL (converts FPL Floodpak to pole mount)	8
FPLRPA	Round Pole Adapter for FPL (for use with FPLPMA)	8
FPSAA	Adjustable arm 1/2" NPT for FPS & FPM - Bronze	3
FPSAA-B	Adjustable arm 1/2" NPT for FPS & FPM - Black	3
FPSPMA	Pole Mount arm FPS/FPM (converts FPS/FPM Floodpak to pole mount)	3
FPSRPA	Round Pole Adapter for FPS & FPM (for use with FPSPMA)	3

PARAFLOOD☆☆☆



Catalogue No.	Lamp Type & Source	Ballast Type	Lamp Watts	Voltage	Ser. Qty	Applic. Pages
PR400MAL-T	ED37 MH	CWA	400	TRI-TAP (120/277/347V)	3	119-124

