



A-Shape LED

19A21/2700-WHT DIM 6/1

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

Product data

• General Characteristics

Cap-Base	E26
Bulb	A21
Rated Avg. Life (Hours)	25000 hr
Rated Lifetime (years)	20 an

• Light Technical Characteristics

Color Code	827
Color Designation	Warm White
Correlated Color Temperature	2700 K
CRI	80
Color Temp. (Kelvin)	2700 K [CCT 2700K]
Rated Luminous Flux	1680 Lm

• Electrical Characteristics

Wattage	19 W
Wattage Technical	19 W
Voltage	120 V
Line Frequency	50-60 Hz
Power Factor	0.9 -
Lamp Current mA	195 mA
Dimmable	Yes
Wattage Equivalent	100 W

Starting Time 0.5 s

• Environmental characteristics

Energy Efficiency Label (EEL) A

• Measuring Conditions

Switching cycle 50000x

• Product Dimensions

Overall Length C 125 mm
Diameter D 60 mm

• Product Data


Product number 432211
Full product name 19A21/2700-WHT DIM 6/1
Short product name 19A21/2700-WHT DIM 6/1
Pieces per Sku 1
eop_pck_cfg 6
Skus/Case 6
Bar code on pack 46677432218
Bar code on case 50046677432213
Logistics code(s) 929000259604
eop_net_weight_pp 0.224 kg



PHILIPS

A-Shape LED

Dimensional drawing

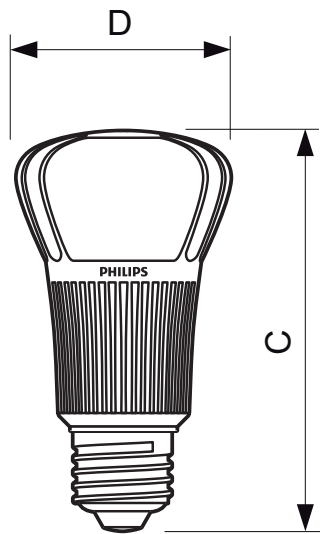


E26

19A21/2700-WHT DIM 6/1

Product	C (Norm)	C1 (Max)	D (Norm)	D1 (Norm)
LED D 19W E26/827 120V A21	125	-	60	-

Photometric data

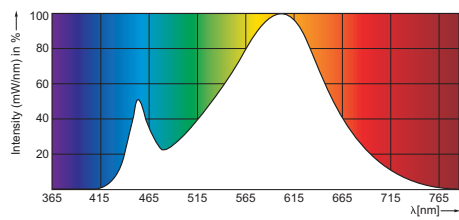

15 W, 19 W, 10-60 W /827



© 2013 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2013, December 9
data subject to change