



# Halogen A19

## Halogen 72A19/EV 120V 12/2


Halogen bulbs reduce energy consumption without sacrificing the qualities of a traditional bulb. They uniquely produce light more efficiently. They work with dimmer switches and are available in the familiar A-shape design. Use them in existing fixtures just as you would standard incandescents and your home will look great while you save energy.

### Product data

General Information		Cap-Base Information	
Cap-Base	E26 [ Single Contact Medium Screw]	Bulb Material	Aluminium [ Aluminium Cap]
Operating Position	Universal [ Universal]	Filament Shape	Glass
Main Application	General Lighting (G)		CC-8 [ Axial]
Gas Filling	GAS		
Light Technical		Product Data	
Luminous Flux Lamp @ 120V	1490 lm	Order product name	Halogen 72A19/EV 120V 12/2
		EAN/UPC - Product	50046677409826
		Order code	409821
		Numerator - Quantity Per Pack	1
		Numerator - Packs per outer box	12
Operating and Electrical		Material Nr. (12NC)	925701836301
Power (Rated) (Nom)	72 W	Net Weight (Piece)	0.005 kg
Lamp Wattage Rated@120V	72 W		
Voltage (Nom)	120 V		
Mechanical and Housing			
Bulb Finish	White (WH)		

## Halogen A19

### Dimensional drawing

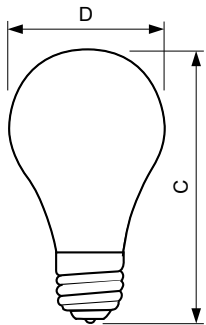

Product	D	C (max)
Halogen 72A19/EV 120V 12/2	2.375 in	4.13 in

72W E26/ALC 120V A19 WH

