



# A-Shape LED

9.5A19/2200-2700 DIM 6/1

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

## Product data

### • General Characteristics

Cap-Base	E26
Bulb	A19
Rated Avg. Life (Hours)	25000 hr
Rated Avg. Life (Hours)	25000 hr

### • Light Technical Characteristics

Color Code	WW
Color Designation	Warm White
Beam Description	- [-]
Correlated Color Temperature	2700 K
Approximate Lumens	800 Lm
Approx. MBCP	800 cd
CRI	80
Luminous Efficacy Lamp	76.19 Lm/W
Color Temp. (Kelvin)	2700 K [CCT 2700K]
Rated Luminous Flux	800 Lm

### • Electrical Characteristics

Wattage	9.5 W
Voltage	120 V
Line Frequency	60 Hz
Power Factor	0.9 -
Lamp Current mA	100 mA

Dimmable	Yes
Wattage Equivalent	60 W
Starting Time	0.5 (max) s

### • Environmental characteristics

Energy consumption kWh/1000h	10 kWh
------------------------------	--------

### • Measuring Conditions

Switching cycle	50000X
-----------------	--------

### • Product Dimensions

Overall Length C	110 mm
Diameter D	62 mm

### • Product Data


Product number	453324
Full product name	9.5A19/2200-2700 DIM 6/1
Short product name	9.5A19/2200-2700 DIM
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677453329
Bar code on case	50046677453324
Logistics code(s)	929001117504
eop_net_weight_pp	0.130 kg



# PHILIPS

# A-Shape LED

## Dimensional drawing

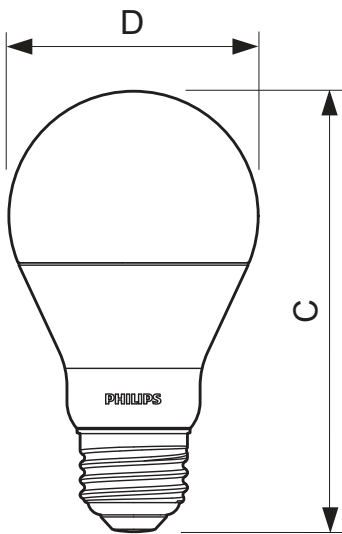

E26

### 9.5A19/2200-2700 DIM 6/1

Product	C (Norm)	D (Norm)
LED 9.5W E26 2700K 120V A19	110	62



© 2015 Koninklijke Philips N.V. (Royal Philips)  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2015, February 9  
data subject to change