


PHILIPS
LIGHTOLIER

Downlighting

SlimSurface LED

Round and square aperture
slim surface mount downlight

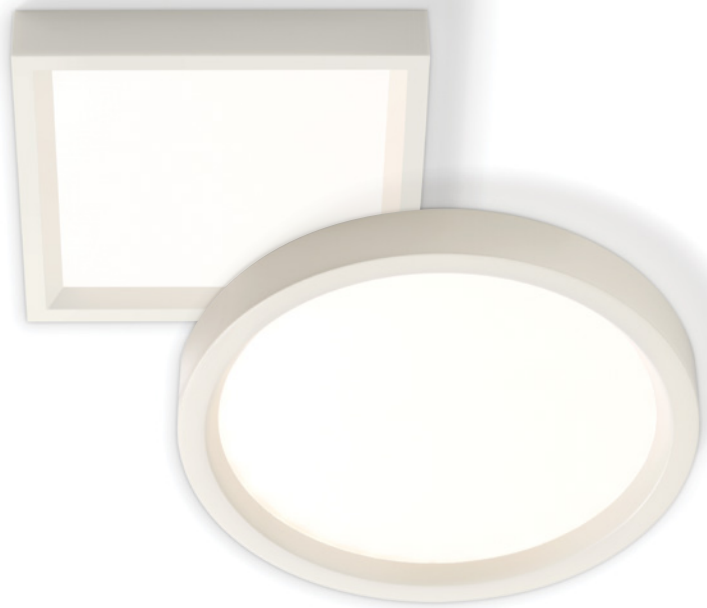


An architecturally pleasing, easy to install and low profile downlight

SlimSurface LED leverages the latest LED technology, optical enhancements and features a similar performance to typical recessed downlights but in a surface mount design.

Delivering high lumen output and great visual comfort, this $\frac{5}{8}$ " surface mount downlight is a pleaser for both specifiers and contractors. SlimSurface LED is characterized by a completely flat lens with a narrow flange, giving it an architecturally pleasing look. This downlighting solution also eliminates the need for an Air-Seal recessed housing or fire rated boxes, reducing material and installation costs.

Benefits

- The thinnest available solution with an integral driver for existing J-boxes or new construction
- Surface mounting fits any ceiling and solves the problem of limited plenum space
- Easy to install on standard j-boxes
- Architecturally pleasing due to its narrow profile
- Provides an affordable alternative to Air-Seal IC recessed housings or Fire-Rated boxes
- Choice of design with square and round apertures
- Glare controlling lens for comfortable light distribution
- Wet location listing allows for use in showers and bathrooms (if local code requires)

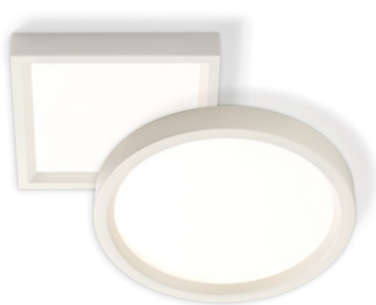

SlimSurface LED

SlimSurface LED is a low profile downlight intended for ceiling or wall mount applications. This $\frac{5}{8}$ " thick luminaire offers the appearance of a recessed downlight but is actually surface mounted.

Round aperture

Catalog No.	Size	CRI	CCT	Listing	Finish (painted)
S5R827K7	5-inch	80	2700K	Wet	White
S5R827K7AL	5-inch	80	2700K	Wet	Aluminum
S5R830K7	5-inch	80	3000K	Wet	White
S5R830K7AL	5-inch	80	3000K	Wet	Aluminum
S5R927K7	5-inch	90	2700K	Wet	White
S5R927K7AL	5-inch	90	2700K	Wet	Aluminum
S5R830K7-D	5-inch	80	3000K	Damp	White
S7R827K10	7-inch	80	2700K	Wet	White
S7R827K10AL	7-inch	80	2700K	Wet	Aluminum
S7R830K10	7-inch	80	3000K	Wet	White
S7R830K10AL	7-inch	80	3000K	Wet	Aluminum
S7R927K10	7-inch	90	2700K	Wet	White
S7R927K10AL	7-inch	90	2700K	Wet	Aluminum
S7R830K10-D	7-inch	80	3000K	Damp	White


Square aperture

Catalog No.	Size	CRI	CCT	Listing	Finish (painted)
S4S827K7	4-inch	80	2700K	Wet	White
S4S827K7AL	4-inch	80	2700K	Wet	Aluminum
S4S830K7	4-inch	80	3000K	Wet	White
S4S830K7AL	4-inch	80	3000K	Wet	Aluminum
S4S927K7	4-inch	90	2700K	Wet	White
S4S927K7AL	4-inch	90	2700K	Wet	Aluminum
S4S830K7-D	4-inch	80	3000K	Damp	White
S6S827K10	6-inch	80	2700K	Wet	White
S6S827K10AL	6-inch	80	2700K	Wet	Aluminum
S6S830K10	6-inch	80	3000K	Wet	White
S6S830K10AL	6-inch	80	3000K	Wet	Aluminum
S6S927K10	6-inch	90	2700K	Wet	White
S6S927K10AL	6-inch	90	2700K	Wet	Aluminum
S6S830K10-D	6-inch	80	3000K	Damp	White


Features

- Apertures: round & square
- Efficacy: 65 - 70 lm/w
- CCT: 2700 & 3000 K
- CRI: 80 & 90
- Lumens: 650 & 1000 lm
- Wattage: 9.5 to 14.2W
- Voltage: 120V (50/60Hz)
- 50,000 hour rated life (L70)
- Dimming to 10% (TRIAC)
- cULus listed suitable for:
 - damp locations (walls)
 - wet locations (ceilings)
- ENERGY STAR® certified
- Standard 5-year limited warranty


5" round downlight

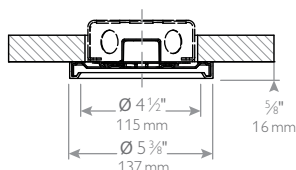


4" square downlight

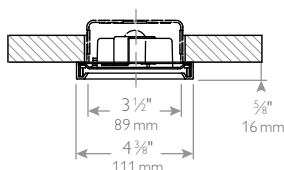

7" round downlight

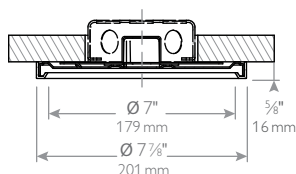

6" square downlight

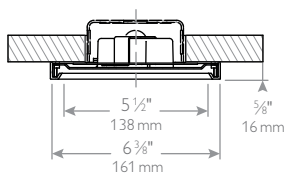

Visit philips.com/warranties for more information on the standard 5-year limited warranty.



© 2014 Koninklijke Philips N.V. All rights reserved. Philips reserves the right to make changes in specifications and/or to discontinue any product at any time without notice or obligation and will not be liable for any consequences resulting from the use of this publication.



Philips Lighting, North America Corporation
200 Franklin Square Drive, Somerset, NJ 08873
Tel. 855-486-2216

Imported by: Philips Lighting,
A division of Philips Electronics Ltd.
281 Hillmount Rd, Markham, ON, Canada L6C 2S3
Tel. 800-668-9008