



EcoVantage

EcoVantage 29W 120V A19 CL 2CT

The new EcoVantage bulbs reduce energy consumption without sacrificing the qualities of a traditional bulb. They uniquely produce light more efficiently. They work with dimmer switches and are available in the familiar A-shape design. Use them in existing fixtures just as you would standard incandescents and your home will look great while you save energy.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A19
Bulb Material	Glass
Bulb Finish	Clear
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
Atmosphere	Gas
Rated Avg. Life @ 120v	1000 hr

• Light Technical Characteristics

Initial Lumens @ 120V	380 Lm
-----------------------	--------

• Electrical Characteristics

Energy Used	29 W
Lamp Wattage	29 W
Rated@120V	

Voltage	120 V
---------	-------

• Product Dimensions


Max. Overall Length (MOL) - C	4.13 (max) in
Diameter D	2.375 in

• Product Data

Order code	925702136301
Full product code	925702136301
Full product name	EcoVantage 29W 120V A19 CL 2CT
Order product name	29W 120V A19 CL 2CT
Pieces per pack	2
Packing configuration	12
Packs per outerbox	12
Bar code on pack - EAN1	46677410506
Bar code on outerbox - EAN3	50046677410501
Logistic code(s) - 12NC	925702136301
Net weight per piece	0.005 kg

PHILIPS

Dimensional drawing

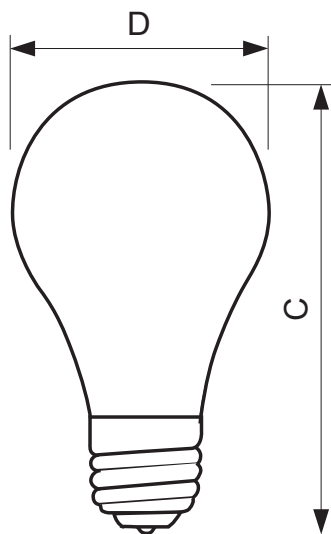

EcoVantage 29W 120V A19 CL 2CT

Product	C (Max)	D (Norm)
29W E26/ALC 120V A-19 Clear	4.13	2.375



E26



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, May 31
data subject to change