



A-Shape LED

6.5A19/2200-2700 DIM 6/1

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

Product data

• General Characteristics

Cap-Base	E26
Bulb	A19
Rated Avg. Life (Hours)	25000 hr
Rated Avg. Life (Hours)	25000 hr

• Light Technical Characteristics

Color Code	WW
Color Designation	Warm White
Beam Description	- [-]
Correlated Color Temperature	2700 K
Approximate Lumens	450 Lm
Approx. MBCP	450 cd
CRI	80
Luminous Efficacy Lamp	64.29 Lm/W
Color Temp. (Kelvin)	2700 K [CCT 2700K]
Rated Luminous Flux	450 Lm

• Electrical Characteristics

Wattage	6.5 W
Voltage	120 V
Line Frequency	60 Hz
Power Factor	0.86 -
Lamp Current mA	75 mA

Dimmable	Yes
Wattage Equivalent	40 W
Starting Time	0.5 (max) s

• Environmental characteristics

Energy consumption kWh/1000h	7 kWh
------------------------------	-------

• Measuring Conditions

Switching cycle	50000X
-----------------	--------

• Product Dimensions

Overall Length C	110 mm
Diameter D	62 mm


• Product Data

Product number	453316
Full product name	6.5A19/2200-2700 DIM 6/1
Short product name	6.5A19/2200-2700 DIM
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677453312
Bar code on case	50046677453317
Logistics code(s)	929001117604
eop_net_weight_pp	0.130 kg



PHILIPS

Dimensional drawing

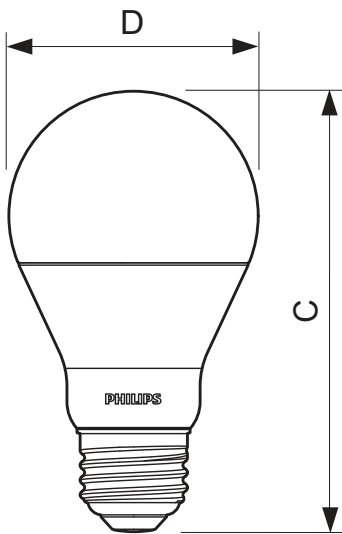

E26

6.5A19/2200-2700 DIM 6/1

Product	C (Norm)	D (Norm)
LED 6.5W E26 2700K 120V A19	110	62



© 2015 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2015, February 19
data subject to change