



# Innovative design, irresistible price

## SlimStyle A-Shape Dimmable LED

Philips SlimStyle A-Shape Dimmable LED Bulb is the same size as a traditional A19/A21 light bulb in a new slim design. Its innovative shape provides energy efficiency and quality light in a durable shape.

### Benefits

- Easy to experience - Provides soft, quality light similar to incandescents - Available in Soft White (2700K)
- Long life reduces the hassle of replacing bulbs so often ; Will not fade fabrics or furnishings
- Contains no mercury; Dimmable\*\*
- Innovative design - Slim shape fits in most fixtures with a medium base
- Rugged design ensures durability and is ideal for households that want to provide a sense of security for their family
- Provides light all-around

### Features

- Long lasting, energy efficient light
- Replaces 40 Watt and 60 Watt incandescent bulbs
- Last up to 22.8 years\*
- Low yearly energy costs

### Warnings and Safety

- Suitable for damp locations
- Not for use in totally enclosed luminaires (fixtures)
- This bulb is not intended for use with emergency exit fixtures or emergency lights.
- Before replacing, turn off power and let bulb cool to avoid electrical shock or burn.



# PHILIPS

Related products




8 W, 10.5 W E26 A19




13 W E26 A21

Dimensional drawing

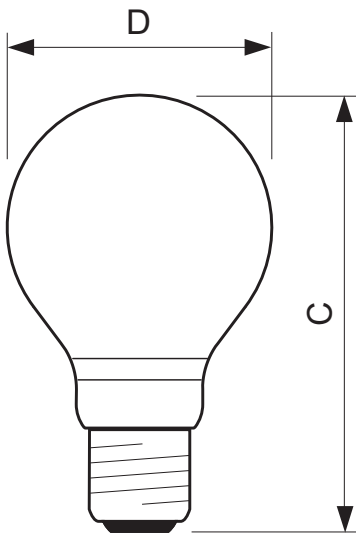

8A19/SLIM/2700 DIM 6/1

Product	C (Norm)	D (Norm)
LED 8-40W E26 2700K 120V A19	111.6	69
LED 10.5-60W E26 2700K 120V A19	111.6	69

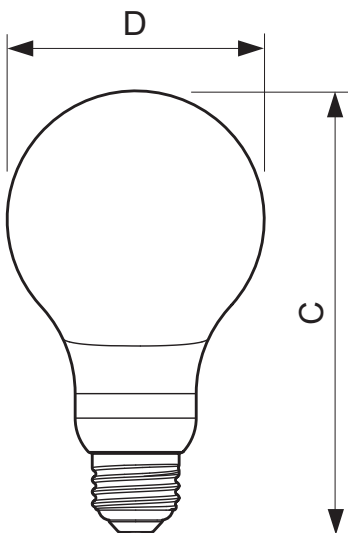

13A21/SLIM/2700 DIM 120V 10/1


Product	C (Norm)	D (Norm)
LED 13W E26 2700K 120V A21	134	78

## General Characteristics

Product number	Full product name	Cap-Base	Bulb	Rated Avg. Life (Hours)	Rated Avg. Life (Hours)
433672	8A19/SLIM/2700 DIM 6/1	E26	A19	25000 hr	25000 hr
433276	10.5A19/SLIM/2700 DIM 6/1	E26	A19	25000 hr	25000 hr

Product number	Full product name	Cap-Base	Bulb	Rated Avg. Life (Hours)	Rated Avg. Life (Hours)
452771	13A21/SLIM/2700 DIM 120V 10/1	E26	A21	25000 hr	25000 hr

## Installation diagrams

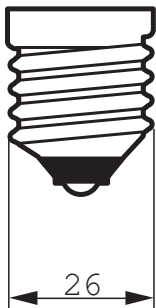


E26

## Light Technical Characteristics

Product number	Full product name	Color Code	Beam Description	Approximate Lumens	CRI	Color Temp. (Kelvin)	Rated Luminous Flux
433672	8A19/SLIM/2700 DIM 6/1	WW	-	450 Lm	80	2700 K	450 Lm
433276	10.5A19/SLIM/2700 DIM 6/1	WW	-	800 Lm	80	2700 K	800 Lm
452771	13A21/SLIM/2700 DIM 120V 10/1	WW	-	1100 Lm	80	2700 K	1100 Lm

## Light technical

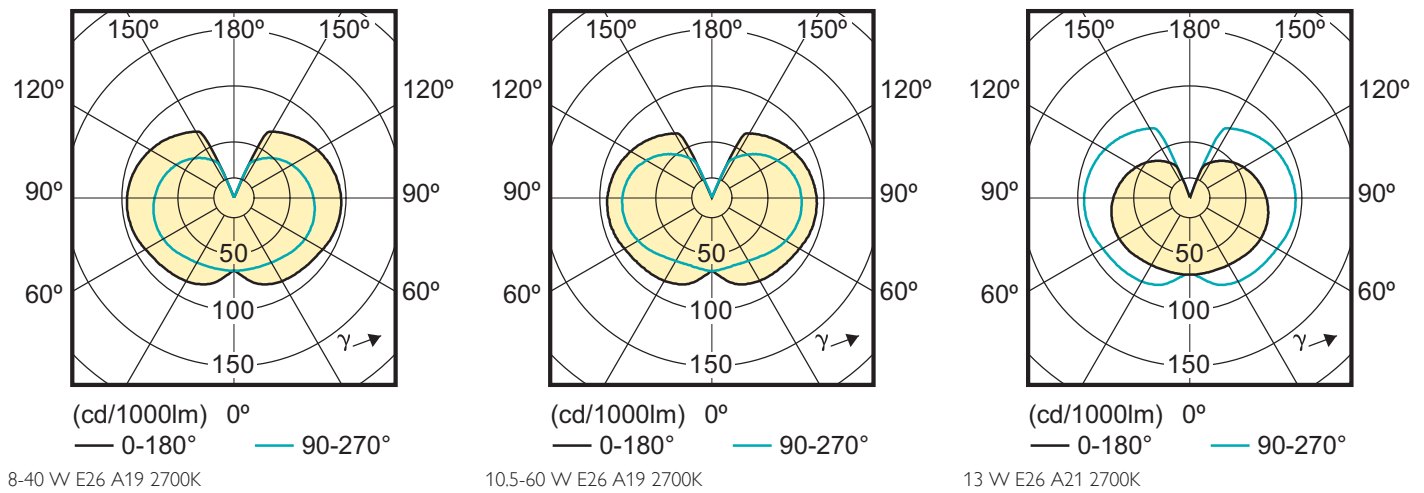

## Electrical Characteristics

Product number	Full product name	Wattage	Voltage	Line Frequency	Dimmable	Wattage Equivalent	Starting Time
433672	8A19/SLIM/2700 DIM 6/1	8 W	120 V	60 Hz	Yes	40 W	0.5 (max) s
433276	10.5A19/SLIM/2700 DIM 6/1	10.5 W	120 V	60 Hz	Yes	60 W	0.5 (max) s
452771	13A21/SLIM/2700 DIM 120V 10/1	13 W	120 V	60 Hz	Yes	75 W	0.5 (max) s

## Environmental characteristics

Product number	Full product name	Energy consumption kWh/1000h
433672	8A19/SLIM/2700 DIM 6/1	8 kWh
433276	10.5A19/SLIM/2700 DIM 6/1	11 kWh
452771	13A21/SLIM/2700 DIM 120V 10/1	13 kWh

## Measuring Conditions

Product number	Full product name	Switching cycle
433672	8A19/SLIM/2700 DIM 6/1	50000X
433276	10.5A19/SLIM/2700 DIM 6/1	50000X
452771	13A21/SLIM/2700 DIM 120V 10/1	50000X



© 2015 Koninklijke Philips N.V. (Royal Philips)  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2015, July 14  
data subject to change