



A-Shape LED

A19 8W 5000K E26

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

Product data

General Information

Cap-Base	E26 [Single Contact Medium Screw]
Nominal Lifetime (Nom)	10950 h
Switching Cycle	50000X
Technical Type	8-60W

Light Technical

Color Code	850 [CCT of 5000K]
Luminous Flux (Nom)	800 lm
Luminous Flux (Rated) (Nom)	800 lm
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Luminous Efficacy (rated) (Nom)	100 lm/W
Color Consistency	ANSI
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and Electrical

Input Frequency	60 Hz
Power (Rated) (Nom)	8 W
Lamp Current (Nom)	135 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s

Warm Up Time To 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.8
Voltage (Nom)	120 V

Temperature

T-Case Maximum (Nom)	95 °C
----------------------	-------

Controls and Dimming

Dimmable	No
----------	----

Mechanical and Housing

Bulb Finish	Frosted
-------------	---------

Approval and Application

Suitable For Accent Lighting	Yes
Energy Consumption kWh/1000 h	8 kWh


Product Data

Order product name	A19 8W 5000K E26
EAN/UPC - Product	046677455606
Order code	929001135203
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4

A-Shape LED

Material Nr. (12NC)	929001135203
Net Weight (Piece)	0.052 kg



Dimensional drawing

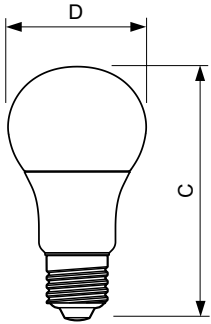

Bulb A19 120V 8W-60W 150D 5000K E26 ND

Product	D	C
A19 8W 5000K E26	61.0 mm	107.4 mm

Photometric data

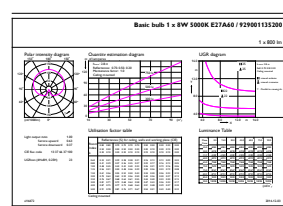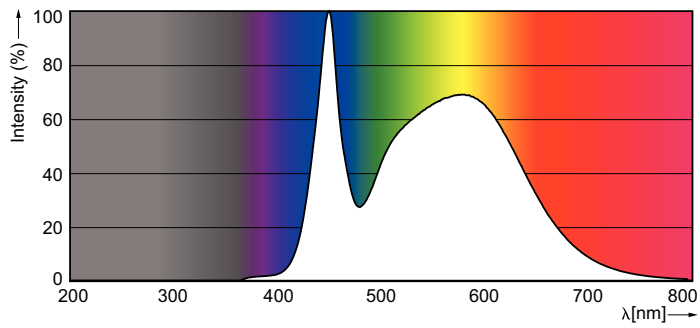

General Uniform Lighting

Calculation Photometrics v.5

Philips Lighting B.V.

Page 1/1

