

Low Pressure Sodium - SOX

SOX 180W 1SL

High energy efficiency low pressure sodium lamps for indoor and outdoor applications.

Product data

• General Characteristics

Base	DC Bayonet
Bulb	T-21 [Diameter: 2.625 inch]
Operating Position	Horizontal +/- 20D [Parallel +/-20D or Horizontal(HOR)]
Life to 5% failures	6000 hr
Life to 20% failures	12000 hr
RatedAvgLife(See Family Notes)	18000 hr

• Light Technical Characteristics

Color Temperature	1800 K
Initial Lumens	32000 Lm
Luminous Efficacy	176 Lm/W
Lamp EM	
Lumen Maintenance 2000h	90 %
Lumen Maintenance 5000h	80 %
Luminance Average EM	9 cd/cm ²

• Electrical Characteristics

Watts	180 W
Lamp Wattage	180.0 W
Lamp Voltage	240 V
Lamp Current	0.78 A
Dimmable	No

• Environmental Characteristics

Energy Efficiency Label (EEL)	A++
-------------------------------	-----

Mercury (Hg) Content	0 mg
Energy consumption kWh/1000h	203 kWh

• Luminaire Design Requirements

Cap-Base Temperature	150 (max) C
Bulb Temperature	150 (max) C

• Product Dimensions


Overall Length C	1120 (max) mm
Diameter D	66 (max) mm

• Product Data

Product number	151167
Full product name	SOX 180W BY22d 1SL
Short product name	SOX 180W BY22d 1SL/6
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677405243
Bar code on case	50046677151169
Logistics code(s)	928147500029
tpd_ilcos_cd	LS-180-BY22d
eop_net_weight_pp	1.033 kg


PHILIPS

Dimensional drawing

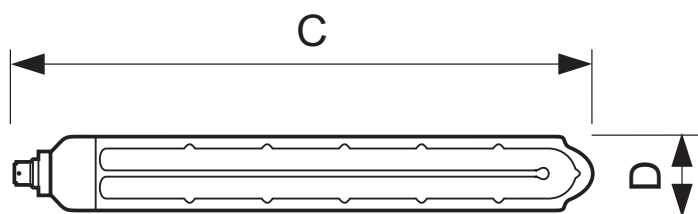

SOX 180W 1SL

Product	C (Max)	D (Max)
SOX 180W BY22d T65	1120	66

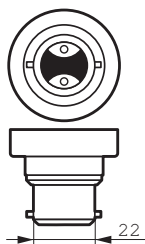

BY22d



© 2015 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2015, August 29
data subject to change