



BR/R LED

6R20/LED/827-22/DIM 120V

Philips BR Dimmable LED Lamps with AirFlux technology provide a soft, diffused level of light and smooth dimming to reduce glare. The sleek, lightweight design is ideal for downlighting.

Product data


General Information		Starting Time (Nom)	
Cap-Base	E26 [Single Contact Medium Screw]		0.5 s
Bulb Shape	R-20 (R20)	Warm Up Time To 60% Light (Nom)	0.5 s
Nominal Lifetime (Nom)	25000 h	Power Factor (Nom)	0.8
Switching Cycle	50000X	Voltage (Nom)	120 V
Technical Type	6-45W		
Light Technical		Temperature	
Color Code	822-827 [tunable warm white]	T-Case Maximum (Nom)	76 °C
Luminous Flux (Nom)	450 lm		
Luminous Flux (Rated) (Nom)	450 lm	Controls and Dimming	
Color Designation	Warm White (WW)	Dimmable	Yes
Correlated Color Temperature (Nom)	2200-2700 K		
Luminous Efficacy (rated) (Nom)	75 lm/W	Mechanical and Housing	
Color Consistency	<6	Bulb Finish	Frosted
Color Rendering Index (Nom)	80		
LLMF At End Of Nominal Lifetime (Nom)	70 %	Approval and Application	
		Energy star mark	Energy star
		Suitable For Accent Lighting	Yes
		Energy Consumption kWh/1000 h	6 kWh
Operating and Electrical		Product Data	
Input Frequency	60 Hz	Order product name	6R20/LED/827-22/DIM 120V
Power (Rated) (Nom)	6 W	EAN/UPC - Product	046677456979
Lamp Current (Nom)	65 mA	Order code	929001155704
Wattage Equivalent	45 W		

BR/R LED

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929001155704

Net Weight (Piece)	0.001 kg
--------------------	----------

Dimensional drawing

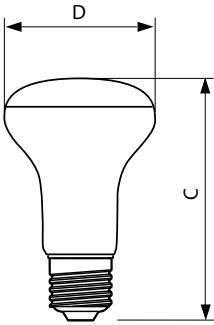

Product	D	C
6R20/LED/827-22/DIM 120V	65 mm	101 mm

R20 G5 120V 6W-45W 450lm 827-22 E26 D

Photometric data

Accent Lighting - Spots

