

# PL-T Triple 4-Pin Base

## PL-T 18W/841/A/4P/ALTO

Philips Linear Compact Fluorescent Lamps offer designers, specifiers and end-users new levels of efficiencies and versatility in sizes, configurations and application possibilities. With so many elegant fixtures available to complement their small size, high light output and advanced technology, Philips Energy Advantage lamps are fast becoming the preferred choice when maximum efficiency and sleek design solutions are required.

### Product data

#### • General Information

Cap-Base GX24Q-2 [ GX24q-2]

#### • Light Technical

Color Code 841 [ CCT of 4100K]  
Initial lumen (Nom) 1175 lm  
Luminous Flux (Rated) (Nom) 1175 lm  
Color Designation Cool White (CW)  
Chromaticity Coordinate X (Nom) 380  
Chromaticity Coordinate Y (Nom) 379  
Correlated Color Temperature (Nom) 4100 K  
Luminous Efficacy (rated) (Nom) 65.3 lm/W  
Color Rendering Index (Nom) 80

#### • Operating and Electrical

Power (Rated) (Nom) 18.0 W  
Lamp Current (Nom) 0.225 A

#### • Temperature

Design Temperature (Nom) 28 °C

#### • Controls and Dimming

Dimmable Yes

#### • Mechanical and Housing

Cap-Base Information 4P

#### • Approval and Application

Energy Efficiency Label (EEL) B  
Mercury (Hg) Content (Nom) 1.4 mg


#### • Product Data

Order product name PL-T 18W/841/A/4P/ALTO  
EAN/UPC - Product 046677268220  
Order code 458232  
Numerator - Quantity Per Pack 1  
Numerator - Packs per outer box 10  
Material Nr. (12NC) 927910584150  
Net Weight (Piece) 58.000 g  
ILCOS Code FSM-18/40/1B-E-GX24q=2

# PHILIPS

# PL-T Triple 4-Pin Base

## Dimensional drawing

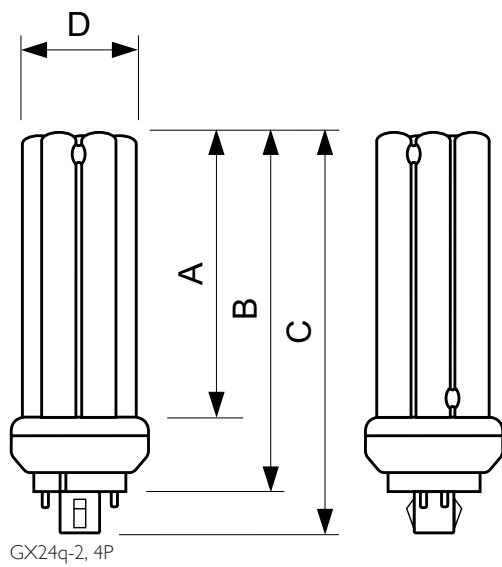

### PL-T ALTO 18W/841/4P A

Product	D	A	B	C
PL-T 18W/841/A/4P/ALTO	41 mm	71.7 mm	96.0 mm	111.7 mm

