

# LED Filament

4.5A19b/LEDFilament/822/CL-A/DIM 120V

Featuring a classic heritage design, LED Deco Classic delivers beautiful, decorative warm-white light while saving around 90% on energy costs.

## Product data

### • General Information

Cap-Base	E26 [ E26 Single Contact Medium Screw]
Bulb Shape	A19 (A19)
Nominal Lifetime (Nom)	15000 h
Switching Cycle	50000X
Technical Type	4.5-40W

### • Light Technical

Color Code	820 [ CCT of 2000K]
Luminous Flux (Nom)	350 lm
Luminous Flux (Rated) (Nom)	350 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2000 K
Luminous Efficacy (rated) (Nom)	77 lm/W
Color Consistency	ANSI
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %

### • Operating and Electrical

Input Frequency	50 or 60 Hz
Power (Rated) (Nom)	4.5 W

Lamp Current (Nom)	50 mA
Wattage Equivalent	40 W
Starting Time (Max)	0.5 s
Warm Up Time To 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	110-130 V

### • Controls and Dimming

Dimmable	Yes
----------	-----

### • Mechanical and Housing

Bulb Finish	Amber
-------------	-------

### • Approval and Application


Energy Consumption kWh/1000 h	- kWh
-------------------------------	-------

### • Product Data

Order product name	4.5A19b/LEDFilament/822/CL-A/DIM 120V
Order code	929001210104
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	929001210104
Net Weight (Piece)	0.030 kg

**PHILIPS**

## Dimensional drawing

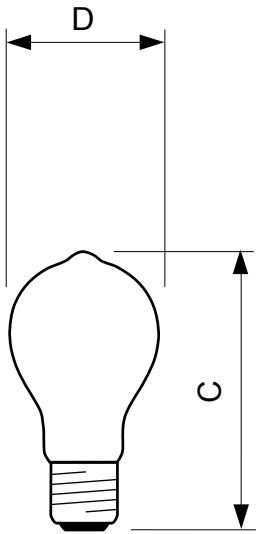


E26 A19

## Filament Bulb A19 CL 4.5-40W 550lm E26 D


Product	D	C
4.5A19b/LEDFilament/822/CL-A/DIM 120V	47 mm	80 mm

## Photometric data

## General Uniform Lighting

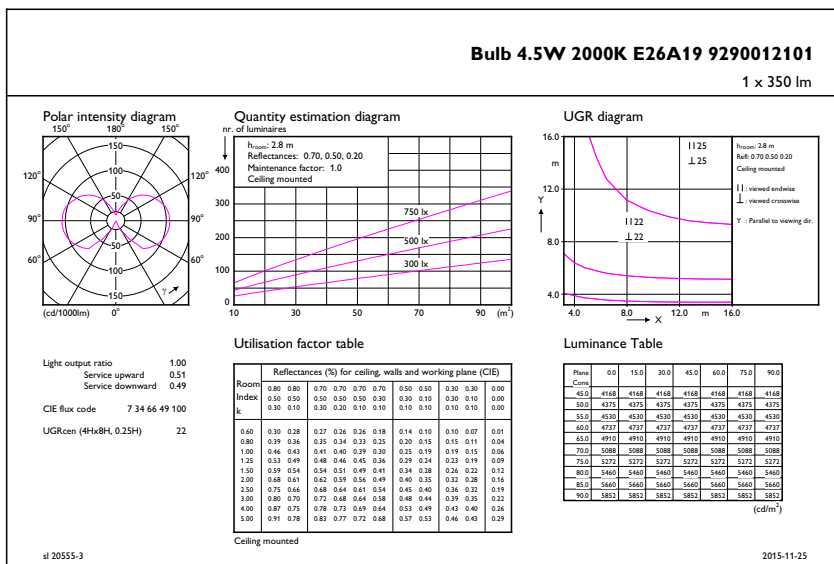

# LED Filament

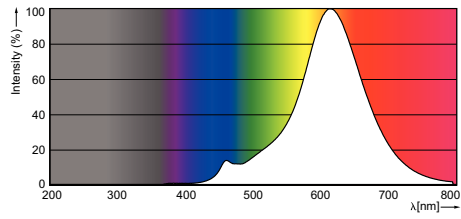

© 2016 Philips Lighting Holding B.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2016, June 15  
data subject to change